



LED Corn Cobs

150CC/LED/850/ND EX39 G2 BB 3/1

Philips Corn Cob LED replacement lamps are perfect LED replacement for a variety of outdoor applications. High intensity illumination, which means you get added visibility for applications like streets, public areas, and much more for a fraction of the energy used by conventional HID.

Product data

General information	
Cap-Base	EX39 [Exclusionary Mogul Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	50000 h
Switching Cycle	50000X
Technical Type	150-400W
Light technical	
Color Code	850 [CCT of 5000K]
Luminous Flux (Nom)	24000 lm
Color Designation	Daylight
Correlated Color Temperature (Nom)	5000 K
Luminous Efficacy (rated) (Nom)	160.00 lm/W
Color Consistency	ANSI 5000K quadrangle
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and electrical	
Input Frequency	50 to 60 Hz
Power (Nom)	150 W
Lamp Current (Nom)	1320 mA
Wattage Equivalent	320-400 W
Starting Time (Nom)	1 s


Warm Up Time to 60% Light (Nom)	1 s
UL Type	Type B - bypass the ballast
Power Factor (Nom)	0.9
Voltage (Nom)	120-277 V
Temperature	
T-Case Maximum (Nom)	75 °C
Controls and dimming	
Dimmable	No
Mechanical and housing	
Bulb Finish	Clear
Bulb Material	Plastic
Bulb Shape	Corncob
Approval and application	
Energy Consumption kWh/1000 h	150 kWh
Product data	
Order product name	150CC/LED/850/ND EX39 G2 BB 3/1
EAN/UPC - Product	046677559892
Order code	929002397804

LED Corn Cobs

Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	3
Material Nr. (12NC)	929002397804

Net Weight (Piece)	0.938 kg
--------------------	----------


Dimensional drawing

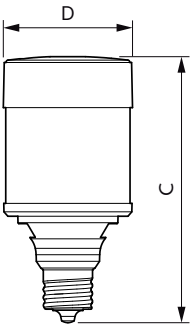


150CC/LED/850/ND EX39 G2 BB 3/1

Product	D	C
150CC/LED/850/ND EX39 G2 BB 3/1	102 mm	211 mm


Photometric data

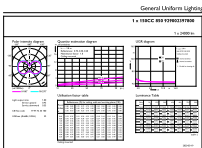

General Uniform Light

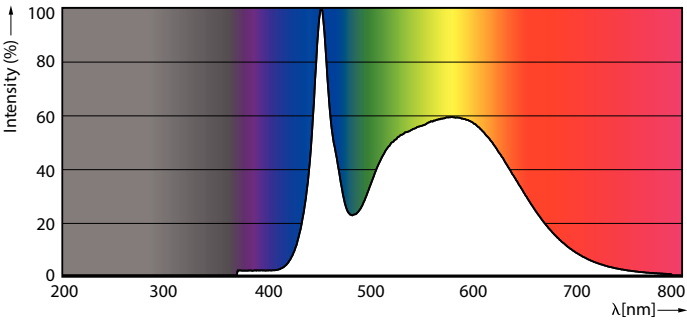

LEDTForce 150W Corncob EX39 850

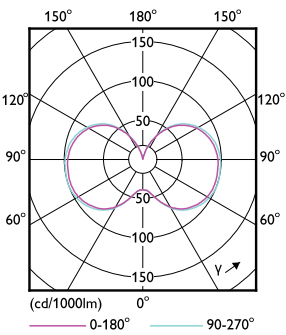


LEDTForce 115W Corncob EX39

LED Corn Cobs

Lifetime



50K

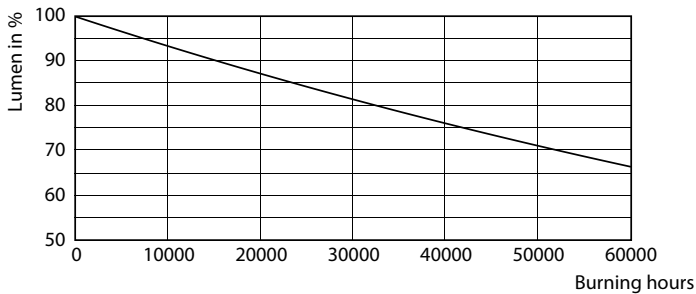

50K

