

SK | AIR CURTAIN™

CEILING FAN HEATER



**AIR
CURTAIN™**



HEAT FROM ABOVE

The Air curtain ceiling fan heater silently beams down heat from above. This unique model is ideal for rooms where wall space is limited. In bathrooms, the Air curtain can be installed just outside the shower or bathtub. With its ceiling-recessed casing, the Air curtain is an excellent way to provide discreet air circulation. The result: uniform heating and air movement, and reduction in mirror and window fog. By adding a wall timer, you can use it on demand.

CEILING MOUNTED

IDEAL FOR ROOMS WITH LIMITED WALL SPACE

HEATING ON DEMAND

OPTIONAL WALL TIMER

COMPACT AND QUIET

347 V MODEL AVAILABLE

COLOURS

- **standard:** white, soft white

FINISH

- epoxy-polyester powdercoat

MANUFACTURING

- 22-gauge steel cabinet and 1/4 in. (6.4 mm) deep 20-gauge steel front grille
- easy access for maintenance (no screws)

THERMAL PROTECTION

- thermal protection with automatic reset

ELEMENT

- nichrome element produces instant heat

CONTROL

- built-in thermostat (optional)
- wall thermostat (not included) – the use of an electronic thermostat is strongly recommended
- 60 minute timer (optional)

INSTALLATION

- ceiling mounted (recommended height 8 ft., maximum 9 ft.)
- surface mounted with surface adapter (optional)
- recessed or surface mounted with adapter for suspended ceiling (optional)
- unit can be mounted parallel or perpendicular to ceiling beams
- approved to be recessed in mineral wool; for all other materials please check with insulating product manufacturer

WARRANTY

- five years

IDEAL FOR:

bathroom, entryway, daycare centre, room with limited wall space

°**STELPRO**




FC_SK_EN_270420

TECHNICAL SPECIFICATIONS

WITHOUT CONTROL		BUILT-IN THERMOSTAT		24 V CONTROL		POWER	VOLTAGE	FLOW	THROW DISTANCE		HEAT RISE		WEIGHT	
CODE		CODE		CODE		WATTS	VOLTS	CFM	M	FT.	°C	°F	KG	LB
SK0501		---		---		500	120	60	2.4	8	26	46	5	11
SK0508		---		---		500	208	60	2.4	8	26	46	5	11
SK0502		---		---		500/375	240/208	60	2.4	8	26	46	5	11
SK0503		SK0503T		SK0503C24		500	347	60	2.4	8	26	46	5	11
SK0751		---		---		750	120	60	2.4	8	42	75	5	11
SK0758		---		---		750	208	60	2.4	8	42	75	5	11
SK0752		---		---		750/560	240/208	60	2.4	8	42	75	5	11
SK0753		SK0753T		SK0753C24		750	347	60	2.4	8	42	75	5	11
SK1001		---		---		1000	120	60	2.4	8	54	97	5	11
SK1008		---		---		1000	208	60	2.4	8	54	97	5	11
SK1002		---		---		1000/750	240/208	60	2.4	8	54	97	5	11
SK1003		SK1003T		SK1003C24		1000	347	60	2.4	8	54	97	5	11
SK1251		---		---		1250	120	60	2.4	8	79	143	5	11
SK1258		---		---		1250	208	60	2.4	8	79	143	5	11
SK1252		---		---		1250/940	240/208	60	2.4	8	79	143	5	11
SK1253		SK1253T		SK1253C24		1250	347	60	2.4	8	79	143	5	11
SK1501		---		---		1500	120	60	2.4	8	102	184	5	11
SK1508		---		---		1500	208	60	2.4	8	102	184	5	11
SK1502		---		---		1500/1125	240/208	60	2.4	8	102	184	5	11
SK1503		SK1503T		SK1503C24		1500	347	60	2.4	8	102	184	5	11
---		---		---		2000	120	90	3.2	10'6"	109	196	5	11
---		---		---		2000	208	90	3.2	10'6"	109	196	5	11
SK2002		---		---		2000/1500	240/208	90	3.2	10'6"	109	196	5	11
SK2003		SK2003T		SK2003C24		2000	347	90	3.2	10'6"	109	196	5	11

Add W for white or SW for soft white

TECHNICAL DRAWINGS

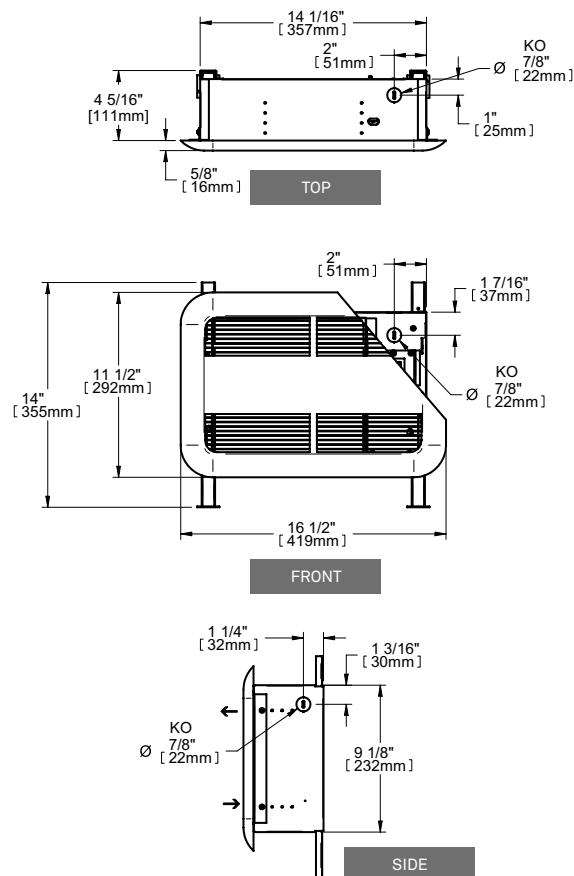

ACCESSORIES

PRODUCT	DESCRIPTION
SKT1*	tamper-proof built-in thermostat [120 V-347 V] (grille must be removed to access this type of thermostat)
SKTBA*	adapter for suspended ceiling (2 ft. x 2 ft.) – recessed or surface mounted with surface adapter (not included)
SKSA*	surface adapter (SK model)
FD60MCW70	60 minute wall timer [120 V-277 V]
SKRE153T*	built-in electronic low voltage relay c/w transformer 24 V [15 A @ 208 V-347 V]

* Add W for white or SW for soft white.

* Factory installed

