

# T822K1034

THERMOSTAT – LOW VOLTAGE / 24 V

## COLOUR

- white

## VOLTAGE

- 1.2 A @ 24 Vac

## CONTROL

- two-wire connection
- all or nothing (on/off) @ 24 Vac
- compatible with all RE, RM and R841 model relays
- temperature in degrees Celsius

## TEMPERATURE RANGE

- 10 to 30 °C (50 to 86 °F)

## WARRANTY

- one year



PRODUCT	DESCRIPTION
T822K1034	LOW VOLTAGE THERMOSTAT (24 V)

Dimensions: 2.83 in. x 4.75 in. x 1.46 in. (71.9 mm x 120.7 mm x 37.1 mm)



# T87K1015

THERMOSTAT – LOW VOLTAGE / 24 V

## COLOUR

- white

## VOLTAGE

- 1 A @ 24 Vac

## CONTROL


- two-wire connection
- all or nothing (on/off) @ 24 Vac
- compatible with all RE, RM and R841 model relays
- temperature in degrees Celsius

## TEMPERATURE RANGE

- 10 to 30 °C (50 to 86 °F)

## WARRANTY

- one year

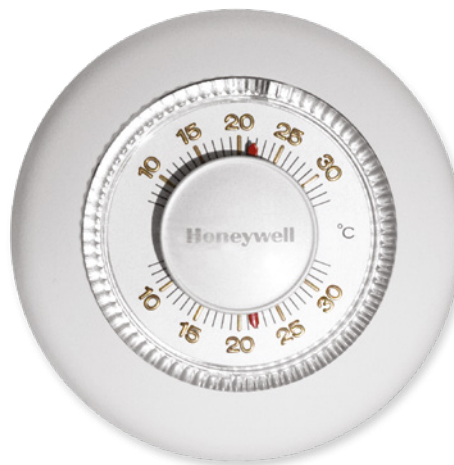

PRODUCT	DESCRIPTION
T87K1015	LOW VOLTAGE THERMOSTAT (24 V)

Dimensions: 3 11/16 in. diameter x 1 3/4 in. (93.7 mm diameter x 44.5 mm)



°STELPRO