

ASKS

KICK SPACE HEATER



HIDE 'N HEAT

“Hide 'n heat” is what the SKS kick space heater by °STELPRO offers. Its sleek, redesigned grille is slimmer than ever for easy installation in narrow spaces under kitchen or bathroom cabinets or in stair risers. Enjoy comfortable forced-air heating from the most discreet fan heater on the market.

POWER SELECTOR SWITCH

EASY INSTALLATION

ATTRACTIVE GRILLE ONE-PIECE, FRAMELESS

COLORS

- **standard:** white, soft white
- **luxury finish:** stainless steel

FINISH

- epoxy-polyester powdercoat or stainless steel

MANUFACTURING

- 22-gauge steel cabinet and 16-gauge steel front
- quiet, 50 CFM capacity
- thermal protection with automatic reset
- added protection provided by a fuse-link (must be replaced once activated)

WATTAGE AND VOLTAGE

- power selector switch

ELEMENT

- tubular element sheathed with spiral-wound fins for improved heat dissipation

CONTROL

- wall thermostat (not included) – the use of an electronic thermostat is strongly recommended
- built-in thermostat (optional)

INSTALLATION

- recessed

WARRANTY

- five years, *three years on electronic components

IDEAL FOR:

under a kitchen or bathroom cabinet, in a stair riser




TECHNICAL SPECIFICATIONS

PRODUCT	POWER	VOLTAGE	THROW DISTANCE (IN FRONT)	HEAT RISE	WEIGHT
CODE	WATTS	VOLTS	FT.	°F	LB
ASKS1001	500 OR 1000	120	4	99	10
ASKS1002	500/375 OR 1000/750	240/208	4	99	10

Add W for white, SW for soft white or SS for stainless steel

TECHNICAL DRAWINGS

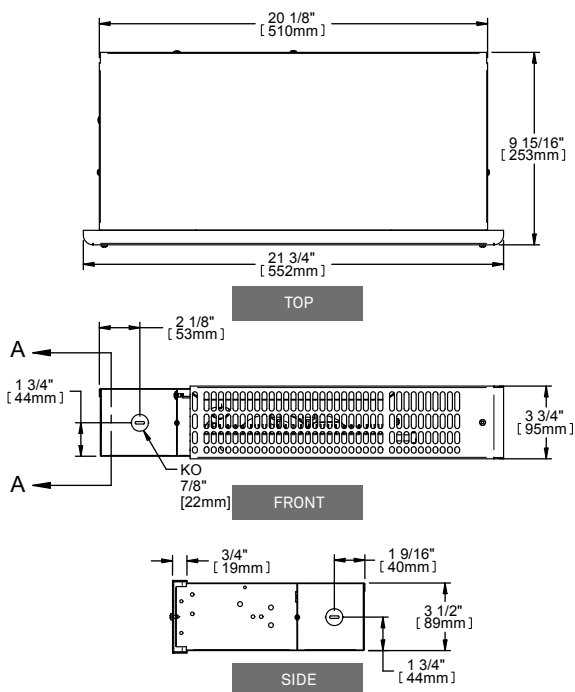

ACCESSORIES

PRODUCT	DESCRIPTION
SKST1	built-in single pole thermostat
SKST2	built-in tamper-proof double pole thermostat
SKSR*	extended grille (23 5/8 in. x 3 3/4 in. – 600 mm x 95 mm) allows to cover gaps or imperfections for a renovation project
SKSRSS	extended stainless steel grille (23 5/8 in. x 3 3/4 in. – 600 mm x 95 mm) allows to cover gaps or imperfections for a renovation project

* Add W for white or SW for soft white.