

°STELPRO

HIGH-END CONVECTOR

SOR SERIES

PATENTS PENDING

ORLÉANS™

INNOVATION TO MAXIMIZE YOUR COMFORT

°STELPRO has reinvented the convector with the new ORLÉANS™ high-end convector. With its unique design, the ORLÉANS™ offers a faster temperature rise than any other convector on the market, ensuring optimal comfort in no time at all. The optional built-in thermostat is equipped with the ZigBee protocol, so it can be connected to the smart home. In addition, the convector is available in optional colours exclusive to °STELPRO, colours that will enhance even the most simple decor. Energy efficiency, connectivity, adjusted profile and a wide variety of models, the ORLÉANS™ is now the benchmark for high-end convectors.



30% SLIMMER CONVECTOR*

STYLISH AND COMPACT DESIGN

OPTIMUM EFFICIENCY

TEMPERATURE RISE 25% FASTER*

BUILT-IN THERMOSTAT AVAILABLE (OPTIONAL)

READY FOR THE SMART HOME

QUICK AND EASY INSTALLATION

EXCLUSIVE BRACKET SYSTEM

NEW STYLISH WHITE SATIN FINISH

IDEAL FOR:

LIVING ROOMS, KITCHENS, BEDROOMS, OFFICES, HALLWAYS, BASEMENTS, BUSINESSES, WAITING ROOMS, CONFERENCE ROOMS

COLOURS

– standard: white, soft white

FINISH

epoxy-polyester powdercoat

MANUFACTURING

- 20-gauge steel cabinet and front
- aluminum grille and front of sides
- bottom air intake and top air discharge
- the cabinet height improves the chimney effect
- safe, rounded corners
- easy access to controls
- thermal protection with automatic reset

ELEMENT

aluminum extrusion, X-shaped one-piece to generate maximum heat

CONTROL

- built-in thermostat equipped with the ZigBee protocol
- consumption indicator going from green or red depending on the required set temperature
- open window detector

INSTALLATION

- surface
- wall mounted at least 4 in. from the floor
- innovative mounting bracket facilitating height adjustment

* Compared to similar convectors. Heat rise tested in laboratory.




TECHNICAL SPECIFICATIONS

| BUILT-IN THERMOSTAT | | WITHOUT THERMOSTAT | | POWER | VOLTAGE | LENGTH | | WEIGHT | |
|---|--|--------------------|--|-----------|---------|--------|--------|--------|------|
| CODE | | CODE | | WATTS | VOLTS | MM | IN. | KG | LB |
| HIGH MODEL - height of 27 7/8 in. (708 mm) | | | | | | | | | |
| SORH1002 | | SORH1002WC | | 1000/750 | 240/208 | 457 | 18 | 6.8 | 15 |
| SORH1502 | | SORH1502WC | | 1500/1125 | 240/208 | 623 | 24 1/2 | 8.8 | 19.4 |
| SORH2002 | | SORH2002WC | | 2000/1500 | 240/208 | 768 | 30 1/4 | 10.5 | 23.2 |
| LOW MODEL - height of 13 in. (330 mm) | | | | | | | | | |
| SORL1002 | | SORL1002WC | | 1000/750 | 240/208 | 750 | 29 1/2 | 5.2 | 11.5 |
| SORL1502 | | SORL1502WC | | 1500/1125 | 240/208 | 1113 | 38 7/8 | 6.9 | 15.2 |
| SORL2002 | | SORL2002WC | | 2000/1500 | 240/208 | 1276 | 50 1/4 | 8.3 | 18.3 |
| STANDARD MODEL - height of 17 7/8 in. (455 mm) | | | | | | | | | |
| SOR0502 | | SOR0502WC | | 500/375 | 240/208 | 457 | 18 | 4.8 | 10.7 |
| SOR1002 | | SOR1002WC | | 1000/750 | 240/208 | 597 | 23 1/2 | 6 | 13.2 |
| SOR1502 | | SOR1502WC | | 1500/1125 | 240/208 | 743 | 29 1/4 | 7.2 | 15.9 |
| SOR2002 | | SOR2002WC | | 2000/1500 | 240/208 | 895 | 35 1/4 | 9.7 | 21.4 |

Add W for white or SW for soft white
Thermostat included except WC = without control.

TECHNICAL DRAWINGS

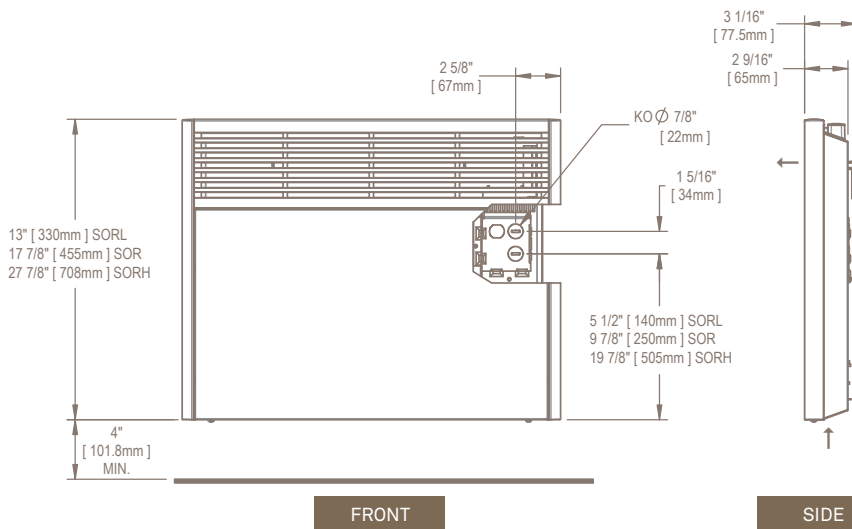

CONTROL



BUILT-IN ELECTRONIC THERMOSTAT READY FOR THE SMART HOME (OPTIONAL)

CONTROL THE TEMPERATURE FROM YOUR SMARTPHONE, TABLET AND COMPUTER



REQUIRED



ZigBee
COMPATIBLE
CONTROLLER

