

## PLASTIC EXIT

NRCan C860 Registered  
LED 120/347VAC Input


**Approvals:**

CSA Certified to C22.2 #141.15 and C860

**DESCRIPTION**

The EXPT series of commercial plastic exit signs is designed using durable and lightweight high impact thermoplastic. Signs and canopy quick snap together for speedy installations. Available in AC only, AC/DC and internally self-powered versions.

**CIRCUITRY - AC & AC/DC**

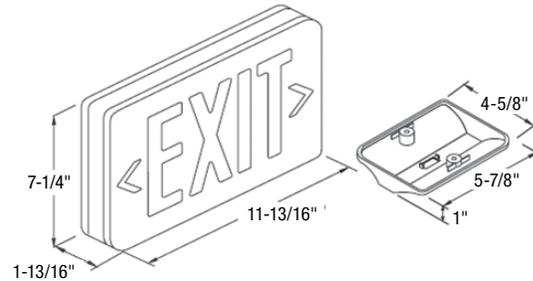
- LED ultra bright light source
- 120/347VAC Input, field selectable
- 2.7 Watt power consumption single or double face
- Emergency DC wattages as follows:  
**6VDC = 0.9W 12VDC = 1.0W 24VDC = 1.4W**

**CIRCUITRY - SELF-POWERED**

- LED ultra bright light source
- 120/347VAC Input, field selectable
- 2.7 Watt power consumption single or double face
- High-performance, sealed Ni-Cad battery
- 90 minutes emergency duration (standard)
- Solid state transfer and battery charger


**MECHANICAL**

- High impact, UV stabilized, thermoplastic construction
- Quick snap faceplates, backplate and universal canopy for rapid and simple installation
- Snap out directional chevrons/arrows
- Universal spider knockout pattern stamped into backplate for junction box mounting
- Universal models include ceiling or end mount, field installable canopy kit c/w spider plate
- White colour is standard

**DIMENSIONS**

**ORDERING GUIDE**

EXPT	U	M	WHT	/	
Series	Nbr of faces	Mounting	Colour	DC Voltage	Options†
EXPT	U - Universal faces	M - Universal	WHT - White	<b>Blank</b> - AC only <b>UNVDC</b> - Universal DC backup voltage 6, 12 or 24VDC selectable <b>BAT</b> - Self-powered for 90 minutes	<b>WRG*, LXG</b>

† For detailed options descriptions, please consult the options page.

\* Specify mounting.