

LED DUSK TO DAWN YARD LIGHT

49W (5046 lumens)



Approvals:
cULus listed
Suitable for outdoor use.
Powered by CREE LED



QUICKSHIP



LED



Not all products are qualified on the DLC QPL. To view our DLC qualified products, please consult the DLC Qualified Products List at www.designlights.org/search.



DESCRIPTION

The Y4D-L series are energy conserving dusk to dawn yard lights. They are a versatile and economic light source that is good on the environment and uses long life LED's for energy efficiency. The Y4D-L comes standard with a photocell which helps to provide significant power savings. It includes an installation bracket for pole and wall mounting and a 21" arm for ease and versatility of installation. All units come standard with 6 feet of cable to facilitate the connection to the junction box when mounting with the pole arm.

TECHNICAL SPECIFICATIONS


- Grey die cast housing
- Standard with photocell (120V only) and 21" arm
- Input voltage: 120V AC
- High quality, long life LEDs
- Estimated lifespan of 50 000 hours
- 4000K colour temperature
- Ambient operating temperature range of -40°C to +40°C

Accessory (order SEPARATELY)

PH0009

Shorting cap

DIMENSIONS

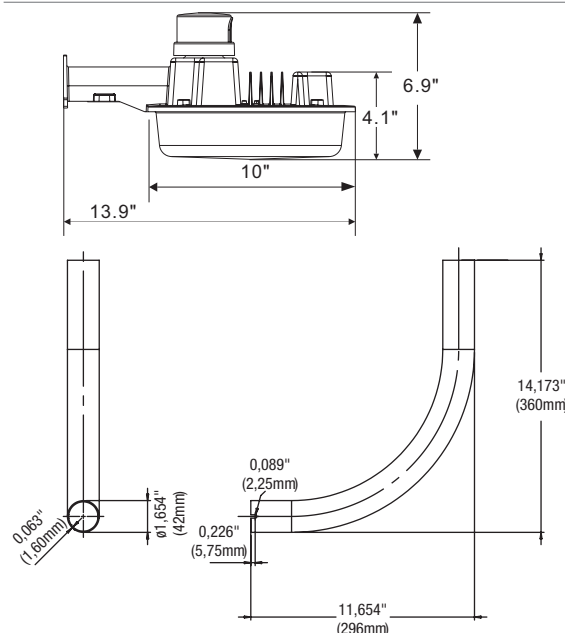

ORDERING GUIDE

Y4D	L	A2	4	4K	PT120
Series	Lamp type	Lumen package	Voltage	Colour temperature	Mandatory selection
Y4D	L - LED	A2 - 49W (5046 lumens)	4 - 120V	4K - 4000K	PT120 - 120V Photocell (twist-lock - standard) with arm