

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1300940246](#)  
**Status:** **Active**  
**Overview:** [Support Grips](#)  
**Description:** Standard Duty Support Grip, Single Eye, Closed Mesh, Single Weave, Cable Diameter 63.50-75.95mm (2.500-2.990"), Approximate Break Strength 1705.51kg (3760 lbs)

**Documents:**

[RoHS Certificate of Compliance \(PDF\)](#)      [Product Literature \(PDF\)](#)

**Agency Certification**


CSA      LR32159

**General**

Product Family	Cable Grips
Series	<a href="#">130094</a>
Eye Type	Single
O-Ring	N/A
Overview	<a href="#">Support Grips</a>
Product Literature Order No	987650-8065
Product Name	Standard Duty
Type	Support Grip
UPC	78678835038
Woodhead	Yes
<b>Physical</b>	
Approximate Break Strength	1705.51kg (3760 lbs)
Bale Length	0.457m (18.00")
Body Style	Straight
Cable Diameter	63.50-75.95mm (2.500-2.990")
Color - Grommet	N/A
Gender	N/A
Material - Body	N/A
Material - Grip	Non-magnetic Tin Bronze Wire
Mesh Length	0.61m (24.00")
Number of Holes	N/A
Thread Size	N/A

**Material Info**

Engineering Number      35038

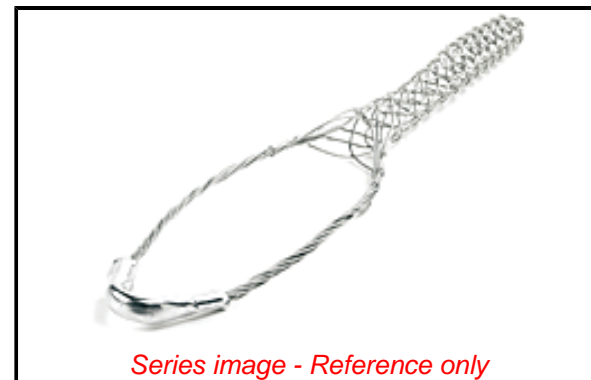

*Series image - Reference only*

**EU ELV**

**Not Reviewed**

**EU RoHS**

**Not Reviewed**

**REACH SVHC**

Not Reviewed

**Halogen-Free**

**Status**

**Not Reviewed**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

**Search Parts in this Series**

[130094 Series](#)

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**