


# Manual Controller

1228

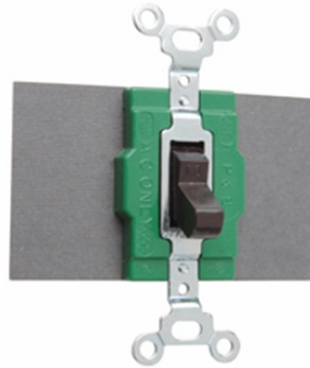

Double Pole, Double Throw Switch, 30 amps, 120/277 volts, Brown.

## features & benefits

- Oversize silver alloy contacts for long life and better heat dissipation.
- Side wired terminals accept #14 - #10 AWG copper or copper-clad conductors.
- Fiber terminal insulation barriers standard.
- Can be mounted in standard device boxes or in NEMA 1 sheet steel enclosures.
- Bodies, covers, and toggles molded of durable nylon.
- Single Pole-Double Throw and Double Pole-Double Throw.
- Locking Switches supplied with one 1498-NT key.
- Normally open.



## specifications

### General Info

Color: Brown  
Type: Maintained Contact  
Number Of Poles: 2  
Special Features: Two Circuit

### Listing Agencies/Third Party Information

CSA Listing Info: Yes  
CUL Listing No: No  
cULus: No  
cURus: No

Federal Spec: No  
UL Listing No: Yes  
UN SPS C: 39121507  
UR: No

**Dimensions**

Depth U S: 1.469"  
Height U S: 3.281"  
Weight: 0.29289  
Width U S: 1.5"

**Technical Information**

Amps: 30 Amp  
Volts: 120/277VAC  
Volts A C: 120/277

**Buy American Act Compliance**

Country of Origin: MEXICO  
Buy American Act Status: Trade Agreement Act Compliant