


TradeMaster Receptacle, Black

3232BK

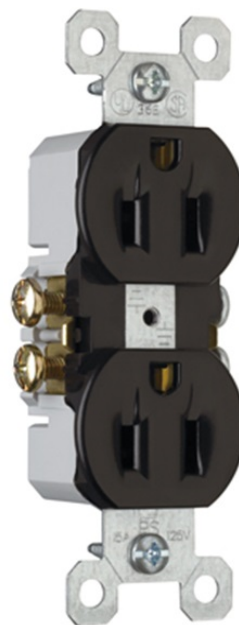

Duplex Grounding Receptacle. 15 amp,
125 volt, Black.

features & benefits

- High-impact resistant thermoplastic construction.
- Extra-long strap. Quickloop wire looping aid.
- Long-term blade retention.
- Longer tri-drive screws for easier #12 AWG looping.
- Extra-large circuit break-off tabs.
- Side-access push wire release.
- Ultrasonic welding of face to back body.
- Side wire accepts #12 - #14 AWG solid wire.
- Push wire accepts #14 AWG solid only.
- Low profile face.
- Traditional contoured face.
- (3232 models) Self-grounding models provide automatic ground clip.

specifications

General Info

Color: Black
Number Of Poles: 2
Number Of Wires: 3

Listing Agencies/Third Party Information

CSA Listing Info: C22.2 No.42
CSA Standard: Yes
Federal Spec: No

UL Listing No: UL498
UL Standard: Yes
UN SPS C: 39121406

Dimensions

Depth U S: 0.96"
Height U S: 3.31"
Width U S: 1.32"

Technical Information

Amps: 15
Volts: 125
Volts A C: 125

Buy American Act Compliance

Country of Origin: CHINA
Buy American Act Status: No