

# Brick Light

## 120V Horizontal / Louver / Open SPECIFICATION SHEET

**GM Lighting**®

Project Name	Type
Catalog #	Date

### PRODUCT OVERVIEW

GM Lighting's new take on brick lighting has resulted in this extensive collection of modern brick lights. Available in horizontal scoop, open horizontal and horizontal louver formats. Perfect for step lighting, path lighting, deck lighting in stairs or railings.



### FEATURES

- 3000K color temperature
- 80+ CRI
- No visible mounting hardware
- Dry and Wet location
- Four Finishes: White, Black, Bronze and Brushed Nickel
- Three Horizontal Faceplate Options: Open, Scoop and Louver
- Die-cast zinc magnesium rough-in housing

### SPECIFICATIONS

#### ELECTRICAL

- 120VAC
- 5W / 60Hz

#### OPERATING TEMP

- -4 to 122°F (-20 to +50°C)

#### CERTIFICATION

- ETL listed for wet locations

#### WARRANTY

- 5-year limited warranty

### ORDERING INFORMATION

Model	Format
GBL-MO	Rough-in housing for open and louver faceplate
GBL-MR	Rough-in housing for horizontal scoop faceplate

### FACEPLATES

Model	Format
GBL-FPO-WH	White Faceplate, Open
GBL-FPO-B	Black Faceplate, Open
GBL-FPO-BZ	Bronze Faceplate, Open
GBL-FPO-BN	Brushed Nickel Faceplate, Open
GBL-FPLV-WH	White Faceplate, Louver
GBL-FPLV-B	Black Faceplate, Louver
GBL-FPLV-BZ	Bronze Faceplate, Louver
GBL-FPLV-BN*	Brushed Nickel Faceplate, Louver
GBL-FPH-WH	White Faceplate, Scoop
GBL-FPH-B	Black Faceplate, Scoop
GBL-FPH-BZ	Bronze Faceplate, Scoop
GBL-FPH-BN	Brushed Nickel Faceplate, Scoop



GBL-FPLV-BZ



GBL-FPH-WH



GBL-FPO-BN

### ACCESSORIES

Model	Format
GBL-SMB	(2) Brick Light Stud Mounting Brackets w/Screws

\*Note: COMING SOON - Brushed Nickel in Louver format


# Brick Light

## 120V Horizontal / Louver / Open SPECIFICATION SHEET




### DIMENSIONS

#### HORIZONTAL

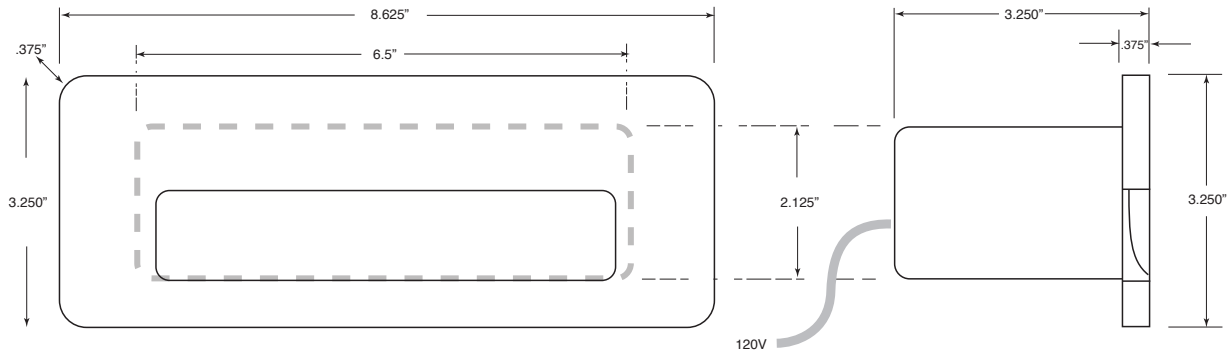

#### LOUVER

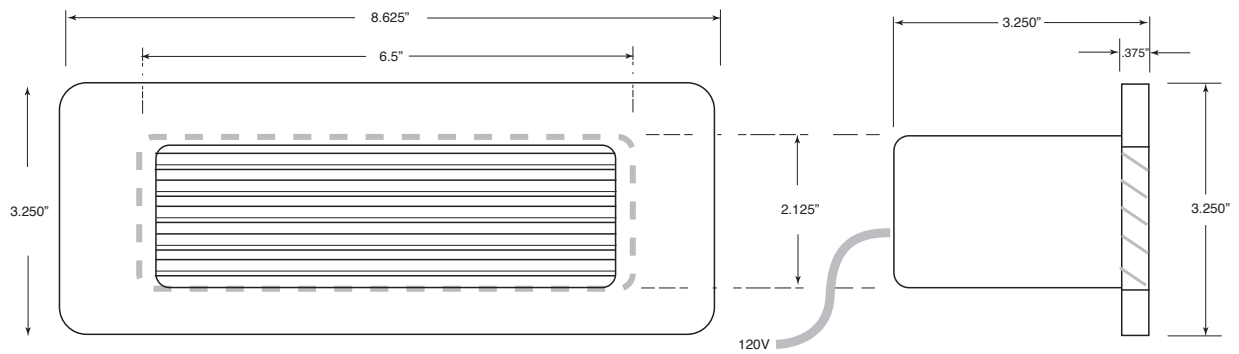

#### OPEN

