

**OS160LED**

OUTDOOR SECURITY SOLUTIONS FOR RESIDENTIAL APPLICATION



NAME:	
TYPE:	
DATE:	
NOTES:	

**SPECIFICATIONS**

<b>LIGHT UNIT:</b>	Rugged cast-aluminum, corrosion-resistant housing with dark bronze or white powder paint for lasting durability.
	LED lamp heads are thermally isolated from the driver that is located in the rear housing, promoting a long service life.
	Lenses are sealed to keep out moisture, dirt and bugs.
	LEDs maintain 70% of light output at 50,000 hours of service life.
<b>INSTALLATION:</b>	Crossbar and hardware provided.
	Wet location listed for mounting 4 feet above ground.
	Tool-less adjustable heads allow for precise aiming.
<b>ELECTRICAL:</b>	Dual mount system: Can be mounted on walls or soffits
	Energy efficient LED provides 2300 lumens, consumes 27W utilizing 120V 60Hz driver.
	Adjustable dusk-dawn photocell provided as standard. Rated for outdoor installations, -40°C minimum ambient.
	Selectable color temperature, choice of 3000K or 4000K.
	<b>LISTINGS</b> UL/cUL listed Listed to U.S. and Canadian safety standards for wet locations.

COLOR TEMPERATURE:	3K or 4K Selectable
OPERATING TEMPERATURE:	-40°C + 40°C
CRI:	70+
LUMEN OUTPUT:	2400LM
WATTS:	23W
LED LIFE:	50,000 hours
WARRANTY:	5 years
VOLTAGE:	120V


**APPLICATIONS**

The high-performance LED CCT oval twin-head security light offers security and general lighting for outdoor residential and commercial applications. Long lasting, energy saving illumination ideal for yards, driveways, walkways, lots and loading areas.

# OS160LED

OUTDOOR SECURITY SOLUTIONS FOR RESIDENTIAL APPLICATION

## DIMENSIONS

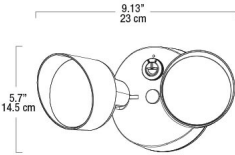

## RATINGS



## ORDERING GUIDE

### OS160LED SERIES

**Series**  
OS160LEDPC-2HO

**Finish**  
DB Dark Bronze  
WH White

**Notes:** Configure product using **BOLD** options: Ex: **OS160LEDPC-2HO-WH**