

24
VOLT



90+
CRI

CLASS
2



5 Yr.
WARRANTY




LTR-S

Tunable White LED Tape

The LTR-S-TUN-24V Tunable White LED Tape enables light to be 'fine tuned' over a spectrum of white color temperatures, therefore, allowing subtle to stark ambiance changes to match the mood, the event, or the subject illuminated. Our Tunable White LED Tape can be adjusted from 2400K to 5000K.

KEY FEATURES:

- 24VDC
- 1.5W/ft., 3.0W/ft. and 5W/ft.
- 90+ CRI
- 2400K to 5000K
- Dry location
- IP20
- Premium diodes
- 120° viewing angle
- Dimmable
- Controlled by LUXcontrol or ChromaDim
- Cuttable every 2"
- 3M adhesive back
- 48" of lead affixed at start of reel
- Max. run: 1.5W and 3W=32'-8" 5.0W=16'-4"
- Custom lengths available consult factory
- ETL listed
- 5 year warranty when used with GM power supply

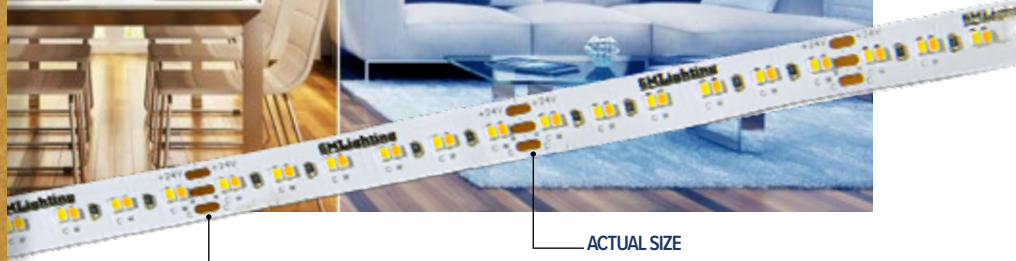

2400K

5000K

Special Tape Product No. Example

LTR-S - TUN - 24V - X.XW - 16

SERIES PREFIX
(S = SPEC)

TYPE

VOLTAGE

WATTS / FOOT
1.5W
3.0W
5.0W

REEL LENGTH
16 = 16'-4"
CUSTOM CUT FEET-INCHES (CUTS MADE IN 2" INCREMENTS)

TITLE 24 COMPLIES WITH TITLE 24 WHEN USED WITH SPECIFIC DRIVERS. CONSULT FACTORY.

FOR PROPER THERMAL MANAGEMENT, MOUNT THIS PRODUCT IN CHANNEL (RECOMMENDED FOR 5W)

ORDERING INFORMATION

| Product No. | Output | Wattage per foot | Type | Length | Lumens per foot | CRI | Color Temp. | Max. Run |
|------------------------|--------|------------------|------|-------------|-----------------|-----|-------------|----------|
| LTR-S-TUN-24V-1.5W-16 | 24VDC | 1.5W | TUN | 16'-4" / 5M | 162 (3500K) | 90+ | 2400K-5000K | 32'-8" |
| LTR-S-TUN-24V-1.5W-100 | 24VDC | 1.5W | TUN | 16'-4" / 5M | 162 (3500K) | 90+ | 2400K-5000K | 32'-8" |
| LTR-S-TUN-24V-1.5W-FT | 24VDC | 1.5W | TUN | 16'-4" / 5M | 162 (3500K) | 90+ | 2400K-5000K | 32'-8" |
| LTR-S-TUN-24V-3.0W-16 | 24VDC | 3.0W | TUN | 16'-4" / 5M | 267 (3500K) | 90+ | 2400K-5000K | 32'-8" |
| LTR-S-TUN-24V-3.0W-100 | 24VDC | 3.0W | TUN | 16'-4" / 5M | 267 (3500K) | 90+ | 2400K-5000K | 32'-8" |
| LTR-S-TUN-24V-3.0W-FT | 24VDC | 3.0W | TUN | 16'-4" / 5M | 267 (3500K) | 90+ | 2400K-5000K | 32'-8" |
| LTR-S-TUN-24V-5.0W-16 | 24VDC | 5.0W | TUN | 16'-4" / 5M | 415 (3500K) | 90+ | 2400K-5000K | 16'-4" |
| LTR-S-TUN-24V-5.0W-100 | 24VDC | 5.0W | TUN | 16'-4" / 5M | 415 (3500K) | 90+ | 2400K-5000K | 16'-4" |
| LTR-S-TUN-24V-5.0W-FT | 24VDC | 5.0W | TUN | 16'-4" / 5M | 415 (3500K) | 90+ | 2400K-5000K | 16'-4" |

16'-4" reel includes 48" lead affixed to tape.

CONNECTORS

| Connector Product No. | Description |
|-----------------------|--|
| LTR-S-TUN-SP | SPLICE CONNECTOR |
| LTR-S-TUN-TPC60 | 60" ADJUSTABLE TAPE TO POWER CONNECTOR |
| LTR-S-TUN-TTC3 | 3" ADJUSTABLE TAPE TO TAPE CONNECTOR |
| LTR-S-TUN-TTC12 | 12" ADJUSTABLE TAPE TO TAPE CONNECTOR |
| LTR-S-TUN-TTC24 | 24" ADJUSTABLE TAPE TO TAPE CONNECTOR |
| LTR-S-TUN-TTC36 | 36" ADJUSTABLE TAPE TO TAPE CONNECTOR |
| LTR-S-TUN-TTC60 | 60" ADJUSTABLE TAPE TO TAPE CONNECTOR |

Connectors ordered separately.

LTR-S TAPE DIAGRAMS: PAGE 20
MUD-IN / WALK OVER / COVE CHANNELS: PAGE 27
COMPLETE LIST OF CHANNELS AND CONNECTORS: PAGES 28-31
POWER SUPPLIES: PAGES 32-37