

LUXcontrol™ High Voltage

V120 SMART CONTROLLER

SPECIFICATION SHEET



Project Name	Type
Catalog #	Date


PRODUCT OVERVIEW

Our 120VAC high voltage controllers provide easy and reliable control of your tape light via GM's LUXcontrol™ App. Connect your single color high voltage luminaires to control dimming, set schedules, turn the lights ON and OFF and preset timers and scenes from the convenience of your smartphone or tablet.



FEATURES

- 120VAC input
- 2.4GHz WiFi required
- Single color
- Recommended for outdoor use - IP65
- Android™ and iOS® compatible
- Works with Google Assistant™ and Amazon Alexa™
- 3 year warranty

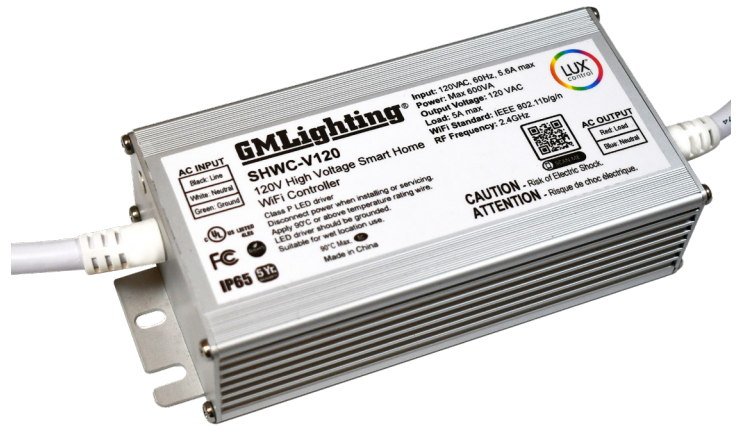

SPECIFICATIONS

ELECTRICAL

- 120VAC
- 5A max. load current
- 600W max. power

HOUSING

- Aluminum enclosure

OPERATING TEMP

- -4 to 122°F (-20 to +50°C)

CERTIFICATION

- FCC compliant
- IEEE 802.11b/g/n

WARRANTY

- 3-year warranty



ORDERING INFORMATION

Example: SHWC-V120

Model	Description
SHWC-V120	Smart 2.4GHz WiFi Controller, 120V High Voltage, IP65, 1-Channel / 2-Wire

ACCESSORIES

Model	Description
GM-WPSC	Universal Wet Location 3-wire splice connector




LUXcontrol™ High Voltage

V120 SMART CONTROLLER


SPECIFICATION SHEET





WIRING DIAGRAM

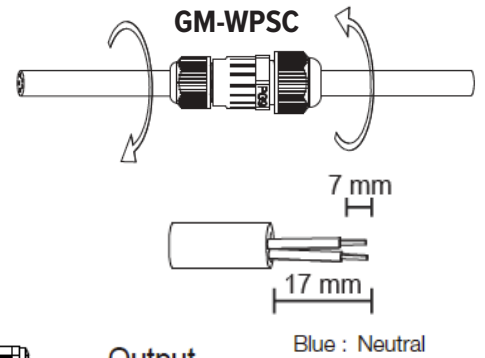

IMPORTANT!
Warning: High output voltage!

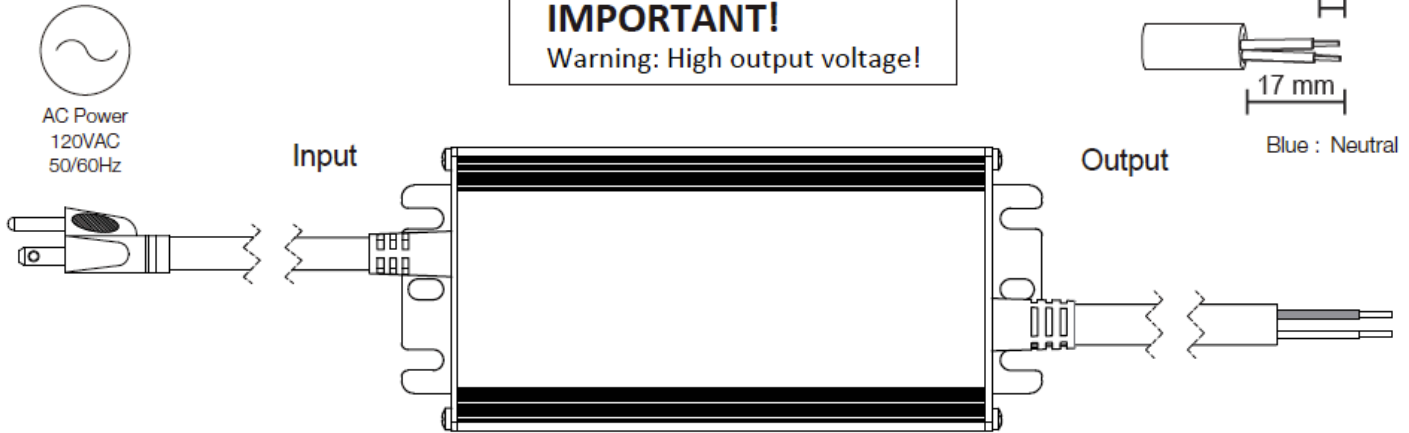

Max. current: 5A, max. load power: 600W

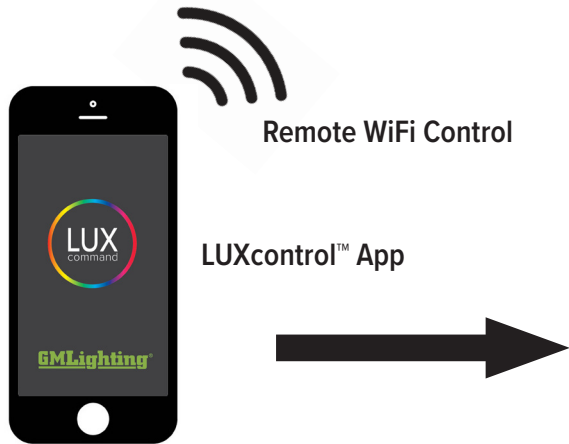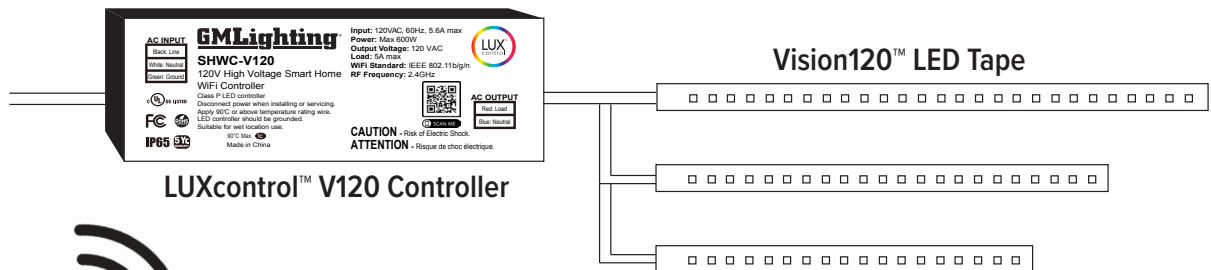

LUXcontrol™ High Voltage

V120 SMART CONTROLLER

SPECIFICATION SHEET



DIMENSIONS

