



A-Shape LED

8.8A19/PER/950/P/E26/DIM 6/1FB T20

Philips A-shape LED lamps are the LED alternative to standard incandescents. It provides beautiful light and dependable performance you expect from LED at an affordable price.

Product data

General information	
Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	50000X
Technical Type	8.8-60W

Light technical	
Color Code	950 [CCT of 5000K]
Beam Angle (Nom)	250°
Initial lumen (Nom)	800 lm
Color Designation	Daylight
Correlated Color Temperature (Nom)	5000 K
Luminous Efficacy (rated) (Nom)	90.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	8.8 W
Lamp Current (Nom)	80 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s

Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7
Voltage (Nom)	120 V

Temperature	
T-Case Maximum (Nom)	194 °F

Controls and dimming	
Dimmable	Yes

Mechanical and housing	
Bulb Finish	Frosted
Bulb Material	Plastic
Bulb Shape	A19 (A19)


Approval and application	
Energy Consumption kWh/1000 h	- kWh
Energy Certifications	Energy Star

Product data	
Order product name	8.8A19/PER/950/P/E26/DIM 6/1FB T20
EAN/UPC - Product	046677550455
Order code	550459
Numerator - Quantity Per Pack	1

A-Shape LED

Numerator - Packs per outer box	6
Material Nr. (12NC)	929002036304
Copy Net Weight (Piece)	0.132 lb



Dimensional drawing

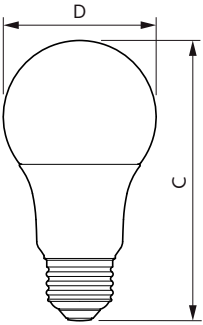

8.8A19/PER/950/P/E26/DIM 6/1FB T20

Product	D	C
8.8A19/PER/950/P/E26/DIM 6/1FB T20	2-1/2 in	4-7/16 in


Photometric data

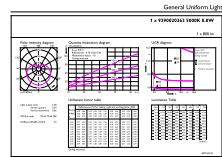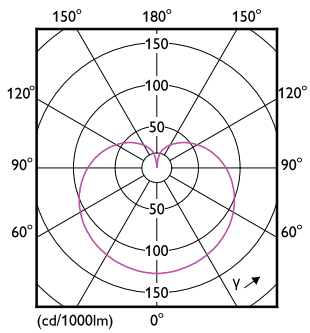

General Lighting Data

40 60 75 100W E26 A19 A21 Frosted



60W E26 A19 950 Frosted

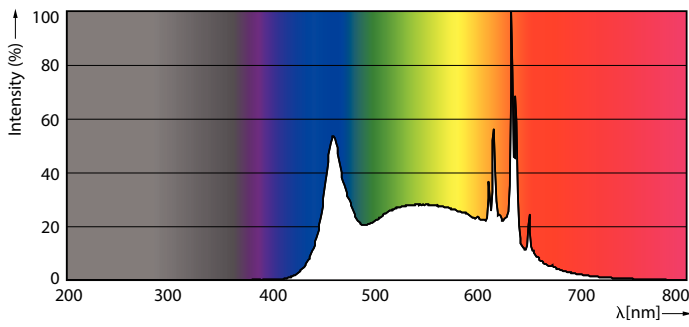

60W E26 A19 950 Frosted

A-Shape LED

Lifetime

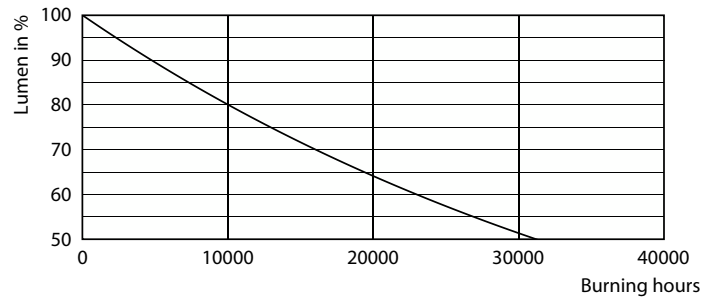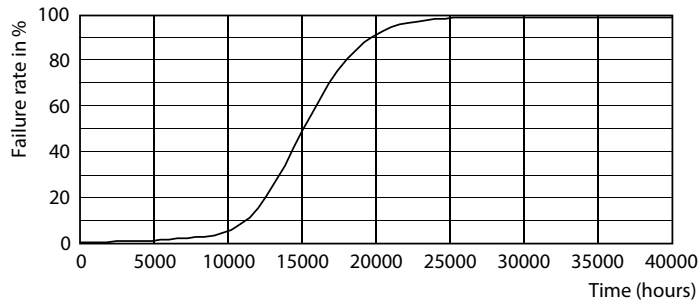

Life Expectancy Diagram

Lumen Maintenance Diagram

