


# Eaton XTCE009B10E

Catalog number: XTCE009B10E

Eaton XT IEC contactor, 9A, 208 Vac, 60 Hz, 1NO, 9A, Frame B, 45 mm, 60 Hz, 0.5, 1, 1.25/ 3, 3, 5, 7.5 hp (1/3PH @115, 200, 230/200, 230, 460, 575 V), Three-pole, Non-reversing, , Screw terminals, FVNR

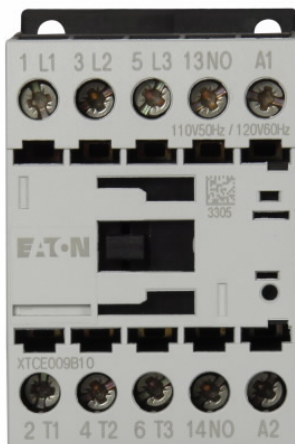

## General specifications

<b>Product Name</b>	<b>Catalog Number</b>
Eaton XT IEC contactor	XTCE009B10E
<b>EAN</b>	<b>Product Length/Depth</b>
4015082766849	4.92913386 in
<b>Product Height</b>	<b>Product Width</b>
2.67716535 in	1.77165354 in
<b>Product Weight</b>	<b>Compliances</b>
.5070632 lb	CE Marked RoHS Compliant
<b>Certifications</b>	<b>Catalog Notes</b>
UL Listed CSA Certified IEC 60947 EN 60947	Screw terminals (6-65A); 5 mm (80-150A); no lugs (185-2000A)

## defaultTaxonomyAttributeLabel

### Contact configuration

1 NO

### Coil voltage

208 Vac, 60 Hz

### Series

XT IEC

### Type

Full voltage non-reversing contactor

### HP rating - max

0.5, 1, 1.25/ 3, 3, 5, 7.5 hp (1/3PH  
@115,200,230/200,230,460,575 V)

### Continuous ampere rating

9 A

### Frequency rating

60 Hz

### Terminals

Screw terminals

### Operation

Non-reversing

### Amperage Rating

9A

### Number Of Poles

Three-pole

## Resources

### Catalogs

[Eaton's Volume 5—Motor Control and Protection](#)

### Drawings

[XTCE\\_B 3D Model Xchange](#)

[XTCE\\_B 2D Drawing Xchange](#)

[XTCE\\_B 2D PDF](#)

[XTCE\\_B 3D Inventor](#)

[XTCE\\_B AutoCAD 2D Footprint](#)

### Specifications and datasheets

[Global Data Sheet - XTCE009B10E](#)

[Eaton Specification Sheet - XTCE009B10E](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2022 Eaton  
All Rights Reserved

Eaton is a registered trademark.

All other trademarks are  
property of their respective  
owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)