


Eaton XTCE009B10A

Catalog number: XTCE009B10A

Eaton XT IEC contactor, 9A, 110 Vac 50 Hz, 120 Vac 60 Hz, 1NO, 9A, Frame B, 45 mm, 50-60 Hz, 0.5, 1, 1.25/ 3, 3, 5, 7.5 hp (1/3PH @115, 200, 230/200, 230, 460, 575 V), Three-pole, Screw terminals, Full voltage non-reversing contactor

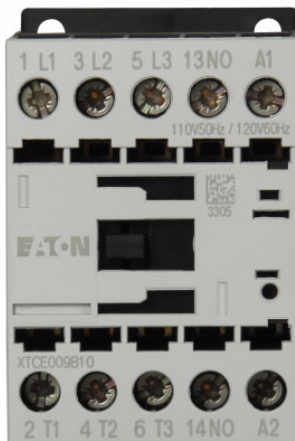

General specifications

Product Name	Catalog Number
Eaton XT IEC contactor	XTCE009B10A
UPC	EAN
786689005269	4015082766870
Product Height	Compliances
2 in	CE Marked RoHS Compliant
Certifications	Catalog Notes
UL Listed CSA Certified IEC 60947 EN 60947	Screw terminals (6-65A); 5 mm (80-150A); no lugs (185-2000A)

defaultTaxonomyAttributeLabel

Frame size

45 mm

Contact configuration

1 NO

Coil voltage

110-120 Vac, 50/60 Hz

Series

XT IEC

Type

Full voltage non-reversing contactor

HP rating - max

0.5, 1, 1.25/ 3, 3, 5, 7.5 hp (1/3PH
@115,200,230/200,230,460,575 V)

Continuous ampere rating

9 A

Frequency rating

50-60 Hz

Terminals

Screw terminals

Operation

Non-reversing

Amperage Rating

9A

Number Of Poles

Three-pole

Resources

Catalogs

[Eaton's Volume 5—Motor Control and Protection](#)

Drawings

[XTCE_B AutoCAD 2D Footprint](#)

[XTCE_B 3D Inventor](#)

[XTCE_B 2D Drawing Xchange](#)

[XTCE_B 3D Model Xchange](#)

[XTCE_B 2D PDF](#)

Specifications and datasheets

[Eaton Specification Sheet - XTCE009B10A](#)

[Global Data Sheet - XTCE009B10A](#)

Warranty guides

[Selling Policy 25-000 - Distribution and Control Products and Services](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2022 Eaton
All Rights Reserved

Eaton is a registered trademark.

All other trademarks are
property of their respective
owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)