


# Eaton XTCE009B10C

Catalog number: XTCE009B10C

Eaton XT IEC contactor, 9A, 415 Vac, 50 Hz, 480 Vac, 60 Hz, 1NO, 9A, Frame B, 45 mm, 50-60 Hz, 0.5, 1, 1.25/ 3, 3, 5, 7.5 hp (1/3PH @115, 200, 230/200, 230, 460, 575 V), Three-pole, Screw terminals, FVNR

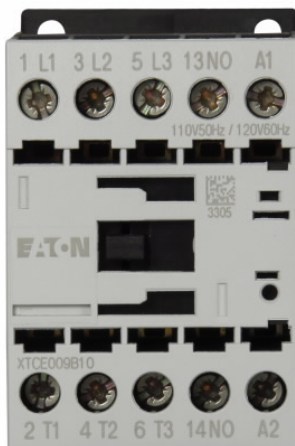

## General specifications

<b>Product Name</b>	<b>Catalog Number</b>
Eaton XT IEC contactor	XTCE009B10C
<b>EAN</b>	<b>Product Length/Depth</b>
4015082766931	3 in
<b>Product Height</b>	<b>Product Width</b>
2 in	3 in
<b>Product Weight</b>	<b>Compliances</b>
.5070632 lb	CE Marked RoHS Compliant
<b>Certifications</b>	<b>Catalog Notes</b>
UL Listed CSA Certified IEC 60947 EN 60947	Screw terminals (6-65A); 5 mm (80-150A); no lugs (185-2000A)

## defaultTaxonomyAttributeLabel

### Frame size

45 mm

### Contact configuration

1 NO

### Coil voltage

415-480 Vac, 50/60 Hz

### Series

XT IEC

### Type

Full voltage non-reversing contactor

### HP rating - max

0.5, 1, 1.25/ 3, 3, 5, 7.5 hp (1/3PH  
@ 115,200,230/200,230,460,575 V)

### Continuous ampere rating

9 A

### Frequency rating

50-60 Hz

### Terminals

Screw terminals

### Operation

Non-reversing

### Amperage Rating

9A

### Number Of Poles

Three-pole

## Resources

### Catalogs

[Eaton's Volume 5—Motor Control and Protection](#)

### Drawings

[XTCE\\_B 3D Model Xchange](#)

[XTCE\\_B 3D Inventor](#)

[XTCE\\_B 2D Drawing Xchange](#)

[XTCE\\_B 2D PDF](#)

[XTCE\\_B AutoCAD 2D Footprint](#)

### Specifications and datasheets

[Eaton Specification Sheet - XTCE009B10C](#)

[Global Data Sheet - XTCE009B10C](#)

### Warranty guides

[Selling Policy 25-000 - Distribution and Control Products and Services](#)