


Eaton XTCE032C10B

Catalog number: XTCE032C10B

Eaton XT IEC contactor, 32A, 220 Vac 50 Hz, 240 Vac 60 Hz, 1NO, 32A, Frame C, 45 mm, 50-60 Hz, 3, 5, 5/ 10, 10, 20, 25 hp (1/3PH @115, 200, 230/200, 230, 460, 575 V), Three-pole, , Screw terminals, FVNR

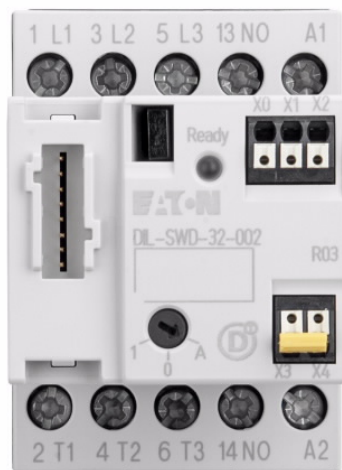

General specifications

Product Name

Eaton XT IEC contactor

Catalog Number

XTCE032C10B

EAN

4015082772598

Product Length/Depth

4 in

Product Height

2 in

Product Width

3.5 in

Product Weight

.5 lb

Compliances

CE Marked RoHS Compliant

Certifications

UL Listed CSA Certified IEC 60947 EN 60947

Catalog Notes

Screw terminals (6-65A); 5 mm (80-150A); no lugs (185-2000A)

defaultTaxonomyAttributeLabel

Frame size

45 mm

Contact configuration

1 NO

Coil voltage

220-240 Vac, 50/60 Hz

Series

XT IEC

Type

Full voltage non-reversing contactor

HP rating - max

3, 5, 5/ 10, 10, 20, 25 hp (1/3PH
@ 115,200,230/200,230,460,575 V)

Continuous ampere rating

32 A

Frequency rating

50-60 Hz

Terminals

Screw terminals

Operation

Non-reversing

Amperage Rating

32A

Number Of Poles

Three-pole

Resources

Catalogs

[Eaton's Volume 5—Motor Control and Protection](#)

Drawings

[XTCE_C 3D Model Xchange](#)

[XTCE_C 2D PDF](#)

[XTCE_C 2D Drawing Xchange](#)

[XTCE_C AutoCAD 2D Footprint](#)

Specifications and datasheets

[Global Data Sheet - XTCE032C10B](#)

[Eaton Specification Sheet - XTCE032C10B](#)