

Discover the power of smart lighting



Dimmer




Remote



Fan remote



Sensor

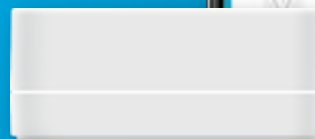

Smart Bridge



Lutron App

Why choose Caséta?

Introduction

Caséta is an easy way to give your customers a smart home. Install Caséta, and a homeowner can control his lights from anywhere, home or away, with a touch, his voice, or with features that do it automatically.

We’ve put together six different Caséta kits specifically for you, with everything you need to get started in a space. Then you can add on whenever your customer is ready to expand his smart home.

Caséta Kits

Switch & Remote Kit	2
3-Way Dimmer Kit with Remote	4
Lamp Dimmer & Remote Kit	6
Smart Switch Starter Kit	8
Dimmer Kit with Smart Bridge	10
Smart Lamp Timer Kit	12
Dimmers	14
Switches	16
Plug-in Lamp Dimmer Kit	17
Fan Control.	18
Pico Remotes.	19
Wireless Sensor	23
Smart Bridge	24
Repeater	25
Lutron App	26
Shades.	27
Thermostats and Ceiling Fans	28
Smart Home Technology	29
Ordering Information.	31

Switch & Remote Kit




Homeowner benefits

- Eliminates the hassle of fumbling around in the dark, trying to find the light switch, for a safe entry
- Add a switch anywhere (perfect if the current switch isn't where the homeowner wants it)
- Add a Smart Bridge anytime, for smart home functionality

Ideal for garages, hallways, and kitchens



P-PKG1WS-WH-C
List price \$110
\$140.40 if purchased individually
Your savings 21%

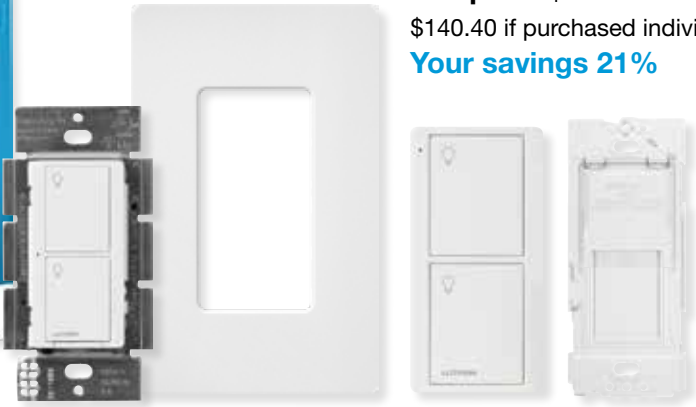

Add a point of control anywhere

- No more pulling wire — mount the Pico remote almost anywhere
- Mount the Pico flat on a wall or over an existing wallbox
- Each Pico can control multiple switches (Caséta has a device limit of 75)
- Pair each switch with up to 10 Pico remotes

Features to sell around

- Pico remotes have a 10-year battery life
- No need to cut a hole in a wall in order to mount a Pico

Potential add-ons

- Caséta smart motion sensor
- Additional Pico remotes for greater control
- A Smart Bridge for more functionality/system expansion

3-Way Dimmer Kit with Remote



Homeowner benefits

- Eliminates the hassle of fumbling around in the dark, trying to find the light switch, for a safe entry
- Add a switch anywhere (perfect if the current switch isn't where the homeowner wants it)
- Add a Smart Bridge anytime, for smart home functionality

Ideal for hallways, family rooms, and kitchens



P-DIM-3WAY-WH-C
List price \$113
\$134.00 if purchased individually
Your savings 15%



Add a point of control anywhere

- No more pulling wire — mount the Pico remote almost anywhere
- Mount the Pico flat on a wall or over an existing wallbox
- Each Pico can control multiple switches; pair each switch with up to 10 Pico remotes

Features to sell around

- Pico remotes have a 10-year battery life
- You can add a point of control in 15 minutes
- No neutral required — ideal for older homes

Potential add-ons

- Caséta smart motion sensor
- Additional Pico remotes for greater control
- A Smart Bridge for more functionality/system expansion

Lamp Dimmer & Remote Kit



Homeowner benefits

- Adjust lights on either side of the bed
- No need to put a voice control device in your bedroom to control the lights
- Conveniently control multiple lamps in a room with one remote

Ideal for bedrooms, living rooms, studies, and home offices



P-PKG1P-WH-C
List price \$88
\$107.50 if purchased individually
Your savings 18%



Easily add dimming control

- Just plug dimmer into a standard outlet
- Connect up to two lamps per plug-in (both will be controlled together)

Features to sell around

- Pico remotes have a 10-year battery life
- You can add a point of control in 15 minutes

Potential add-ons

- Tabletop pedestal
- Additional Pico remotes for greater control

Smart Switch Starter Kit



Homeowner benefits

- Always come back to a well-lit home
- Easily check which lights are on or off, using the Lutron App
- Add even more convenience by integrating with Siri, Alexa, or the Google Assistant
- Have outdoor lights scheduled to automatically turn on at dusk and off at sunrise

Take advantage of the geofencing feature to turn lights when you come home

Ideal for outdoor lighting



P-BDG-PKG1WS-C
List price \$165
\$240.30 if purchased individually
Your savings 31%



The Smart Bridge connects to the Wi-Fi router via the Ethernet connection. Setup is easy — follow the step by step instructions in the Lutron App.



Hassle-free scheduling

- Schedule outdoor light changes by sunrise/sunset or time of day
- No need to come back and adjust the schedule for daylight saving time

Features to sell around

- Once you add the Smart Bridge, it's easy to add additional devices to the system
- Can integrate with the homeowner's favorite voice assistant
- The Smart Bridge doesn't depend on the home's Wi-Fi (if the Wi-Fi goes down, Caseta still works)

Potential add-ons

- Additional switches or dimmers throughout the home
- Pico remotes for additional points of control

You could also set up Smart Away, geofencing, and other app features, for added value for the homeowner

Dimmer Kit with Smart Bridge

Homeowner benefits

- Create the right light for any occasion
- Easily check which lights are on or off, using the Lutron App
- Add even more convenience by integrating with Siri, Alexa, or the Google Assistant

Ideal for the kitchen and living, family, and dining rooms



P-BDG-PKG1W-C
List price \$176
\$262.80 if purchased individually
Your savings 33%



The Smart Bridge connects to the Wi-Fi router via the Ethernet connection. Setup is easy — follow the step by step instructions in the Lutron App.



Add more smarts — without stress

- Easily add on to projects when you're adding retrofit light kits
- Simply plug the Smart Bridge into the router, download the Lutron App, and follow the instructions
- No neutral required — ideal for older homes

Features to sell around

- Once you add the Smart Bridge, it's easy to add additional devices to the system
- Can integrate with the homeowner's favorite voice assistant
- The Smart Bridge doesn't depend on the home's Wi-Fi (if the Wi-Fi goes down, Caséta still works)
- Dim or brighten lights to create the perfect atmosphere for any activity

Potential add-ons

- Additional switches or dimmers throughout the home
- Pico remotes for additional points of control

Smart Lamp Timer Kit

Homeowner benefits

- Perfect for rooms with no overhead lighting
- Control lights with voice integration, the Lutron App, or a Pico remote

Ideal for living rooms and bedrooms



P-BDG-PKG1P-C
List price \$176
\$246.50 if purchased individually
Your savings 28%



The Smart Bridge connects to the Wi-Fi router via the Ethernet connection. Setup is easy — follow the step by step instructions in the Lutron App.

Easily add dimming control

- Just plug dimmer into a standard outlet
- Connect up to two lamps per plug-in (both will be controlled together)


Features to sell around

- Plug-in can control up to two lamps
- Pico remotes have a 10-year battery life

Potential add-ons

- Tabletop pedestal
- Pico remotes for greater control
- Additional dimmers and switches


Dimmers



Controls wall and ceiling lights

Caséta provides superior dimming for dimmable LEDs

- Easily adjust the low-end trim for flicker-free dimming.
- Mix different bulb types on the same circuit.
- UL Listed to dim 100s of LED light bulbs.
- Find the list at CasetaWireless.com/support.



Controls ELV, LED, and more.

Dimmer

- Doesn't require a neutral wire — ideal for retrofit or new construction
- No polarity for line or load wiring — mistake-proof wiring
- Works with compatible dimmable LEDs (up to 150W), halogen and incandescent bulbs (up to 600W)
- Use Pico remotes for additional dimmers in 3-way or multi-location dimming applications


Dimmer PRO

- Works with approved dimmable LEDs (up to 250W), halogen and incandescent bulbs (up to 1000W)
- Also works with MLV lighting (up to 1000VA)
- Compatible with Lutron LTE LED drivers, PHPM, and GRX-TVI interfaces
- Neutral wire optional (required for MLV and drivers/interfaces)
- Use Pico remotes or existing toggle switches in 3-way or multi-location applications
- **Only available to the Pros. Not yet a PRO? Sign up at lutron.com/PRO.**

Dimmer ELV+

- Works with all load types — dimmer is phase selective
- Favorite button for preset level on dimmer (matches Pico remote)
- 500W ELV/HAL/INC
- 400W MLV
- 250W LED
- Neutral wire required
- 10W minimum load
- Use Pico remotes for additional dimmers in 3-way or multi-location dimming applications

Switches

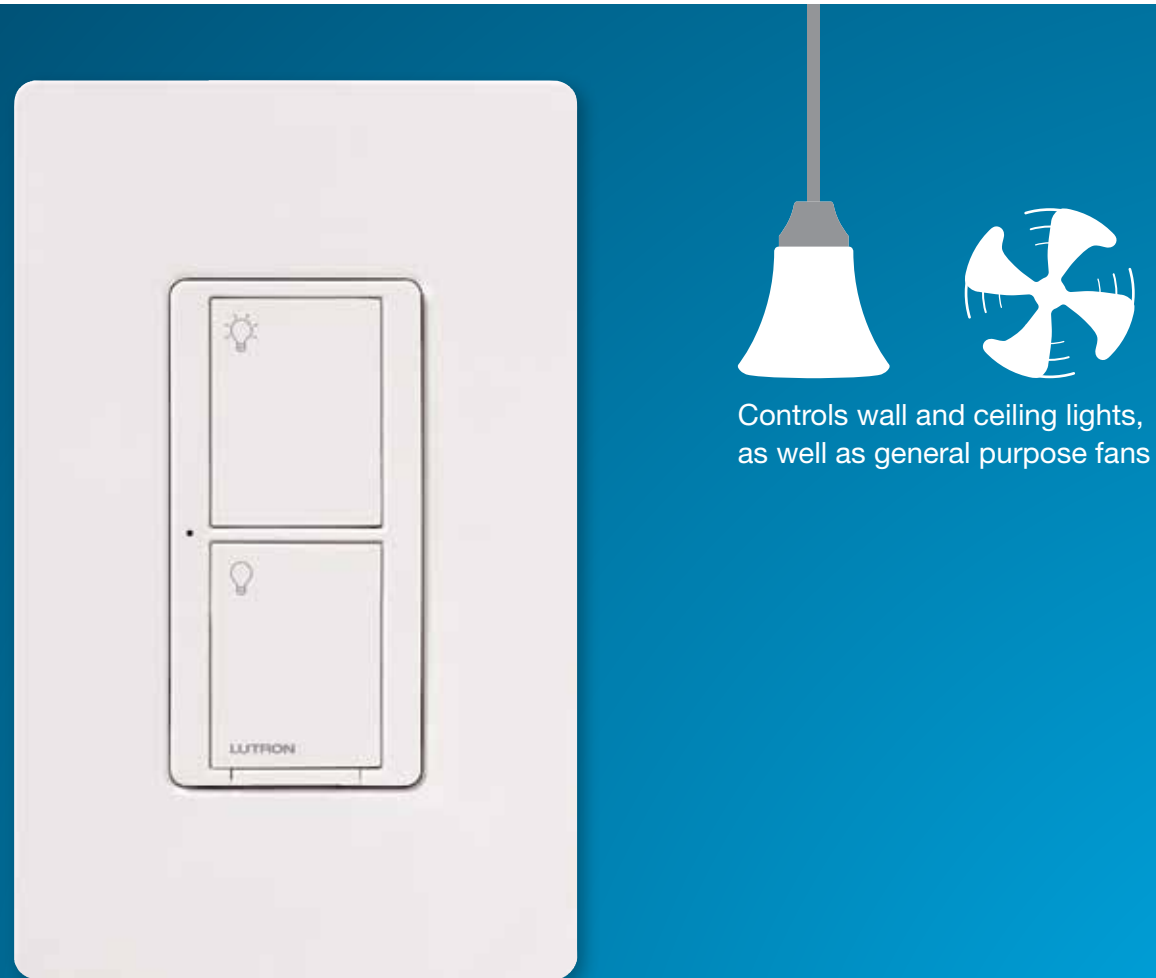

Neutral switch

- Neutral wire required — provides higher capacity and 10W minimum load or one LED bulb
- Use Pico remotes or existing toggle switches in 3-way or multi-location switching applications
- Controls 6A lighting load (LED, HAL, INC, CFL) or 3.6A fan load
- 5A model also available

Switch PRO

- Dual voltage — works in 120V and 277V applications
- Doesn't require a neutral wire
- Minimum load cap included (for switching LED, CFL, and ELV loads)
- Use Pico remotes or existing toggle switches in 3-way or multi-location switching applications
- **Only available to the Pros. Not yet a PRO? Sign up at lutron.com/PRO.**


Plug-in lamp dimmer



Plug-in lamp dimmer

- Features two receptacles for simultaneous control of two lamps
- Simply plugs into a standard wall receptacle
- Works with dimmable LEDs (up to 100W)
- Also works with halogen and incandescent bulbs (up to 300W)
- First lamp dimmer added to Smart Bridge acts as a Clear Connect range extender — provides 30 ft. of additional range (limit one per system)

Fan control

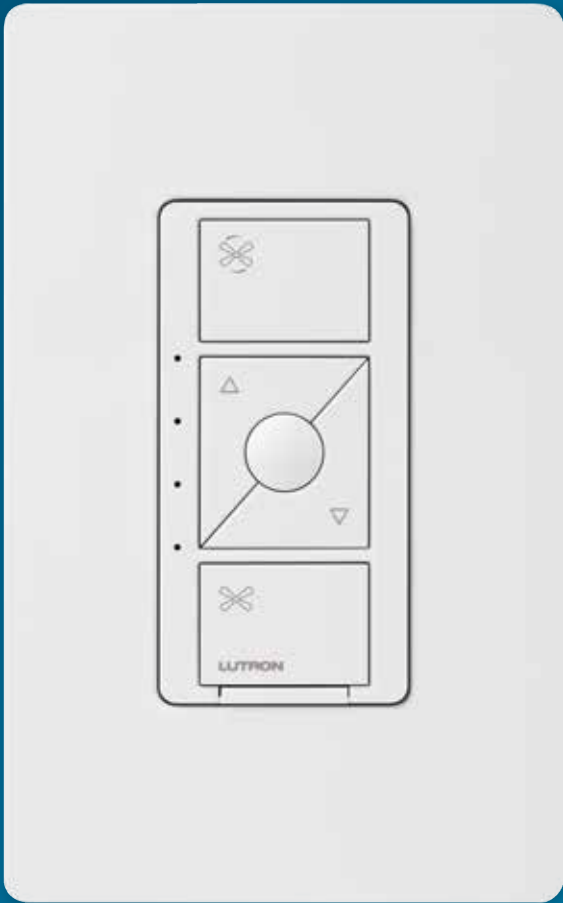

Controls ceiling fans

Fan speed control

- Neutral wire required — can control one AC ceiling fan
- Use Pico fan remotes in 3-way or multi-location control applications
- 4 speed fan control and off
- Favorite button to recall preferred fan speed setting

Pico remotes



Mount a Pico to a tabletop pedestal, clip it to a car visor, or mount it to a wall.



Tabletop pedestal



Car visor clip



Wall-mounting kit

Promoting the Pico

Don't forget to emphasize the ease of adding 3-way control with a Pico. Make sure to stress to homeowners that you won't have to climb into their attic or other tight space to run wire and cut holes.

Pico remote control

- Provides convenient remote control
- Add a light switch without having to wire anything
- Battery powered — features a 10-year battery life
- Works with Caséta dimmers, switches, and wireless shades

Pico remotes



3-scene control



2-group switch control



Dimming control



Fan control



Audio control



4-button Pico remote control PRO

Choose from three options

- 3-scene control — create three different scenes, as well as turn all lights off
- 2-group switch control — control two groups of lights independently from one another
- Dimming control — same functionality (full on/off and raise/lower) as a standard Pico remote control, but in a 4-button aesthetic
- **Only available to the Pros. Not yet a PRO? Sign up at lutron.com/PRO.**

Note: light/shade and shade-only 4-button remotes also available

Visit lutron.com/pico for information on model numbers and engraving options


Pico fan remote control

- Provides convenient remote control
- Add an additional point of fan control without having to wire anything
- Battery powered — features a 10-year battery life
- Works with Caséta fan speed control

Pico remote control for audio

- Controls any model Sonos speaker(s) from anywhere around the home
- Play/pause, skip tracks, raise/lower volume, and select favorite playlists or stations
- Smart Bridge or Smart Bridge PRO required
- 10-year battery life


Pico remotes

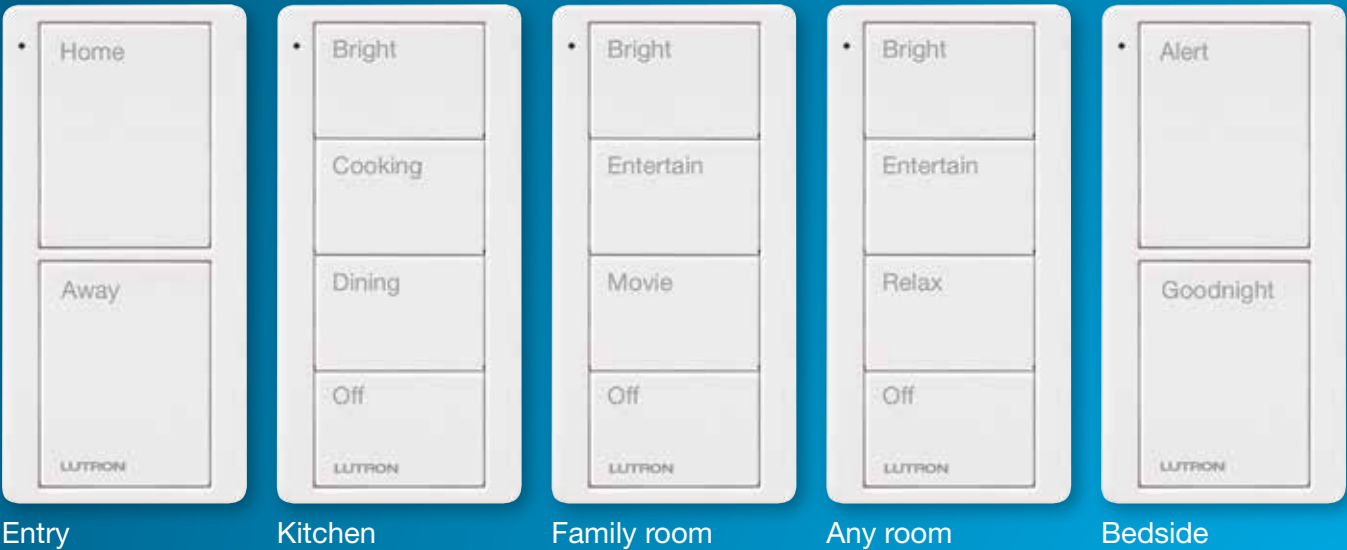

Pico scene keypad

- Provides access to scene control with the touch of a button
- Keypad automatically programs when added to room in app
- Each button is individually configurable for multiple lights and shades, as well as for audio
- Pre-engraved buttons for typical scenes/ activities
- 2- or 4-button options available
- **Only available to the Pros. Not yet a PRO? Sign up at lutron.com/PRO.**

Wireless sensor

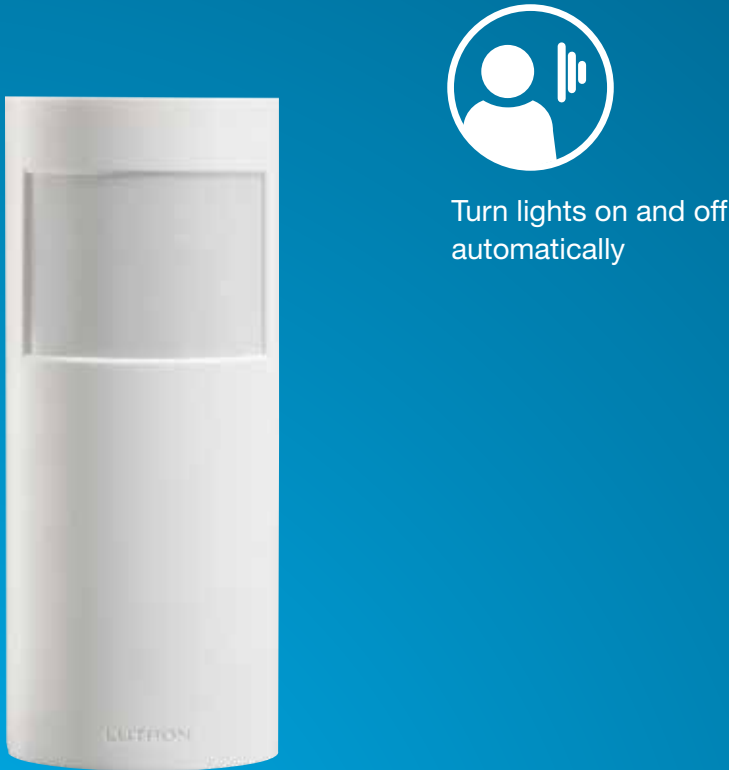

Wireless sensor

- Mount on a wall, corner, or a horizontal surface
- 180° field of view
- Ideal for hallways, closets, bathrooms, etc.
- Occupancy and vacancy versions are available
- Battery powered — features a 10-year battery life
- Can control one or many Caséta dimmers and switches

Smart Bridge



Smart Bridge

Get started in 3 simple steps

1 Connect the Ethernet cable and power cord to the Smart Bridge



2 Download the FREE Lutron App



3 Launch the app and walk through setup




Smart Bridge

- Enables control of lights, shades, and temperature using the Lutron App
- Compatible with Caséta dimmers and switches, Serena shades, Honeywell Wi-Fi Thermostats, Sonos speakers, and the major voice assistants (Amazon Alexa, Google Assistant, and Siri)
- Easy to install; just plugs into a Wi-Fi router
- Uses Clear Connect wireless technology — no customer callbacks


Smart Bridge PRO

- Also compatible with Lutron Triathlon battery-powered shades and select styles of Sivoia QS Wireless shades
- Adds integration with third-party A/V remote controls and security systems
- **Only available to the Pros. Not yet a PRO? Sign up at lutron.com/PRO.**

Repeater



Repeater

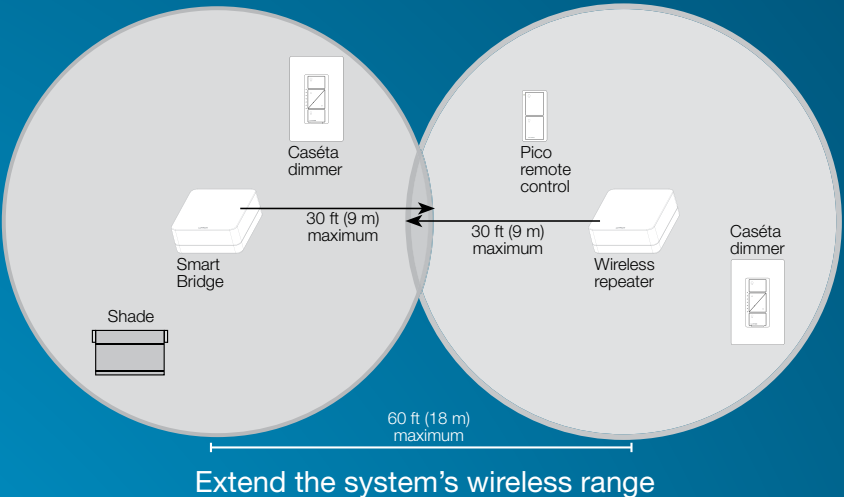


Extend the system's wireless range

Repeater

- Extend the system range up to 60ft
- Repeater must be within 60ft of the Smart Bridge
- Only one repeater per Smart Bridge (needs to be within range of the bridge)
- Plug it in anywhere, does not require an Ethernet connection

Lutron App

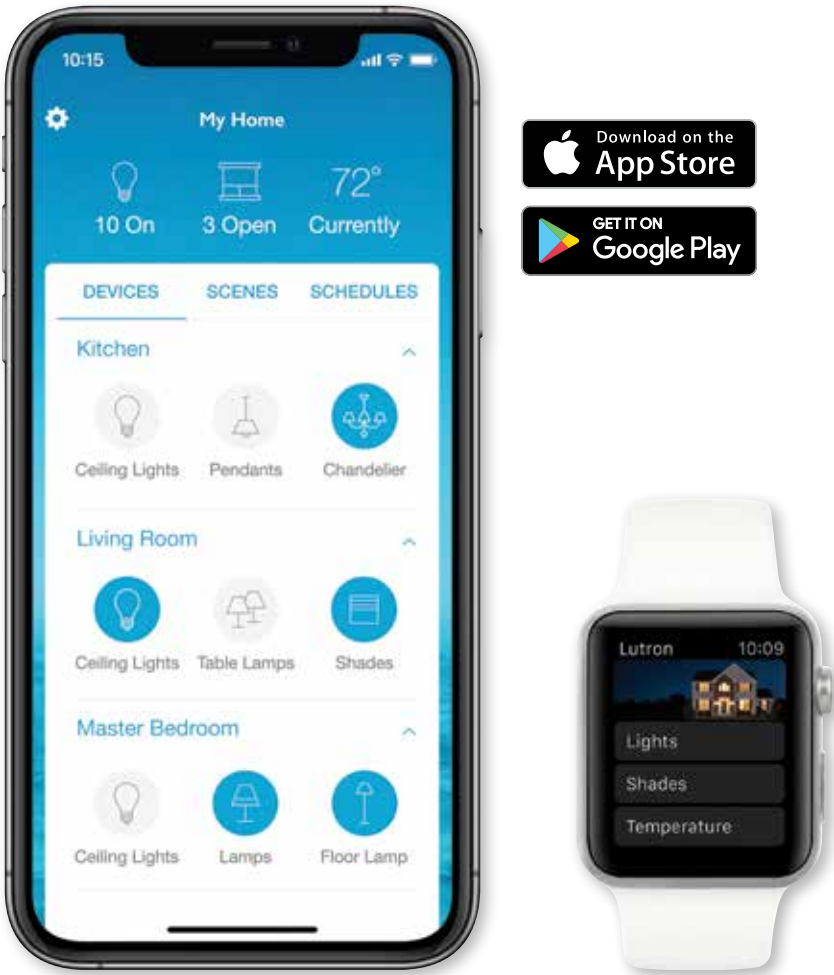

Lutron App

- Control individual lights, shades, thermostats, and speakers — even when away from home
- Intuitive interface makes adding and scheduling scenes to adjust lights and shades easy
- Set up the system in contractor mode — bypass the homeowner registration process and quickly configure the system
- Homeowners can:
 - receive notifications on their smart device if they've left lights on when they leave home
 - use the geofencing feature to automatically turn lights on as they arrive home/turn them off as they leave
 - create a lived-in look with the “Smart Away” feature, which allows them to pick several lights that will randomly turn on/off in the evening when they're away.

Shades

Caséta expands beyond lighting control. It works with other connected home solutions, such as shades, thermostats, ceiling fans, and even other manufacturer's apps.

Shading solutions

Eliminate glare, create privacy, and help keep a room cool, all with one touch.




Roller



Honeycomb

Lutron automated shades

- Battery-powered; batteries last 3–5 years
- Wireless, easy to install
- Cordless design
- Available in roller or insulating honeycomb styles
- Additional styles compatible with the Smart Bridge PRO (Triathlon shades and select styles of Sivoia QS Wireless shades)

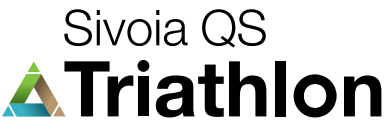

Thermostats and Ceiling Fans

View the full list of integration partners at CasetaWireless.com/integration.

Wireless thermostats

Control heating and cooling from anywhere using the Lutron App and a wide range of compatible thermostats.



(available from Lutron)

Lutron-Honeywell Wireless Thermostat

- Remotely control a home's temperature from the Lutron App
- 7-day programmable schedule
- Large touchscreen display with backlight
- Precise comfort control of temperature and humidity
- The Lutron App is also compatible with the following:



HomeKit-enabled ceiling fans

Conveniently adjust ceiling fans from the Lutron App or by using Siri. Turn them on and off, and change speeds. And if the fan has a light attached to it, homeowners can even adjust that, too — right from their phone.



Hunter Symphony and Signal ceiling fans

- 54" ceiling fans with either plastic (Symphony) or wooden (Signal and Apache) blades
- Both fans include an integrated light kit
- Whisperwind motor delivers quiet, ultra-powerful air movement
- For additional product information visit hunterfan.com



Additional smart home technology












	Amazon Alexa Create just the right light using Alexa voice control. Ask Alexa to turn lights on, off, or dim them to your favorite level.
	Apple HomeKit The Smart Bridge contains Apple HomeKit technology, so you can use Siri to control your lights and shades.
	The Google Assistant Get the lights with just your voice. Smart lighting control is now available through any Google Assistant-enabled device.
	IFTTT (If This Then That) Create IFTTT recipes: a sequence of conditions that when triggered (If This) cause your Caséta system to turn on the lights or open the shades (Then That).
	Logitech Harmony Dim lights, lower shades, and start a movie with one button press on Logitech Harmony hub-based remote controls or from the Harmony app.
	Samsung SmartThings Control lights and shades from the Samsung SmartThings app, and create new routines to tie in other smart devices like locks, sensors, cameras, and more.
	Sonos Control your Sonos Home Sound System from a Pico remote control for audio or from scenes in the Lutron App. You can also control your lights using your voice via the Sonos One with Amazon Alexa & Google Assistant.
	XFINITY Home Control your lights from anywhere using the XFINITY Home app.

Ordering Information


 

 
 

 
Pro-level integration*

Security

Automatically turn off lights and close shades when arming the security system before leaving for the day. Turn lights on and open shades when disarming the system when arriving home or in the event of an alarm.

* Smart Bridge PRO required for pro-level integration

Product	Name	Model Number	Specifications/ Descriptions	Voltage	List Price
Dimmers and Switches					All prices in CAD
	Dimmer	PD-6WCL-XX-C*	Single pole / multi-location** 150 W dimmable LED 600 W HAL / INC 434 MHz	120V~ No polarity for line or load wiring	\$91.00
	Dimmer PRO	PD-10NXD-XX-C*	Single pole / multi-location** 250 W dimmable LED 1000 W HAL / INC 1000 VA MLV 434 MHz	120V~ Neutral optional	\$124.00
	Dimmer ELV+	PD-5NE-XX-C*	Single pole / multi-location** 500 W ELV / HAL / INC 400 W MLV 250 W dimmable LED 434 MHz	120V~ Neutral required	\$170.00
	Fan Speed Control	PD-FSQN-XX	Single pole / multi-location** 1.5 A single ceiling fan 434 MHz	120V~ Neutral required	\$101.00
	Neutral Switch	PD-6ANS-XX*	Single pole / multi-location** 720 W HAL / INC / ELV† 720 VA MLV 6 A LED / CFL† 3.6 A general purpose fan 434 MHz	120V~ Neutral required	\$99.00
	Neutral Switch	PD-5ANS-XX	600 W HAL / INC / ELV 600 VA MLV 5 A LED / CFL 3 A general purpose fan 434 MHz	120V~ Neutral required	\$95.00
	Switch PRO	PD-5WS-DV-XX*	Single pole / multi-location** 600 W HAL / INC / ELV† 600 VA MLV 5 A LED / CFL† 3 A general purpose fan 434 MHz	120/277V~ No neutral	\$112.00
	Lamp Dimmer	PD-3PCL-WH-C	Use with one or two lamps 100 W dimmable LED 300 W HAL / INC 434 MHz	120V~ Plugs into a standard receptacle	\$81.00






* XX denotes gloss color suffix (at right).

WH	IV	LA	BL
White	Ivory	Light Almond	Black

** For multi-location applications, replace additional switches with Pico remote controls using wallplate brackets.

† Switching ELV, LED, CFL requires minimum load cap LUT-MLC (included).



Ordering Information

Product	Name	Model Number	Specifications/Descriptions	Voltage	List Price
Pico Remote Controls					All prices in CAD
	Pico Remote Control	PJ2-3BRL-WH-L01R (White)	3-button with raise/lower and light icon engraving 434 MHz	3V=== 10mA**	\$26.50
		PJ2-3BRL-LA-L01R (Light Almond)	Additional Pico styles available. Please visit lutron.com/pico to view the full selection.		
	2-Button Pico Remote Control	PJ2-2B-GWH-L01 (White)	2-button with light icon engraving 434 MHz	3V=== 10mA**	\$28.90
		PJ2-2B-GBL-L01 (Black)	2-button with light icon engraving 434 MHz	3V=== 10mA**	\$63.90
	4-Button Pico Remote Control PRO	PJ2-4B-XX-L01P*	Dimming control 4-button with raise/lower and light icon engraving 434 MHz	3V=== 10mA**	\$28.50
		PJ2-4B-XX-L21P*	2-group switch control 4-button with dual group light icon engraving 434 MHz	3V=== 10mA**	\$44.50
		PJ2-4B-XX-L31P*	3-scene control 4-button with light icon scene engraving 434 MHz	3V=== 10mA**	\$44.50
	Pico Fan Speed Remote Control	PJ2-3BRL-GXX-F01*	3-button with raise/lower and fan icon engraving 434 MHz	3V=== 10mA**	\$48.00
	Pico Remote Control for Audio	PJ2-3BRL-GWH-A02 (White)	3-button with raise/lower and audio icon engraving 434 MHz	3V=== 10mA**	\$62.00
		PJ2-3BRL-GBL-A02 (Black)			

* XX denotes gloss color suffix (at right).

** Uses single CR 2032 battery (included).

WH	IV	LA	BL
White	Ivory	Light Almond	Black








Product	Name	Model Number	Specifications/Descriptions	Voltage	List Price
Pico Scene Keypad					All prices in CAD
	2-Button Pico Scene Keypad	PJ2-2B-GXX-P01*	2-button pre-engraved keypad with Home and Away scenes	3V=== 10mA**	\$71.00
		PJ2-2B-GXX-P02*	2-button pre-engraved keypad with Alert and Goodnight scenes	3V=== 10mA**	\$71.00
	4-Button Pico Scene Keypad	PJ2-4B-GXX-P01*	4-button pre-engraved keypad with Bright, Entertain, Movie, and Off scenes	3V=== 10mA**	\$71.00
		PJ2-4B-GXX-P02*	4-button pre-engraved keypad with Bright, Cooking, Dining and Off scenes	3V=== 10mA**	\$71.00
		PJ2-4B-GXX-P03*	4-button pre-engraved keypad with Bright, Entertain, Relax, and Off scenes	3V=== 10mA**	\$71.00

 * XX denotes gloss color suffix (at right).




 
 
** Uses single CR 2032 battery (included).

WH	IV	LA	BL
White	Ivory	Light Almond	Black

Ordering Information

 
 
 
 

 
 
Product	Name	Model Number	Specifications/Descriptions	Voltage	List Price
Pico Accessories					All prices in CAD
	Wallplate Bracket	PICO-WBX-ADAPT	Wallplate bracket allows for easy installation of a Pico remote/keypad over an existing wallbox or directly on any wall surface		\$10.20
	Car Visor Clip	PICO-CAR-CLIP	Provides an easy way to attach a Pico remote/keypad to your car's sun visor		\$11.50
	Tabletop Pedestals	L-PED1-WH	Single pedestal — White		\$17.10
		L-PED1-BL	Single pedestal — Black		\$28.90
		L-PED2-WH	Double pedestal — White		\$34.00
		L-PED2-BL	Double pedestal — Black		\$45.40
		L-PED3-WH	Triple pedestal — White		\$114.10
		L-PED3-BL	Triple pedestal — Black		\$114.10
Wireless sensors					All prices in CAD
	Wireless Sensor	PD-OSENS-WH	Wireless occupancy/vacancy sensor with wall- and corner- mount brackets 434MHZ	3V=== 14mA*	\$88.00
		PD-VSENS-WH	Wireless vacancy only sensor with wall- and corner- mount brackets 434MHZ	3V=== 14mA*	\$88.00

** Uses single CR 123 battery (included).

Product	Name	Model Number	Specifications/Descriptions	Voltage	List Price
Smart Bridge and Smart Bridge PRO					All prices in CAD
	Smart Bridge with HomeKit technology	L-BDG2-WH-C	Smart Bridge allows control via the Lutron App and integration with leading smart home brands	120V~ 5V=== 300mA (power supply included)	\$139.00
	Smart Bridge PRO with HomeKit technology	L-BDGPRO2-WH-C	Smart Bridge PRO allows third-party pro level integration, control via the Lutron App and integration with leading smart home brands	120V~ 5V=== 300mA (power supply included)	\$189.00
Repeater					All prices in CAD
	Repeater	PD-REP-WH	Extends wireless range up to 60'	5V=== 100mA (power supply included)	\$125.00
Thermostat					All prices in CAD
	Lutron-Honeywell Wireless Thermostat	L-HWLV2-WIFI	Up to 3 heat /2 cool heat pump or up to 2 heat /2 cool conventional Requires common wire connection	24V~	\$415.00
Automated Shades					
	Please visit lutron.com/triathlon				

Ordering Information

Notes:

Product	Name	Model Number	Specifications/ Descriptions	List Price
Kits				All prices in CAD
	1 Switch 1 Pico Remote 1 Wallplate Bracket 1 Wallplate	P-PKG1WS-WH-C	(1) PD-5ANS-WH (1) PJ2-2B-WH-L01 (1) PICO-WBX-ADAPT (1) CW-1-WH	\$110.00
	1 Dimmer 1 Pico Remote 1 Wallplate Bracket 1 Wallplate	P-DIM-3WAY-WH-C	(1) PD-6WCL-WH (1) PJ2-3BRL-WH-L01 (1) PICO-WBX-ADAPT (1) CW-1-WH	\$113.00
	Lamp Dimmer 1 Pico Remote	P-PKG1P-WH-C	(1) PD-3PCL-WH (1) PJ2-3BRL-WH-L01R	\$88.00
	1 Switch 1 Wallplate 1 Smart Bridge	P-BDG-PKG1WS-C	(1) PD-5ANS-WH (1) CW-1-WH (1) L-BDG2-WH	\$165.00
	1 Dimmer 1 Pico Remote 1 Wallplate 1 Smart Bridge	P-BDG-PKG1W-C	(1) PD-6WCL-WH (1) PJ2-3BRL-WH-L01 (1) CW-1-WH (1) L-BDG2-WH	\$176.00
	1 Lamp Dimmer 1 Pico Remote 1 Smart Bridge	P-BDG-PKG1P-C	(1) PD-3PCL-WH (1) PJ2-3BRL-WH-L01R (1) L-BDG2-WH	\$176.00
PRO Kits				All prices in CAD
	1 Smart Bridge PRO 1 Pico Remote 1 Dimmer 1 Wallplate	P-BDGPRO-PKG1W-C (White only)	(1) L-BDGPRO2-WH (1) PD-6WCL-WH (1) PJ2-3BRL-WH-L01R (1) CW-1-WH (Claro wallplate)	\$251.00
	1 Smart Bridge PRO 3 Pico Remotes for Audio 2 Pedestals 1 Wallplate Bracket 1 Wallplate	P-BDGPRO-PKG3AWC (White only)	(1) L-BDGPRO2-WH (3) PJ2-3BRL-GWH-A02 (2) L-PED1-WH (1) PICO-WBX-ADAPT (1) CW-1-WH (Claro wallplate)	\$430.00

[illegible]



The Lutron logo, Lutron, the Caséta logo, Caséta, Claro, Clear Connect, Pico, Serena, Sivoia QS, and Triathlon are trademarks or registered trademarks of Lutron Electronics Co., Inc., in the U.S. and other countries.

All other product names, logos, and brands are property of their respective owners.

CasetaWireless.com

Lutron Electronics Co., Inc., 7200 Suter Road, Coopersburg, PA 18036-1299

Customer Assistance

Online: lutron.com/help | Email: support@lutron.com | Phone: 1.844.LUTRON1 (588.7661) — includes 24/7 technical support

© 09/2020 Lutron Electronics Co., Inc. | P/N 367-2499/CA REV Q

