

OVERVIEW

Utilizing pre-terminated CAT-5e cables is a great way to reduce labor costs. These CAT-5e patch cables are pre-terminated with RJ45 style connectors on both ends. All cables are plenum rated and conform to the T568B pin-pair specification. The RJ-45 terminations are unbooted (i.e. no molded strain relief) which allows for easier connection to nLight devices. Cables are available in several lengths for convenience. All cables are white (with the exception of red isolation cables) and labeled "Acuity Brands Controls".

SPECIFICATIONS

- 350MHz
- 4 Pair 24 AWG Wire (Solid)
- ROHS Complaint
- TIA/EIA-568-B.2 Wired
- ETL
- FT6 and CMP Plenum Rated

Red CAT5 Isolation Cables only communicate, they do not provide bus power.

Note: Maximum cable length per zone is 1500 feet.

Warranty

Five-year limited warranty. Complete warranty terms located at: www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx


Note: Actual performance may differ as a result of end-user environment and application. Specifications subject to change without notice



nLight®

CAT5

Preterminated Cable

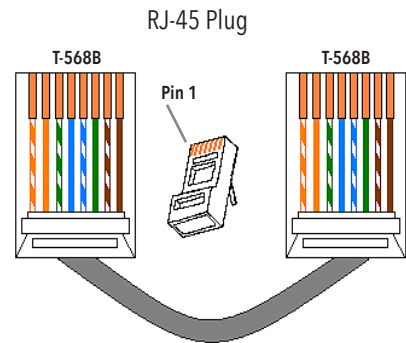

ORDERING INFORMATION

CAT5		Example: CAT5 5FT J1						
Cable	Lengths						Packaging	
CAT5 CAT5 cable	6IN	6 inch	20FT	20 foot	100FT	100 foot	J1 Job pack of one	
	1FT	1 foot	25FT	25 foot	150FT	150 foot		
	2FT	2 foot	30FT	30 foot	200FT	200 foot		
	5FT	5 foot	35FT	35 foot	250FT	250 foot		
	8FT	8 foot	40FT	40 foot	300FT	300 foot		
	10FT	10 foot	50FT	50 foot				
	15FT	15 foot	75FT	75 foot				

ACCESSORIES	
CAT5 Y J1	All Female 3-RJ45 Port Y Splitter
CAT5 1FT Y J1	1FT Cable with 1 Male to 2 Female Y Splitter
CAT5 CPLR J1	1 Female to 1 Female Coupler
CAT5 ISO J1	6 in Isolation Cable & 1 Female to 2 Female Splitter
CAT5 ISO EZ J1	6 in Isolation Cable & 1 Female to 1 Female Coupler