



# LEDBar™



# LIGHT UP

## WITH LEDBAR

### FEATURES

EXPANDABLE: Maximum link of 10 fixtures

120V



DIMMABLE



WITH ON/OFF  
SWITCH



UV FREE



25,000  
LIFE HOURS



### 6 LENGTH OPTIONS

9" 229mm 3W	13-1/2" 344mm 5W	22-5/8" 575mm 9W	34-1/2" 876mm 14W	46-1/4" 1175mm 18W	58" 1473mm 22W
-------------------	------------------------	------------------------	-------------------------	--------------------------	----------------------

### COLOR TEMPERATURE OPTIONS



2700 K Soft White



3000 K Warm White



4000 K Cool White



5000 K Daylight



### 2700 K SOFT WHITE

LEDBAR9-27K-90	9", 3W, 2700 K, 150 Lumens
LEDBAR14-27K-90	13-1/2", 5W, 2700 K, 250 Lumens
LEDBAR23-27K-90	22-5/8", 9W, 2700 K, 550 Lumens
LEDBAR34-27K-90	34-1/2", 14W, 2700 K, 850 Lumens
LEDBAR34-27K-90N	34-1/2", 14W, 2700 K, 850 Lumens
LEDBAR46-27K-90	46-1/4", 18W, 2700 K, 1000 Lumens
LEDBAR58-27K-90	58", 22W, 2700 K, 1200 Lumens



### 4000 K COOL WHITE

LEDBAR9-40K	9", 3W, 4000 K, 250 Lumens
LEDBAR14-40K	13-1/2", 5W, 4000 K, 400 Lumens
LEDBAR23-40K	22-5/8", 9W, 4000 K, 775 Lumens
LEDBAR34-40K	34-1/2", 14W, 4000 K, 1175 Lumens
LEDBAR46-40K	46-1/4", 18W, 4000 K, 1500 Lumens
LEDBAR58-40K	58", 22W, 4000 K, 1800 Lumens

### 3000 K WARM WHITE



LEDBAR9-30K	9", 3W, 3000 K, 250 Lumens
LEDBAR14-30K	13-1/2", 5W, 3000 K, 400 Lumens
LEDBAR23-30K	22-5/8", 9W, 3000 K, 775 Lumens
LEDBAR34-30K	34-1/2", 14W, 3000 K, 1175 Lumens
LEDBAR46-30K	46-1/4", 18W, 3000 K, 1500 Lumens
LEDBAR58-30K	58", 22W, 3000 K, 1800 Lumens

### 5000 K DAYLIGHT



LEDBAR9-50K	9", 3W, 5000 K, 250 Lumens
LEDBAR14-50K	13-1/2", 5W, 5000 K, 400 Lumens
LEDBAR23-50K	22-5/8", 9W, 5000 K, 775 Lumens
LEDBAR34-50K	34-1/2", 14W, 5000 K, 1175 Lumens
LEDBAR46-50K	46-1/4", 18W, 5000 K, 1500 Lumens
LEDBAR58-50K	58", 22W, 5000 K, 1800 Lumens


# LINK

## UP TO 10

## FIXTURES



ALFT902-WH-3

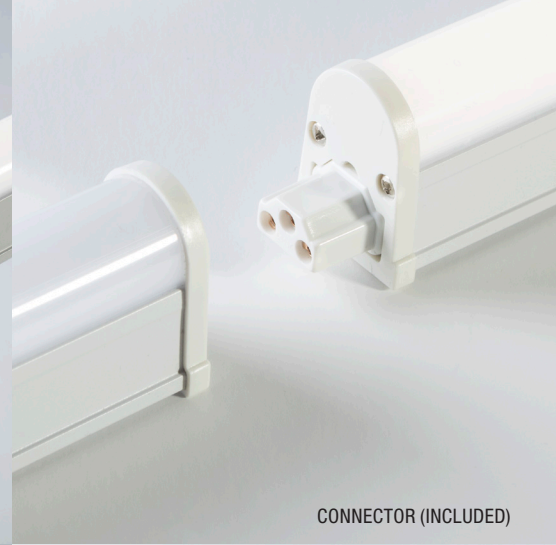

CONNECTOR (INCLUDED)



ALFT6300-WH



ALFT90-WH-3



CONNECTOR (INCLUDED)

### POWER CORD

<b>ALFT6000-WH-3</b>	6' Power cord
<b>ALFT6000S-WH-3</b>	6' Power cord with ON/OFF switch
<b>ALFT6016-WH-3</b>	16" Power cord
<b>FBT6124-BL-WH-3</b>	Power feed with bare lead

### FLEXIBLE CORD WITH 90° CONNECTOR

<b>ALFT90-WH-3</b>	Cord with 90° connectors (top connection)
<b>ALFT901-WH-3</b>	Cord with 90° connectors (left connection)
<b>ALFT902-WH-3</b>	Cord with 90° connectors (bottom connection)
<b>ALFT903-WH-3</b>	Cord with 90° connectors (right connection)
*6' Flexible 3-wire cord with 90° connectors	

### POWER CORD WITH 90° CONNECTOR

<b>ALFT60901-WH-3</b>	Power cord* with 90° connectors (top connection)
<b>ALFT60902-WH-3</b>	Power cord* with 90° connectors (left connection)
<b>ALFT60903-WH-3</b>	Power cord* with 90° connectors (bottom connection)
<b>ALFT60904-WH-3</b>	Power cord* with 90° connectors (right connection)
*6' Flexible 3-wire power cord with 90° connectors	

### FLEXIBLE CORD WITH STRAIGHT CONNECTOR

<b>FBT6106-WH-3</b>	6" Flexible connector
<b>FBT6100-WH-3</b>	12" Flexible connector
<b>FBT6124-WH-3</b>	24" Flexible connector
<b>FBT6136-WH-3</b>	36" Flexible connector

### MAG CLIPS

<b>LEDBAR-MAGCLIP-3</b>	Screwless magnetic mounting clips (3 pack)
-------------------------	--

### HARDWIRE BOX

<b>ALFT6300-WH</b>	Hardwire box with ON/OFF switch
<b>ALFT6300-OS-WH</b>	Hardwire box with ON/OFF motion sensor






## NO COMPROMISE CONNECTIONS

Thin, sleek and easy to install, the LEDBAR by Liteline is the ideal solution for your commercial or residential task lighting needs. With dependable features that include a durable extruded aluminum frame, you can be confident in product longevity. Suitable for dry locations, this product is an optimal choice for kitchen spaces amongst other similar applications. The built-in, non-flicker, electronic LED driver provides dimming capability with Triac, ELV and incandescent dimmers. The ability to hardwire this fixture is accompanied by the capability to link up to 10 fixtures with an added no shadow linking connector to maximize light output. With a built in on/off switch, a choice of 6 lengths and 4 color temperatures, LEDBAR gives you the perfect combination of design and functionality.

## ORDERING GUIDE

	Length	Color Temp.
<b>LEDBAR</b>	<input type="text"/>	<input type="text"/>
 <b>QUICKSHIP</b> <b>2-DAY</b>	9 : 9"	27-90 : 2700 K, 90CRI
	14 : 14"	30 : 3000 K
	23 : 23"	40 : 4000 K
	34 : 34"	50 : 5000 K
	46 : 46"	
	58 : 58"	

Highlighted option denotes QuickShip.



Liteline Corporation  
Copyright © 2019  
All rights reserved.

Telephone  
416.996.1856  
1.866.730.7704

Fax  
905.709.5255  
1.888.738.9736

[LITELINE.COM](http://LITELINE.COM)

M-LEDBAR-E  
REV 07.07.20