

ORDERING INFORMATION

Order code: 10002
 Description: F17T8/41K/8/RS/G13/STD ESV
 UPC: 69549100022
 Case quantity: 25




Nominal length : 24 in. (610 mm) Dia. : 1 in. (26 mm)


PERFORMANCE DATA

Shape: T8
 Base: G13 (Med Bipin)
 Starting method: Rapid Start (RS)
 Wattage (W): 17
 Colour temperature (K): 4 100
 CRI: 85
 Rated life on PS/PRS¹ ballast:
 Based on a 3 hour start 24 000
 Based on a 12 hour start 30 000
 Initial lumens (lm): 1 400
 Mean lumens (lm): 1 330
 Nominal efficiency (lm/W): 82
 TCLP compliant: Yes
 Phosphor composition: Triphosphor
 Nominal lamp operating frequency (Hz): 60
² Minimum starting temperature (°C): -10

DIMENSIONS

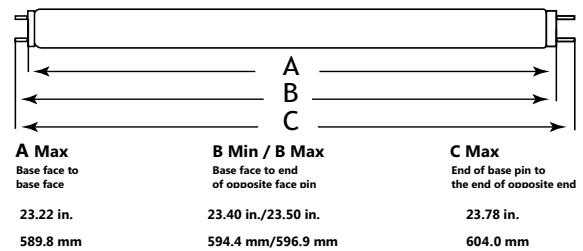

SPECTRAL DISTRIBUTION

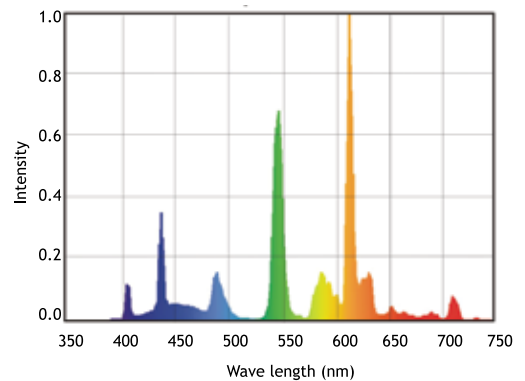

¹ The life rating indicated is based on 3 hour burning cycles under specified conditions and with ballast meeting ANSI specifications.

² The minimum starting temperature is a function of the ballast. The minimum starting temperature is based on a STANDARD brand T8 800 series ballast.

