

# Half-mirror



**A19**

MOL.: 4 1/4 in. (108 mm)  
LCL.: 3 1/8 in. (79 mm)



**A21**

MOL.: 5 5/16 in. (135 mm)  
LCL.: 3 17/32 in. (90 mm)



**G16.5**

MOL.: 2 7/8 in. (73 mm)  
LCL.: 1 7/8 in. (48 mm)



**G25**

MOL.: 4 1/2 in. (114 mm)  
LCL.: 3 1/32 in. (77 mm)



**G30**

MOL.: 5 5/16 in. (135 mm)  
LCL.: 3 5/8 in. (92 mm)




**G40**

MOL.: 5 13/32 in. (137 mm)  
LCL.: 3 9/32 in. (83 mm)


Order code	Description	Watts (W)	Base	Volts (V)	Lumen output (lm)	Average life (hrs)	Filament type	Color	Case qty (inner/master)
<b>A19</b>									
52170	40A19/SLV/3M/HM/130V/STD	40	E26	130	N/A	3 000	C-9	Silver	6/120
52019	60A19/SLV/3M/HM/130V/STD	60	E26	130	N/A	3 000	C-9	Silver	6/120
52020	100A19/SLV/3M/HM/130V/STD	100	E26	130	N/A	3 000	C-9	Silver	24/120
<b>A21</b>									
52051	100A21/SLV/3M/HM/130V/STD	100	E26	130	N/A	3 000	C-9	Silver	24/120
<b>G16.5</b>									
52159	25G16.5/SLV/3M/HM/E12/120V/STD	25	E12	120	N/A	3 000	C-7A	Silver	25/500
52160	40G16.5/SLV/3M/HM/E12/120V/STD	40	E12	120	N/A	3 000	C-7A	Silver	25/500
<b>G25</b>									
52058	25G25/SLV/3M/HM/130V/STD	25	E26	130	N/A	3 000	C-9	Silver	6/60
52054	60G25/SLV/3M/HM/130V/STD	60	E26	130	N/A	3 000	C-9	Silver	6/60
<b>G30</b>									
52163	40G30/SLV/3M/HM/130V/STD	40	E26	130	N/A	3 000	C-9	Silver	10/500
51160	60G30/SLV/3M/HM/130V/STD	60	E26	130	N/A	3 000	C-9	Silver	10/100
<b>G40</b>									
14502	60G40/SLV/2.5M/HM/130V	60	E26	130	N/A	2 500	C-9	Silver	6/24
14503	100G40/SLV/2.5M/HM/130V	100	E26	130	N/A	2 500	C-9	Silver	6/24

# Neodymium

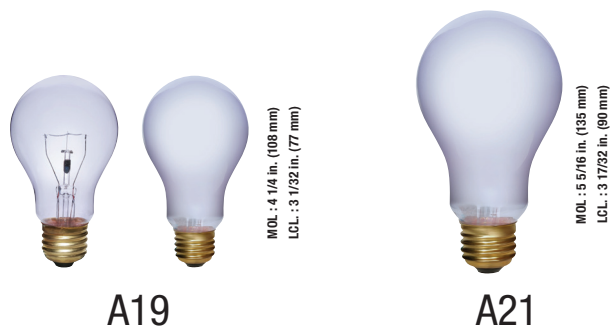

Order code	Description	Watts (W)	Base	Volts (V)	Lumen output (lm)	Average life (hrs)	Filament type	Finish	Case qty (inner/master)
<b>A19</b>									
50558 <sup>1</sup>	60A19/N/CL/2M/120V/STD	60	E26	120	750	2 000	CC-6	Clear	6/24
50559 <sup>1</sup>	60A19/N/F/2M/120V/STD	60	E26	120	740	2 000	CC-6	Frost	6/24
<b>A21</b>									
50560 <sup>1</sup>	100A21/N/CL/2M/120V/STD	100	E26	120	1 160	2 000	C-9	Frost	6/24
50955	50/150A21/F/N/5M/120V/STD	50/100/150	E26d	120	520/1 200/1 720	5 000	CC-8	Frost	6/24

# Krypton & Daylight

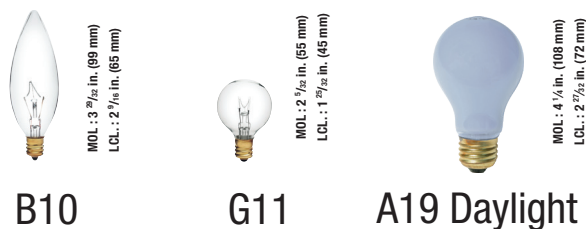

Order code	Description	Watts (W)	Base	Volts (V)	Lumens output <sup>2</sup> (lm)	Average life <sup>2</sup> (hrs)	Filament type	Finish	Case qty (inner/master)
<b>Krypton</b>									
<b>B10</b>									
14467	40B10/CL/3M/K/E12/120V	40	E12	120	450	3 000	C-7A	Clear	10/120
14468	60B10/CL/3M/K/E12/120V	60	E12	120	760	3 000	C-7A	Clear	10/120
<b>G11</b>									
14531	25G11/CL/3M/K/E12/120V	25	E12	120	300	3 000	CC-2V	Clear	10/120
<b>A19 Daylight</b>									
14638	25A19/DL/5M/130V/STD	25	E26	130	N/A	5 000	C-9	Daylight	24/120

<sup>1</sup> This product is no longer manufactured as per Energy Efficiency Regulations. Note that it will remain available until stock is depleted.

# Infrared & Appliance



MOL.: 6.9/16 in. (167 mm)  
LCL.: 4.1/4 in. (106 mm)

**BR40**



MOL.: 6.9/16 in. (167 mm)  
MOL.: 7.1/4 in. (184 mm)  
LCL.: 3.29/32 in. (99 mm)

**R40**



MOL.: 3.3/8 in. (86 mm)  
LCL.: 2.7/16 in. (62 mm)

**A15**

Order code	Description	Watts (W)	Base	Volts (V)	Lumen output (lm)	Average life (hrs)	Filament type	Finish	Case qty (inner/master)
<b>Infrared BR40</b>									
10249	125BR40/IR/CL/5M/120 130V/STD	125	E26	120	1 200	5 000	C-9	Clear	1/12
10251	250BR40/IR/CL/5M/120 130V/STD	250	E26	120	2 400	5 000	C-9	Clear	1/12
<b>R40</b>									
10250	125R40/IR/R/5M/ES/120 130V/STD	125	E26	120	N/A	5 000	C-9	Red	1/12
10252	250R40/IR/R/5M/120 130V/STD	250	E26	120	N/A	5 000	C-9	Red	1/12
62561	375R40/IR/CL/5M/120V/STD	375	E26	120	N/A	5 000	C11-3	Clear	1/12
<b>A15 Appliance (Up to 280°C / 535°F)</b>									
67721	40A15/CL/5M/APPL/130V/STD	40	E26	130	350	5 000	C-9	Clear	6/60
67722	40A15/FR/5M/APPL/130V/STD	40	E26	130	320	5 000	C-9	Frost	6/60

# Flashing, BLB & Bug



MOL.: 4.21/32 in. (116 mm)

**G25**



MOL.: 4.1/4 in. (108 mm)  
LCL.: 3.1/32 in. (77 mm)

**A19**



MOL.: 5 in. (127 mm)

**T10**



MOL.: 4.1/4 in. (108 mm)  
LCL.: 3.1/32 in. (77 mm)

**A19**



MOL.: 6.15/16 in. (176 mm)  
LCL.: 3.29/32 in. (99 mm)

**G40**

Order code	Description	Watts (W)	Base	Volts (V)	Lumen output (lm)	Average life (hrs)	Filament type	Finish/Color	Case qty (inner/master)
<b>Flashing</b>									
<b>G25</b>									
52203	XFLASH/CL/120V	1	E26	120	1 040	10 000 000 flashes	C-11V	Clear	1/50
52204	XFLASH/B/120V	1	E26	120	N/A	10 000 000 flashes	C-11V	Blue	1/50
52205	XFLASH/G/120V	1	E26	120	N/A	10 000 000 flashes	C-9	Green	1/50
52207	XFLASH/Y/120V	1	E26	120	N/A	10 000 000 flashes	C-9	Yellow	1/50
<b>Black light blue (BLB)</b>									
<b>A19</b>									
52016	75A19/BLB/1.5M/120V/STD	75	E26	120	N/A	1 500	C-9	Black light blue	6/120
<b>T10</b>									
14662	40T10/BLB/1M/120V	40	E26	120	N/A	1 000	C-8	Black light blue	25/300
<b>Bug light - 2 pack</b>									
<b>A19</b>									
50153	60A19/CY/6M/BG/130V/STD/2P	60	E26	130	N/A	6 000	C-9	Ceramic yellow	12/120
<b>G40</b>									
52056	60G40/CY/3M/BG/130V/STD	60	E26	130	N/A	3 000	C-9	Ceramic yellow	1/24

# Mining, Traffic & Plant



MOL: 6.9/16 in. (167 mm)  
LCL: 4 1/4 in. (108 mm)

R40



MOL: 4 1/4 in. (108 mm)  
LCL: 3 1/8 in. (79 mm)

A19



MOL: 5 5/16 in. (135 mm)  
LCL: 2 7/16 in. (62 mm)

A21



MOL: 5 1/8 in. (130 mm)  
LCL: 3 11/32 in. (85 mm)

BR30

Order code	Description	Watts (W)	Base	Volts (V)	Lumens at 120 V (lm)	Average life at 120 V (hrs)	Filament type	Finish	Case qty (inner/master)
<b>Mining Service</b>									
<b>R40</b>									
50482	300R40/FL/5M/MN/130V/STD	300	E26	130	2 271	5 000	CC-6	Clear	1/12
<b>Traffic Light</b>									
<b>A19</b>									
10863	60A19/CL/8M/TS/K/120 125V	125	E26	120	1 200	5 000	C-9	Clear	6/120
<b>A21</b>									
15554	40A21/CL/8M/TS/125 130V	40	E26	125	610	8 000	C-11V	Clear	1/120
<b>A21 - 2 pack</b>									
14620	67A21/CL/8M/TS/125 130V /2P	67	E26	125	610	8 000	C-9	Clear	1/60
10905	69A21/CL/8M/TS/125 130V /2P	69	E26	125	665	10 000	C-11V	Clear	1/120
<b>Plant Light</b>									
<b>BR30</b>									
50958	75R30/1.5M/PL/120V/STD	75	E26	120	N/A	1 500	C-9	Plant light	1/60

# Trilight



MOL: 5 5/16 in. (135 mm)  
LCL: 3 27/32 in. (98 mm)

A21



MOL: 6 15/16 in. (175 mm)  
LCL: 5 1/32 in. (128 mm)

PS25

Order code	Description	Watts (W)	Base	Volts (V)	Lumens at 120 V (lm)	Average life at 120 V (hrs)	Filament type	Finish	Case qty (inner/master)
<b>A21</b>									
10500	30/100A21/F/4M/130V/STD	30 / 70 / 100	E26d	130	210 / 605 / 815	4 000	CC-8	Frost	6/24
50152	30/100A21/WH/4M/130V/STD	30 / 70 / 100	E26d	130	175 / 575 / 750	4 000	CC-8	White	6/24
50117	50/150A21/WH/4M/130V/STD	50 / 100 / 150	E26d	130	395 / 910 / 1300	4 000	CC-8	White	6/24
10486	50/150A21/F/4M/130V/STD	50 / 100 / 150	E26d	130	440 / 1 045 / 1 485	4 000	CC-8	Frost	6/24
51159	50/250A21/WH/2M/120V/STD	50 / 200 / 250	E26d	120	400 / 2 200 / 2 600	2 000	CC-8	White	6/24
<b>PS25</b>									
51123	100/300/PS25/WH/E39/130V/STD	100 / 200 / 300	E39d	130	910 / 1 815 / 2 725	2 500	CC-6	White	6/24

# Long life



MOL: 4 1/4 in. (108 mm)  
LCL: 3 1/32 in. (77 mm)

**A19**



MOL: 5 5/16 in. (135 mm)  
LCL: 3 1/2 in. (89 mm)

**A21**



MOL: 4 1/2 in. (114 mm)  
LCL: 2 7/8 in. (73 mm)

**G25**



MOL: 6 15/16 in. (176 mm)  
LCL: 4 3/8 in. (111 mm)

**G40**



MOL: 3 29/32 in. (99 mm)  
LCL: 2 15/16 in. (75 mm)

**R20**



MOL: 3 1/2 in. (89 mm)  
LCL: 2 17/32 in. (64 mm)

**S14**

Order code	Description	Watts (W)	Base	Volts (V)	Lumen output (lm)	Average life (hrs)	Filament type	Finish	Case qty (inner/master)
<b>A19</b>									
51121	25A19/CL/20M/120V/STD	25	E26	120	105	20000	C-9/4	Clear	6/120
10160	25A19/F/20M/120V/STD	25	E26	120	105	20000	C-9/4	Frost	6/120
10161	40A19/CL/20M/120V/STD	40	E26	120	200	20000	C-9/4	Clear	6/24
10166 <sup>1</sup>	100A19/F/20M/120V/STD	100	E26	120	800	20000	C-9/5	Frost	6/24
<b>A21</b>									
10327 <sup>1</sup>	100A21/F/20M/120V/STD	100	E26	120	800	20000	C-9/5	Frost	6/24
<b>G25</b>									
14600	40G25/WH/20M/120V	40	E26	120	320	20000	C-11	White	1/60
<b>G40</b>									
14606	25G40/CL/20M/120V	25	E26	120	190	20000	C-11	Clear	1/24
<b>R20</b>									
10256 <sup>1</sup>	50R20/SP/20M/120V/STD	50	E26	120	400	20000	C-9/5	Clear	6/200
<b>S14</b>									
10259	10S14/CL/20M/120V/STD	10	E26	120	50	20000	C-9/5	Clear	6/24
14613	15S14/CL/20M/120V	15	E26	120	88	20000	C-11	Clear	1/120

<sup>1</sup> This product is no longer manufactured as per Energy Efficiency Regulations. Note that it will remain available until stock is depleted.

# Low Voltage



MOL.: 4 1/4 in. (108 mm)  
LCL.: 3 1/8 in. (78 mm)

**A19**



MOL.: 5 5/16 in. (135 mm)  
LCL.: 3 17/32 in. (90 mm)

**A21**



MOL.: 2 5/16 in. (69 mm)  
LCL.: 1 1/2 in. (38 mm)

**S11**



MOL.: 3 5/16 in. (84 mm)  
LCL.: 2 17/32 in. (64 mm)

**S14**



MOL.: 6 3/16 in. (157 mm)  
LCL.: 5 1/32 in. (128 mm)

**A23**

Order code	Description	Watts (W)	Base	Volts (V)	Lumen output (lm)	Average life (hrs)	Filament type	Finish/Color	Filament type	Case qty (inner/master)
<b>A19</b>										
52022	25A19/F/1.5M/12V/STD/6P	25	E26	12	220	1 500	C-6	Frost	C-6	6/120
52024	25A19/F/1.5M/24V/STD/6P	25	E26	24	220	1 500	C-6	Frost	C-6	6/120
52222	25A19/F/1.5M/32V/STD/6P	25	E26	32	220	1 500	C-6	Frost	C-6	6/120
52010	50A19/F/1.5M/12V/STD	50	E26	12	410	1 500	C-6	Frost	C-6	6/120
52011	50A19/F/1.5M/24V/STD	50	E26	24	410	1 500	C-6	Frost	C-6	6/120
52012	50A19/F/1.5M/32V/STD/6P	50	E26	32	410	1 500	C-6	Frost	C-6	6/120
59846	50A19/F/RS/1M/75V/STD	50	E26	75	500	1 000	C-9	Frost	C-9	6/120
52023	100A19/F/1.5M/12V/STD/6P	100	E26	12	1 385	1 500	C-6	Frost	C-6	6/120
52025	100A19/F/1.5M/24V/STD/6P	100	E26	24	1 385	1 500	C-6	Frost	C-6	6/120
52026	100A19/F/1.5M/32V/STD/6P	100	E26	32	1 385	1 500	C-6	Frost	C-6	6/120
52225	100A19/F/1.5M/34V/STD/6P	100	E26	34	1 385	1 500	C-6	Frost	C-6	6/120
<b>A21</b>										
50075	50A21/F/2M/47V/STD	50	E26	47	650	2 000	C-6	Frost	C-6	24/120
<b>S11</b>										
50790	15S11/CL/1M/BA15d/75V/STD	15	BA15d	75	140	1 000	C-7A	Clear	C-7A	25/500
50791	30S11/CL/BA15d/75V/STD	30	BA15d	75	280	1 000	C-7A	Clear	C-7A	25/500
<b>S14</b>										
52209	11S14/CL/1.5M/24V/STD	11	E26	24	74	1 500	C-6	Clear	C-6	25/500

# Rough Service



MOL.: 4 1/4 in. (108 mm)  
LCL.: 3 1/32 in. (77 mm)

**A19**



MOL.: 5 5/16 in. (135 mm)  
LCL.: 3 17/32 in. (90 mm)

**A21**



MOL.: 6 3/16 in. (157 mm)  
LCL.: 5 1/32 in. (128 mm)

**A23**

Order code	Description	Watts (W)	Base	Volts (V)	Lumen output (lm)	Average life (hrs)	Filament type	Finish	Case qty (inner/master)
<b>A19 - 2 pack</b>									
61799	50A19/F/RS/130V/STD/2P	50	E26	130	360	5 000	C-7A	Frost	1/120
61800	60A19/F/RS/130V/STD/2P	60	E26	130	520	5 000	C-7A	Frost	1/120
61801	75A19/F/RS/130V/STD/2P	75	E26	130	680	5 000	C-7A	Frost	1/120
61802	100A19/F/RS/130V/STD/2P	100	E26	130	1 050	5 000	C-7A	Frost	1/120
<b>A21</b>									
52134	100A21/F/RS/130V/STD	100	E26	130	1 050	5 000	C-7A	Frost	6/60
50073	150A21/F/RS/130V/STD	150	E26	130	1 750	5 000	C-7A	Frost	6/60
<b>A23</b>									
50087	150A23/F/RS/130V/STD	150	E26	130	1 750	5 000	C-7A	Frost	6/60
50074	200A23/F/RS/130V/STD	200	E26	130	2 500	5 000	C-7A	Frost	6/60

# High Voltage



MOL.: 3 1/2 in. (89 mm)  
LCL.: 2 3/8 in. (60 mm)

**A15**



MOL.: 4 1/4 in. (108 mm)  
LCL.: 3 1/8 in. (79 mm)

**A19**



MOL.: 3 29/32 in. (99 mm)  
LCL.: 2 9/16 in. (65 mm)

**B10**



MOL.: 2 5/16 in. (68 mm)  
LCL.: 1 15/32 in. (57 mm)

**T7**



MOL.: 9 13/32 in. (239 mm)  
LCL.: 7 in. (178 mm)

**PS35**

Order code	Description	Watts (W)	Base	Volts (V)	Lumen output (lm)	Average life (hrs)	Filament type	Finish	Case qty (inner/master)
<b>A15</b>									
14797	40A15/IF/250V	40	E26	250	300	5 000	C-9	Frost	1/50
<b>A19</b>									
59541	40A19/F/1M/E27/230 240V/STD	40	E27	240	410	1 000	CC-9	Frost	10/100
52021	50A19/F/2M/E27/230 250V/STD	50	E27	230	485	2 000	CC-9	Frost	6/120
14656	100A19F/2M/B22/230 250V	100	B22	230	1 380	2 000	CC-9	Frost	10/100
<b>B10</b>									
52158	25B10/CL/3M/E12/220V/STD	25	E12	220	185	3 000	C-7A	Clear	25/500
<b>T7</b>									
52193	15T7/CL/1.5M/E12/250V/STD	15	E12	250	95	1 500	C-7A	Clear	25/1 000
<b>PS35</b>									
14660	500PS35/CL/2M/E39/240V	500	E39	240	8 500	2 000	CC-9	Clear	1/12