

ORDERING INFORMATION

Order code: 31279
 Description: E22142-347-TDE FLX
 UPC: 69549312791

SPECIFICATIONS



Ballast type: Electronic
 Starting method: Program Start
 Lamp connection: Series
 Input voltage (V): 347 V
 Input frequency (Hz): 60 HZ
 Max. case temperature: 90 °C
 Thermal protection: Class P
 Type: 1 Outdoor
 Contains PCBs: No
 Sound rating: A
 Open current voltage (OCV) (V): 550
 Inherent thermal protection: Yes
 Lamp protection circuit: Yes
 ICES-005 Compliant: Class A RFLD



Lamp Type:	Number of lamps	Rated lamp watts	Min. start temp. (°F / °C)	Input current (A)	Input power (ANSI watts)	Ballast factor	Max THD (%)	Power factor	Max. lamp current crest factor	B.E.F.
347 VOLTS										
PL26/TTT (26W)	2	26	-22/-30	0.17	53	0.86	10	0.98	1.7	1.62
PL27/TTL (27W)	2	27	-22/-30	0.14	48	0.85	10	0.98	1.7	1.77
PL24/TTL (24W)	2	24	-22/-30	0.15	50	0.83	10	0.98	1.7	1.66
2D (21W)	2	21	-22/-30	0.13	43	0.81	15	0.98	1.7	1.88
PL42/TTT (42W)	1	42	-22/-30	0.11	39	0.80	15	0.98	1.7	2.05
PL32/TTT (32W)	1	32	-22/-30	0.09	30	0.80	20	0.97	1.7	2.67
PL26/TTT (26W)	1	26	-22/-30	0.08	27	0.88	20	0.97	1.7	3.26
PL40/TTL (40W)	1	40	-22/-30	0.11	37	0.78	15	0.97	1.7	2.11
PL39/TTL (39W)	1	39	-22/-30	0.09	29	0.49	15	0.96	1.7	1.69
PL36/TTL (36W)	1	36	-22/-30	0.08	28	0.73	15	0.96	1.7	2.61
PL27/TTL (27W)	1	27	-22/-30	0.06	23	0.82	25	0.95	1.7	3.57
PL24/TTL (24W)	1	24	-22/-30	0.06	22	0.80	25	0.95	1.7	3.64
2D (38W)	1	38	-22/-30	0.11	36	0.65	15	0.97	1.7	1.81
2D (28W)	1	28	-22/-30	0.08	28	0.67	15	0.96	1.7	2.39
FC9T5 (40W)	1	40	-22/-30	0.12	42	0.80	15	0.98	1.7	1.90
FC12T5 (22W)	1	22	-22/-30	0.07	23	0.78	25	0.95	1.7	3.39

This lighting equipment complies with Canadian standard ICES-005; for use in commercial applications.

WARRANTY:

Ballast warranty of 5 years for electronic ballast 70-75 °C. Ballast warranty of 3 years for electronic ballast 90 °C. For more information visit our website.



Data is based upon tests performed in a controlled environment and representative of relative performance. Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.

March 30, 2015

ORDERING INFORMATION


Order code: 31279
 Description: E22142-347-TDE FLX
 UPC: 69549312791

WIRING DIAGRAM

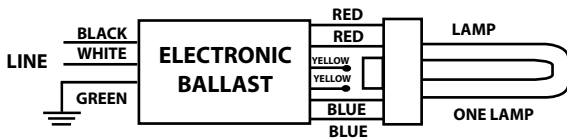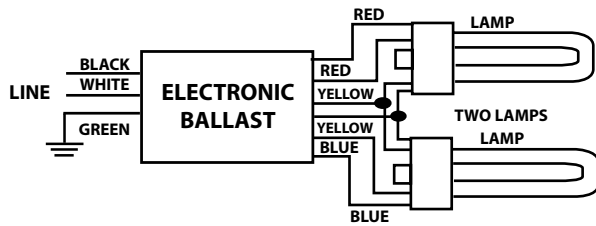

BALLAST DIMENSIONS

Length (L):	4.92" (12.5 cm)
Width (W):	2.51" (6.4 cm)
Height (H):	1.14" (2.9 cm)
Mounting (M):	4.49" (11.4 cm)

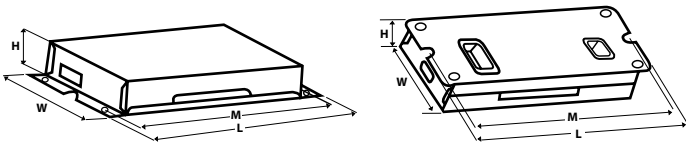

This lighting equipment complies with Canadian standard ICES-005; for use in commercial applications.

WARRANTY:

Ballast warranty of 5 years for electronic ballast 70-75 °C. Ballast warranty of 3 years for electronic ballast 90 °C. For more information visit our website.

Data is based upon tests performed in a controlled environment and representative of relative performance. Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.
 March 30, 2015