


# TECHNICAL INFORMATION BULLETIN

## ORDERING INFORMATION

Order code: **61951**  
 Description: **T120V/150W/AR/STD**  
 UPC: **69549619517**  
 Warranty: **3 Years**  
 Certification: 

## GENERAL INFORMATION


Ballast type: Halogen transformer  
 Transformer Type: Electronic  
 Lamp Connection: Parallel  
 Input Voltage: 120 VAC ±10 %  
 Input Frequency: 50/60 Hz  
 Minimum Starting Temperature: 0 °F, -18 °C  
 Maximum Case Temperature: 167 °F, 75 °C  
 Transient Protection meets ANSI: ANSI/IEEE C62.41 Cat. A  
 Short Circuit Protection: Yes  
 Dimmable: Yes

Lamp type	Power Output (W)	Input Current (A)	Power Factor	Output Voltage (V)
12 V Halogen lamps	150	1.35	0.99	12


## BALLAST DIMENSIONS

Length (L):	4.11 in.
Mounting (M):	3.62 in.
Width (W):	1.38 in.
Height (H):	1.10 in.
Lead Length:	
White, Black:	8 in.
Red:	6 in.
Case material:	Aluminum


## CASE DIAGRAM

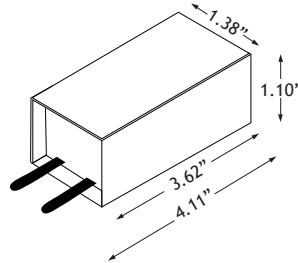

## WIRING DIAGRAM

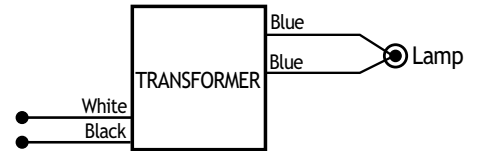

## HOT SPOT LOCATION

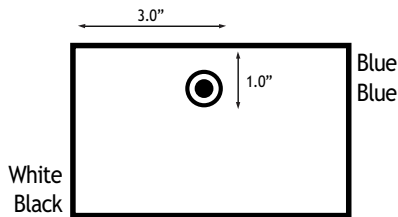

Data is based upon tests performed in a controlled environment and representative of relative performance. Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.