



G4



G9 2.5 W




G9 3.5 W



G9 4 W



T3 - 78 mm

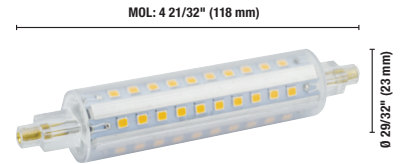

T3 - 118 mm

Order code	Description	Watts (W)	Base	Volts (VAC)	Color temp. (K)	Finish	Life L70 (hrs)	Lumen output (lm)	Beam angle (°)	Traditional equivalent (W)	Dimming capability (Yes/No)	Case qty (inner/master)
G4												
67093 ^{1 2}	G4/S2/12V/2.3W/30K/STD	2.3	G4	12	3 000	Clear	15 000	230	360	20	Yes	100/1 000
67094 ^{1 2}	G4/S2/12V/2.3W/40K/STD	2.3	G4	12	4 000	Clear	15 000	230	360	20	Yes	100/1 000
G9												
63618	LED/G9/2.5W/27K/STD	2.5	G9	120	2 700	Frost	20 000	190	300	20	Yes	50/200
63619	LED/G9/2.5W/30K/STD	2.5	G9	120	3 000	Frost	20 000	200	300	20	Yes	50/200
63620	LED/G9/2.5W/40K/STD	2.5	G9	120	4 000	Frost	20 000	210	300	20	Yes	50/200
63444 ²	LED/G9/3.5W/27K/STD	3.5	G9	120	2 700	Frost	30 000	210	300	20	Yes	50/500
63445 ²	LED/G9/3.5W/30K/STD	3.5	G9	120	3 000	Frost	30 000	225	300	20	Yes	50/500
63446 ²	LED/G9/3.5W/40K/STD	3.5	G9	120	4 000	Frost	30 000	245	300	20	Yes	50/500
66692	G9H0/S2/4W/27K/FR/STD	4	G9	120	2 700	Frost	10 000	430	330	40	Yes	50/200
66693	G9H0/S2/4W/30K/FR/STD	4	G9	120	3 000	Frost	10 000	450	330	40	Yes	50/200
66694	G9H0/S2/4W/40K/FR/STD	4	G9	120	4 000	Frost	10 000	450	330	40	Yes	50/200
67941 ³	G9H0/S3/5W/30K/CL/STD	5	G9	120	3 000	Clear	15 000	480	360	40	Yes	50/500
67942 ³	G9H0/S3/5W/50K/CL/STD	5	G9	120	5 000	Clear	15 000	480	360	40	Yes	50/500
T3-R7S												
64466 ¹	LED/R7S/5W/30K/78/ND/STD	5	R7S	120	3 000	Clear	15 000	450	360	50	No	50/200
64467 ¹	LED/R7S/8W/30K/118/ND/STD	8	R7S	120	3 000	Clear	15 000	650	360	100	No	50/200

Lumen values are derived from photometric testing
 For a complete list of compatible dimmers, please visit www.standardpro.com
³ If used in totally enclosed luminaire life hours may be reduced by 50%

