


Date: _____
 In hands date of project: _____
 Project name/Number: _____
 Name of distributor: _____
 Client #: _____
 Name of end user: _____

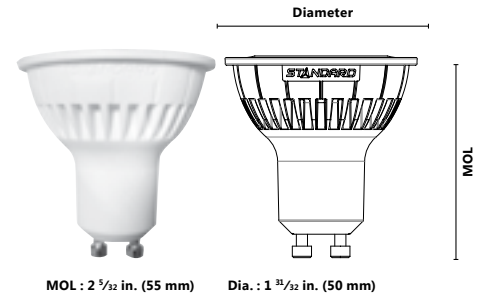

ORDERING INFORMATION

Order code: 63995
 Description: LED/GU10/5W/30K/38/STD
 UPC: 69549639959
 Case quantity: 24

PERFORMANCE DATA

Shape: MR16
 Base: GU10
 Wattage (W): 5
 Lamp voltage (VAC): 120
 Colour temperature (K)**: 3 000
 Average life (L70 hours): 40 000
 Initial lumens (lm)*: 452
 Initial lumens per watt (lm/W): 90
 CRI: 83
 R9: 10
 Beam angle (°): 38
 CBCP: 937
 Power factor: 0.85
 Operating temperature range: - 40 °C / - 40 °F to 40 °C / 104 °F

*Initial lumens range: +/- 10 % **Typical colour temperature range: +/- 10 %



COMPATIBLE DIMMER LIST

Legrand	HCL453P
Cooper	DAL06P, SAL06P, SLC03P, AAL06
Leviton	IPL06, 6674, DSM10-1LZ
Lutron	CTCL-153P

CAUTIONS

- Turn power off before inspection, installation, or removal.
- Risk of electrical shock – do not use where directly exposed to water or weather.
- Not for use in totally enclosed luminaire.
- Suitable for use in damp locations.
- Do not open – no user serviceable parts inside.
- Use only on 120 VAC, 60Hz circuits.
- This device is not intended for use with emergency exit fixtures or emergency exit lights.
- Compatible with most dimmers.
- For complete dimmer and warranty information visit www.standardpro.com.
- Not recommended for use with timers.
- Operating temperature: -40 °C / -40 °F to 40 °C / 104 °F
- 5 Years Limited Warranty.

Qty	Description	Price

I accept the specifications of the lamp configuration mentioned above.

Name: _____
 Company: _____
 Signature: _____

Date: _____

Data is based upon tests performed in a controlled environment and representative of relative performance. Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.