



# LED Filament

The LED filament lamps distinguish themselves by their sparkling white light, blending perfectly with crystal chandeliers and modern style fixtures.

The LED filament victorian style lamps, they have an amber coating which provides a warm light that resembles the ambiance created by incandescent lamps.


This line also includes a long life lamps series, which bring style to any decor while offering an exceptional long life of 25 000 hours.



Order Code	Description	Filament type	Watts (W)	Base	Volts (VAC)	Colour temp. (K)	CRI	Life L70 (hrs)	Lumen output (lm)	Traditional equivalent (W)	Case qty (inner/master)
<b>Half Mirror</b>											
<b>A19</b>											
65821 <sup>2</sup>	LED/A19/S2/4W/27K/HM/O/FIL/STD	Oblique	4	E26	120	2 700	80	15 000	360	40	10/50
<b>G25</b>											
67661 <sup>2</sup>	G25/S3/4.5W/27K//HM/O/FIL/STD	Vertical	4.5	E26	120	2 700	80	15 000	380	40	10/40
<b>Soft White</b>											
<b>A19</b>											
65820 <sup>1,2</sup>	LED/A19/S2/7W/27K/SW/FIL/STD	N/A	7	E26	120	2 700	80	15 000	700	60	10/50
67781 <sup>1,2</sup>	A19/S3/8.5W/30K/SW/FIL/STD	N/A	8.5	E26	120	3 000	80	15 000	800	60	10/40
<b>B11</b>											
65823 <sup>1,2</sup>	LED/B11/S2/4W/27K/SW/E12/FIL/STD	N/A	4	E12	120	2 700	80	15 000	360	40	10/50
<b>G16.5</b>											
67166 <sup>1</sup>	G16.5/S2/5W/27K/SW/E12/FIL/STD	N/A	5	E12	120	2 700	80	15 000	400	60	1/75
<b>G25</b>											
67662 <sup>1,2</sup>	G25/S3/4.5W/27K/SW/FIL/STD	N/A	4.5	E26	120	2 700	80	15 000	380	40	10/40
<b>G40</b>											
67667 <sup>1,2</sup>	G40/S3/8.5W/27K/SW/FIL/STD	N/A	8.5	E26	120	2 700	80	15 000	800	60	5/20
<b>T9</b>											
67783 <sup>1,2</sup>	T9/S3/5W/27K/SW/FIL/STD	N/A	5	E26	120	2 700	80	15 000	500	60	10/100




Lumen values are derived from photometric testing. For a complete list of compatible dimmers, please visit [www.standardpro.com](http://www.standardpro.com)

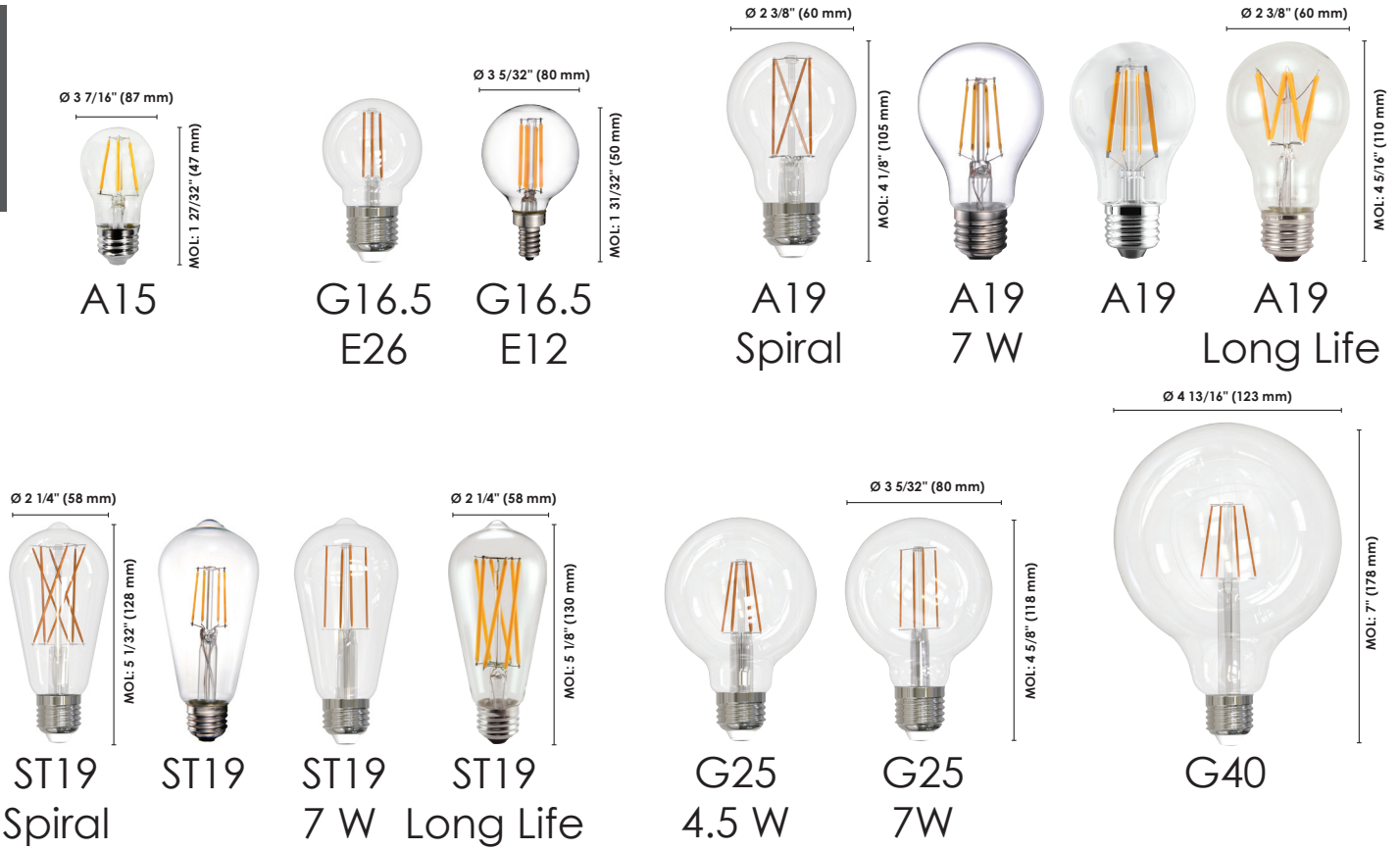

Order Code	Description	Filament type	Watts (W)	Base	Volts (VAC)	Colour temp. (K)	CRI	Finish	Life L70 (hrs)	Lumen output (lm)	Traditional equivalent (W)	Case qty (Inner/master)
<b>A15</b>												
65832	LED/A15/S2/6W/27K/O/FIL/STD	Oblique	6	E26	120	2 700	80	Clear	15 000	500	60	1/50
<b>A19</b>												
65677	LED/A19/S2/5.6W/27K/O/FIL/STD	Oblique	5.6	E26	120	2 700	80	Clear	15 000	450	40	1/50
64266 <sup>1</sup>	LED/A19/6.5W/27K/O/FIL/STD	Oblique	6.5	E26	120	2 700	80	Clear	15 000	800	60	1/50
64526 <sup>4</sup>	LED/A19/6W/27K/LL/Z/FIL/STD	Zig-Zag	6	E26	120	2 700	95	Clear	25 000	600	60	50/100
65770	LED/A19/S2/7W/27K/V/FIL/STD	Vertical	7	E26	120	2 700	80	Clear	15 000	800	60	1/50
67746	A19/S3/7W/30K/S/FIL/STD	Spiral	7	E26	120	3 000	80	Clear	15 000	800	60	10/40
<b>ST19</b>												
67750	ST19/S3/4.5W/27K/O/FIL/STD	Oblique	4.5	E26	120	2 700	80	Clear	15 000	450	40	10/40
67749	ST19/S3/4.5W/30K/S/FIL/STD	Spiral	4.5	E26	120	3 000	80	Clear	15 000	450	40	10/40
64530 <sup>4</sup>	LED/ST19/6W/27K/LL/S/FIL/STD	Spiral	6	E26	120	2 700	95	Clear	25 000	600	60	50/100
67162 <sup>2</sup>	ST19/S2/7W/27K/V/FIL/STD	Vertical	7	E26	120	2 700	80	Clear	15 000	800	60	10/40
67163 <sup>2</sup>	ST19/S2/7W/30K/V/FIL/STD	Vertical	7	E26	120	3 000	80	Clear	15 000	800	60	10/40
<b>G16.5</b>												
65833	LED/G16.5/S2/5W/27K/E12/V/FIL/STD	Vertical	5	E12	120	2 700	80	Clear	15 000	425	40	1/75
67764	G16.5/S3/5W/27K/V/FIL/STD	Vertical	5	E26	120	2 700	80	Clear	15 000	500	60	1/75
<b>G25</b>												
67663 <sup>2</sup>	G25/S3/4.5W/27K/O/FIL/STD	Oblique	4.5	E26	120	2 700	80	Clear	15 000	450	40	10/40
67664 <sup>2</sup>	G25/S3/7W/27K/V/FIL/STD	Vertical	7	E26	120	2 700	80	Clear	15 000	800	60	10/100
<b>G40</b>												
67666 <sup>2</sup>	G40/S3/4.5W/27K/O/FIL/STD	Oblique	4.5	E26	120	2 700	80	Clear	15 000	450	40	5/20




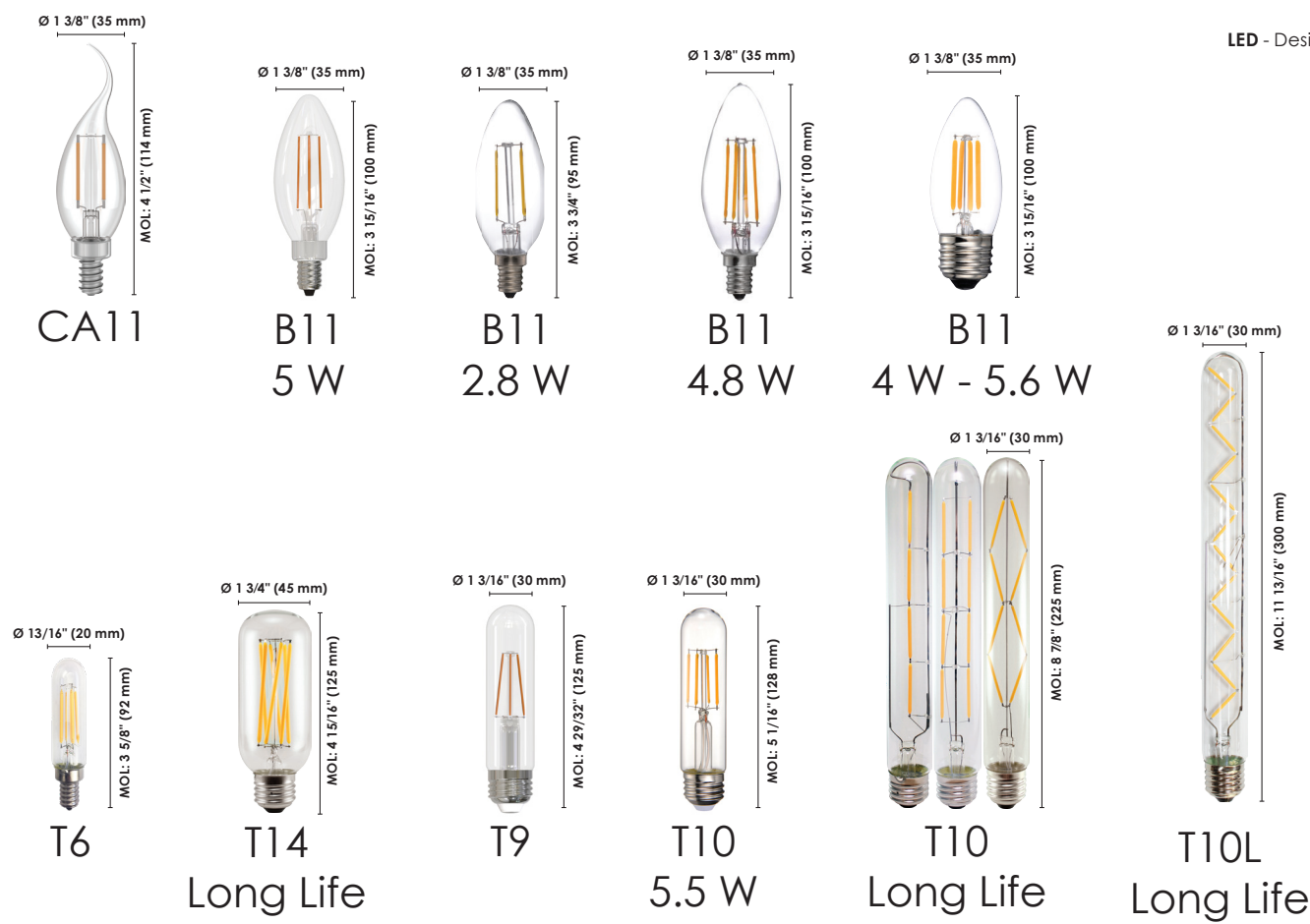

Order Code	Description	Filament type	Watts (W)	Base	Volts (VAC)	Colour temp. (K)	CRI	Finish	Life L70 (hrs)	Lumen output (lm)	Traditional equivalent (W)	Case qty (inner/master)
<b>B11</b>												
65671	LED/B11/S2/2.8W/27K/E12/V/FIL/STD	Vertical	2.8	E12	120	2 700	80	Clear	15 000	225	25	1/72
65669	LED/B11/S2/4W/27K/V/FIL/STD	Vertical	4	E26	120	2 700	80	Clear	15 000	336	40	1/72
65672	LED/B11/S2/4.8W/27K/E12/V/FIL/STD	Vertical	4.8	E12	120	2 700	80	Clear	15 000	400	60	1/72
65834	LED/B11/S2/4.8W/30K/E12/V/FIL/STD	Vertical	4.8	E12	120	3 000	80	Clear	15 000	400	60	1/72
65835	LED/B11/S2/4.8W/40K/E12/V/FIL/STD	Vertical	4.8	E12	120	4 000	80	Clear	15 000	400	60	1/72
67757	B11/S3/5W/50K/E12/V/FIL/STD	Vertical	5	E12	120	5 000	80	Clear	15 000	500	60	10/100
65670	LED/B11/S2/5.6W/27K/V/FIL/STD	Vertical	5.6	E26	120	2 700	80	Clear	15 000	500	60	1/72
<b>CA11</b>												
64612	LED/CA11/2.5W/27K/E12/V/FIL/STD	Vertical	2.5	E12	120	2 700	80	Clear	15 000	200	25	1/80
65674	LED/CA11/S2/4.8W/27K/E12/V/FIL/STD	Vertical	4.8	E12	120	2 700	80	Clear	15 000	398	60	1/80
<b>T6</b>												
67207 <sup>2,3</sup>	T6/S2/4W/27K/E12/V/FIL/STD	Vertical	4	E12	120	2 700	90	Clear	25 000	280	40	10/100
67208 <sup>2,3</sup>	T6/S2/4W/30K/E12/V/FIL/STD	Vertical	4	E12	120	3 000	90	Clear	25 000	280	40	10/100
<b>T14</b>												
64528 <sup>4</sup>	LED/T14/6W/27K/LL/S/FIL/STD	Spiral	6	E26	120	2 700	95	Clear	25 000	450	40	50/100
<b>T9</b>												
67784	T9/S3/5W/30K/O/FIL/STD	Oblique	5	E26	120	3 000	80	Clear	15 000	500	60	10/100
<b>T10</b>												
64518 <sup>4</sup>	LED/T10/3W/27K/LL/V/FIL/STD	Vertical	3	E26	120	2 700	95	Clear	25 000	300	40	50/100
67165	T10/S2/5.5W/27K/V/FIL/STD	Vertical	5.5	E26	120	2 700	80	Clear	15 000	500	60	1/72
64520 <sup>4</sup>	LED/T10/6W/27K/LL/V/FIL/STD	Vertical	6	E26	120	2 700	95	Clear	25 000	600	60	50/100
64522 <sup>4</sup>	LED/T10/6W/27K/LL/Z/FIL/STD	Zig-Zag	6	E26	120	2 700	95	Clear	25 000	600	60	50/100
<b>T10L</b>												
64524 <sup>4</sup>	LED/T10L/6W/27K/LL/Z/FIL/STD	Zig-Zag	6	E26	120	2 700	80	Clear	25 000	600	60	50/100



Lumen values are derived from photometric testing. For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit [www.standardpro.com](http://www.standardpro.com)

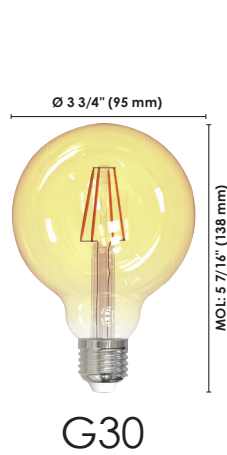

Order Code	Description	Filament type	Watts (W)	Base	Volts (VAC)	Colour temp. (K)	CRI	Finish	Life L70 (hrs)	Lumen output (lm)	Traditional equivalent (W)	Case qty (inner/master)
<b>Victorian Style</b>												
<b>A19</b>												
64527 <sup>2</sup>	LED/A19/6W/22K/LL/A/Z/FIL/STD	Zig-Zag	6	E26	120	2 200	95	Amber	25 000	450	40	50/100
<b>ST19</b>												
64278 <sup>1</sup>	LED/ST19/2.5W/22K/A/V/FIL/STD	Vertical	2.5	E26	120	2 200	80	Amber	15 000	210	25	1/50
65772	LED/ST19/S2/4W/22K/A/V/FIL/STD	Vertical	4	E26	120	2 200	80	Amber	15 000	400	40	10/50
65680	LED/ST19/S2/4.5W/22K/A/V/FIL/STD	Vertical	4.5	E26	120	2 200	80	Amber	15 000	407	40	1/50
64531 <sup>2</sup>	LED/ST19/6W/22K/LL/A/S/FIL/STD	Spiral	6	E26	120	2 200	95	Amber	25 000	450	40	50/100
<b>G30</b>												
67665	G30/S3/4.5W/22K/A/O/FIL/STD	Oblique	4.5	E26	120	2 200	80	Amber	15 000	380	40	10/40
<b>G40</b>												
67668	G40/S3/4.5W/22K/A/O/FIL/STD	Oblique	4.5	E26	120	2 200	80	Amber	15 000	380	40	5/20



B11  
4.8 W




B11  
3 W




CA11



T14  
Long Life

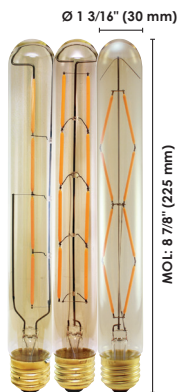

T10  
Long Life

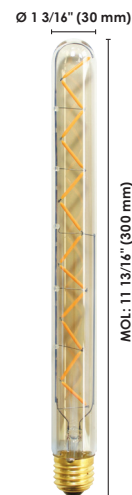


T10L  
Long Life

Order Code	Description	Filament type	Watts (W)	Base	Volts (VAC)	Colour temp. (K)	CRI	Finish	Life L70 (hrs)	Lumen output (lm)	Traditional equivalent (W)	Case qty (inner/master)
<b>Victorian Style</b>												
<b>B11</b>												
64550	LED/B11/3W/24K/A/V/FIL/STD	Vertical	3	E26	120	2 400	75	Amber	15 000	280	25	1/24
67758	B11/S3/3.6W/22K/A/E12/V/FIL/STD	Vertical	3.6	E12	120	2 200	80	Amber	15 000	320	40	10/100
<b>CA11</b>												
65676	LED/CA11/S2/4.8W/22K/A/E12/V/FIL/STD	Vertical	4.8	E12	120	2 200	80	Amber	15 000	338	40	1/80
<b>T14</b>												
64529 <sup>2</sup>	LED/T14/6W/22K/LL/A/S/FIL/STD	Spiral	6	E26	120	2 200	95	Amber	25 000	450	40	50/100
<b>T10</b>												
64519 <sup>2</sup>	LED/T10/3W/22K/LL/A/V/FIL/STD	Vertical	3	E26	120	2 200	95	Amber	25 000	250	25	50/100
64521 <sup>2</sup>	LED/T10/6W/22K/LL/A/V/FIL/STD	Vertical	6	E26	120	2 200	95	Amber	25 000	450	40	50/100
64523 <sup>2</sup>	LED/T10/6W/22K/LL/A/Z/FIL/STD	Zig-Zag	6	E26	120	2 200	95	Amber	25 000	450	40	50/100
<b>T10L</b>												
64525 <sup>2</sup>	LED/T10L/6W/22K/LL/A/Z/FIL/STD	Zig-Zag	6	E26	120	2 200	95	Amber	25 000	450	40	50/100



Lumen values are derived from photometric testing. For a complete list of compatible dimmers and ENERGY STAR qualified products, please visit [www.standardpro.com](http://www.standardpro.com)



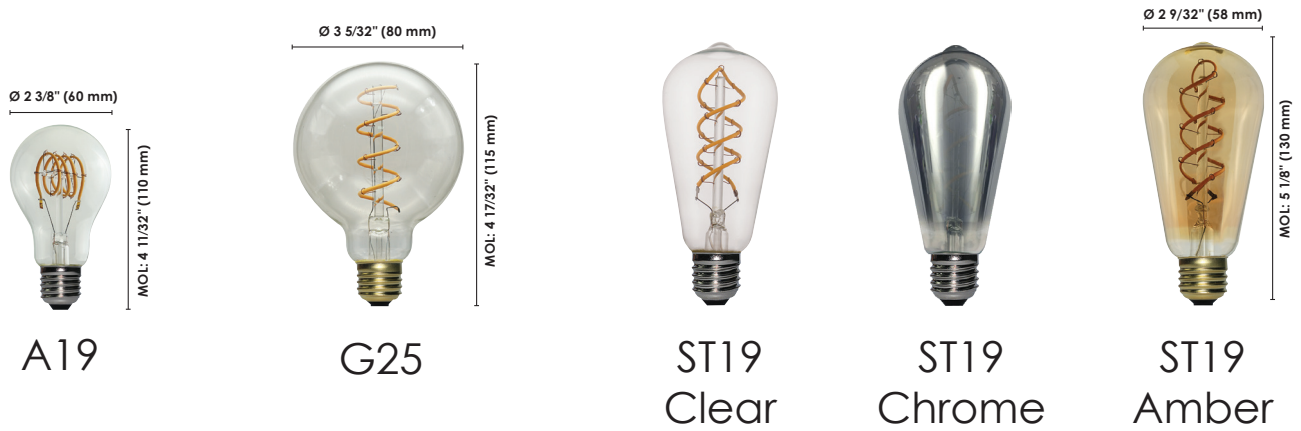

Order Code	Description	Filament type	Watts (W)	Base	Volts (VAC)	Colour temp. (K)	CRI	Finish	Life L70 (hrs)	Lumen output (lm)	Case qty (inner/master)
<b>Soft Filament</b>											
<b>A19</b>											
67315	A19/4.5W/27K/QL/FIL/STD	Quad Loop	4.5	E26	120	2 700	90	Clear	15 000	250	50/100
<b>ST19</b>											
67317	ST19/5W/27K/DH/FIL/STD	Double Helix	5	E26	120	2 700	90	Clear	15 000	300	50/100
67318	ST19/5W/27K/CH/DH/FIL/STD	Double Helix	5	E26	120	2 700	90	Chrome	15 000	125	50/100
67319	ST19/5W/27K/A/DH/FIL/STD	Double Helix	5	E26	120	2 700	90	Amber	15 000	250	50/100
<b>G25</b>											
67316	G25/4.5W/27K/H/FIL/STD	Helix	4.5	E26	120	2 700	90	Clear	15 000	285	25/50



BEAM SPREAD



DAMP



DIMMABLE



ENCLOSED FIXTURE



3 YEARS WARRANTY

