

Project: \_\_\_\_\_ Type: \_\_\_\_\_

Drawn by: \_\_\_\_\_ Catalogue #: \_\_\_\_\_ Date: \_\_\_\_\_

## Individual Spec Sheet

# GIMBAL

## TRIM

### ORDERING INFORMATION

**Order code:** 66230  
**Model number:** LED/DL/GIMBAL/3IN/TRIM/RND/FLAT/BK/STD  
**UPC:** 069549662308  
**Case quantity:** 96

### PHYSICAL DATA


**Shape:** Round  
**Type:** Flat  
**Trim material:** Diecast aluminum  
**Colour:** Black  
**Aperture:** Round  
**Aperture diameter:** 1 7/8" (47.5 mm)  
**Diameter:** 3 3/8" (85 mm)  
**Installation method:** Twist-lock

### COMPATIBLE MODULES<sup>1</sup>

Order code	Model number
65422	LED/DL/GIMBAL/MOD/7W/30K/BN/STD
65423	LED/DL/GIMBAL/MOD/7W/40K/BN/STD
65982	LED/DL/GIMBAL/MOD/7W/30-22K/BN/STD
65420	LED/DL/GIMBAL/MOD/7W/30K/WH/STD
65421	LED/DL/GIMBAL/MOD/7W/40K/WH/STD
65981	LED/DL/GIMBAL/MOD/7W/30-22K/WH/STD

<sup>1</sup>Gimbal LED Modules are sold separately.

### DIMENSIONS

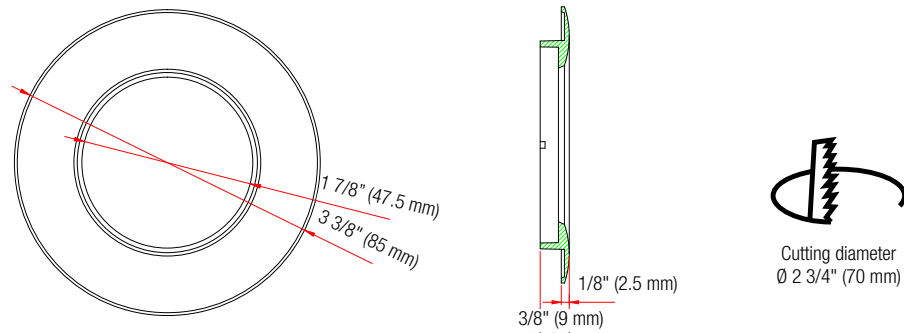

Qty	Description	Price

I accept the specifications of the luminaire configuration mentioned above.

Name: \_\_\_\_\_  
 Company: \_\_\_\_\_  
 Signature: \_\_\_\_\_

Date: \_\_\_\_\_

Data is based upon tests performed in a controlled environment. Actual performance can vary depending on operating conditions.  
 All products are subject to change or may be discontinued any time without notice.



Cutting diameter  
 Ø 2 3/4" (70 mm)