



# T RIGHT AWAY Y

**CABLOFIL®**

Tray Right Away Offering

Get ladder tray faster, directly to your jobsite.  
Ships from our facility in **5 days.**

 **legrand®**


## CUT SHIPPING TIMES IN HALF. START YOUR PROJECTS SOONER.

With **Tray Right Away**, you can get up and running in no time. With our expedited shipping, our most popular selection of sturdy and innovative Itray Ladder Tray items leaves our facility within **5** business days after you place your order. Streamline your delivery and installation all at once.

Tray Right Away includes Itray 4" and 6" depths with NEMA 12C and 20C class designations.


## JUST WHAT YOU NEED, ONLY MUCH QUICKER.

- Absolutely no upcharges or extra costs for first truck load
- Access to our most popular ladder tray items
  - Ships within 5 business days of order placement\*
  - Everything you need to assemble a complete system
    - Dedicated customer service, production & logistics teams
      - Can be ordered and quoted via **myLegrand**

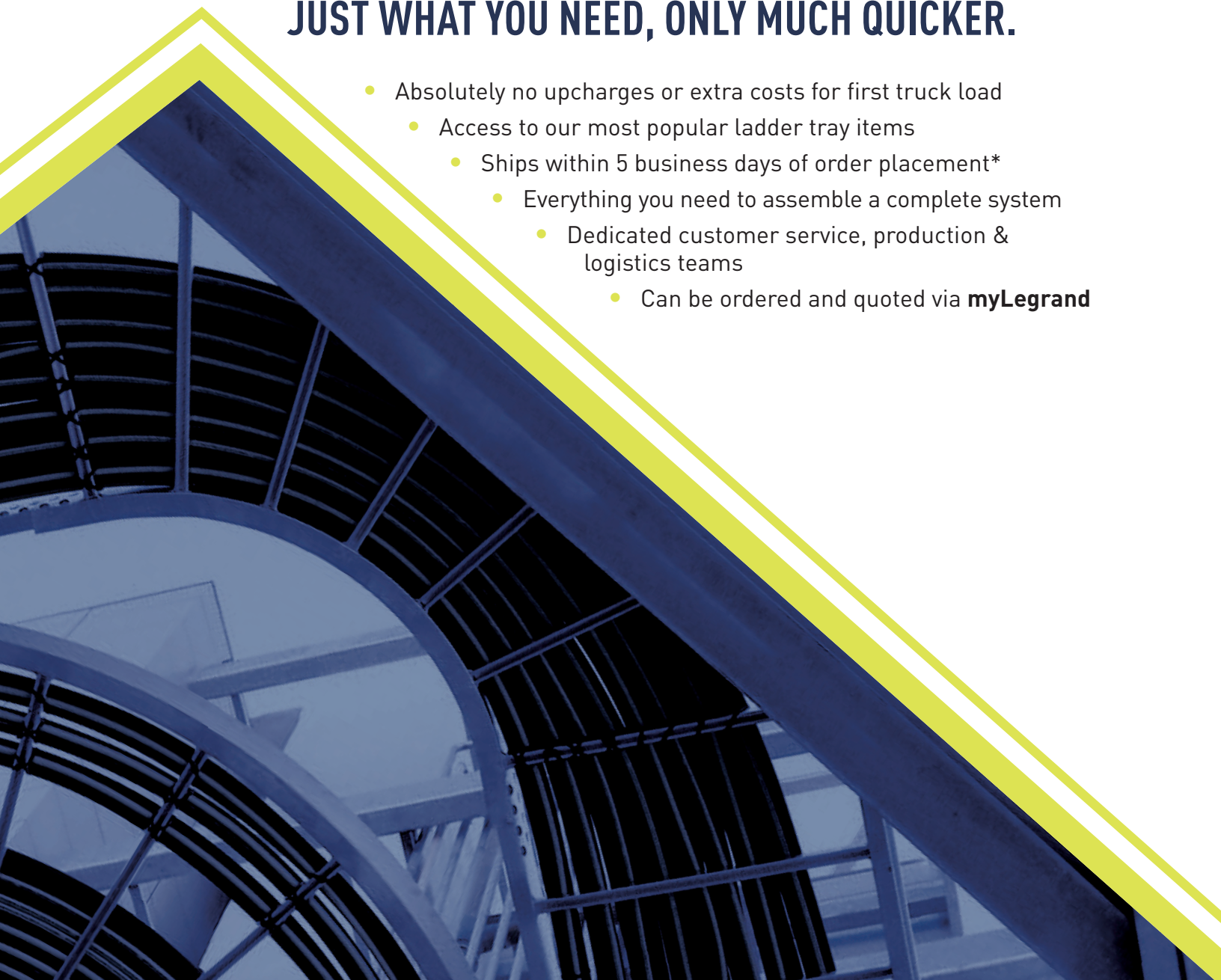


# CHOOSE THE BETTER, STRONGER CABLE TRAY. CHOOSE ITRAY.

- 30% faster installation with 50% less hardware
- Simple mid-span splicing while maintaining full NEMA load class
- I-beam side rails make a stronger, lighter tray
- Smoother, easier cable pulling with less damage
- Fittings that fit well together allow for smoother installations
- All-aluminum construction
- Integrates well with most existing tray installations

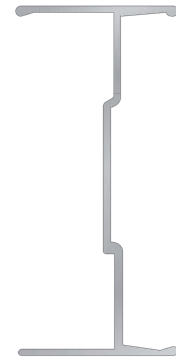


## FROM HERE TO THERE. GET STARTED ANYWHERE.

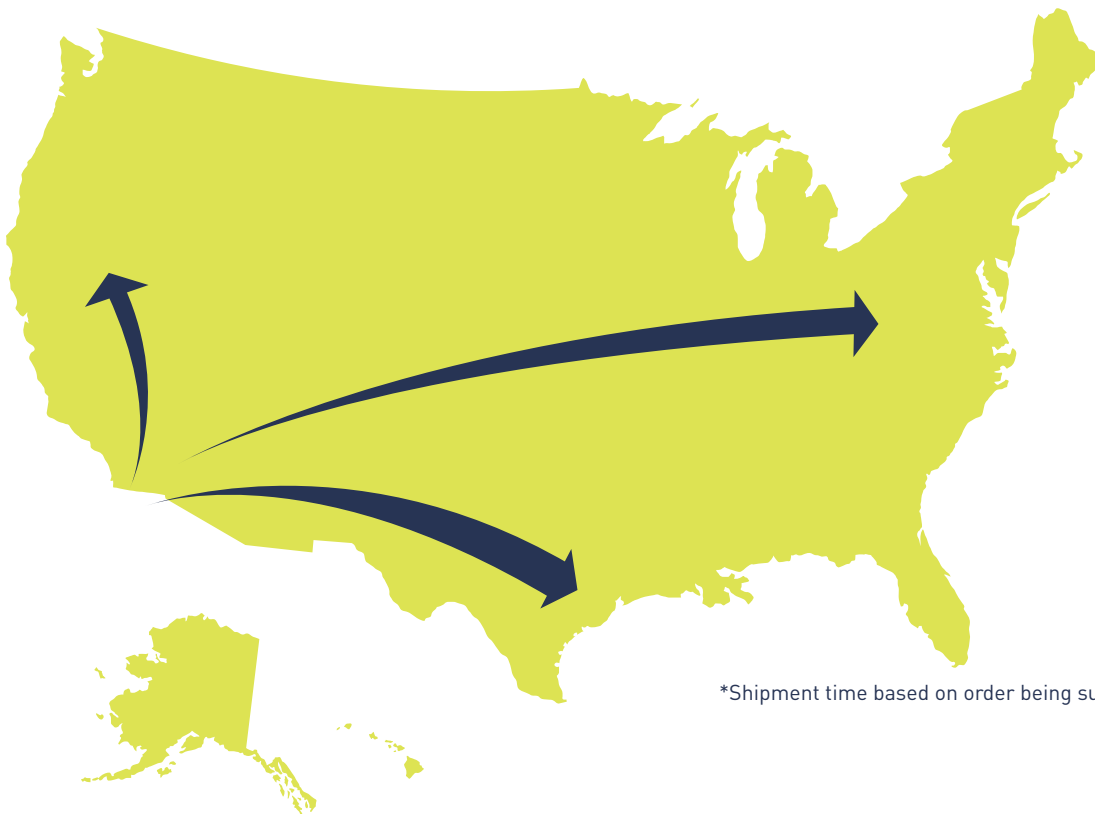

\*Shipment time based on order being submitted by 12:00PM CST.

**TO ORDER:** Just ask your sales rep to mark “Tray Right Away” on your quote. Be sure your order ships directly to the jobsite.

The products listed on the following product selection guide are eligible for the Tray Right Away program.

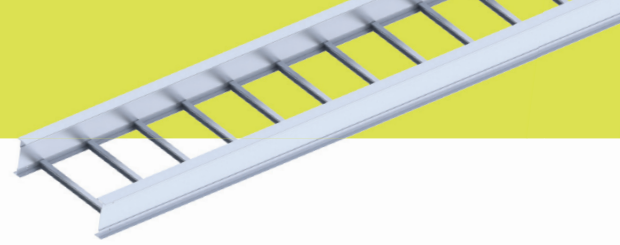

## STRAIGHT SECTIONS

PART NO.	NEMA CLASS	RUNG SPACING	HEIGHT	LENGTH	WIDTH
09-4A12C-S144-06	12C	9"	4"	144"	6"
09-4A12C-S144-12	12C	9"	4"	144"	12"
09-4A12C-S144-18	12C	9"	4"	144"	18"
09-4A12C-S144-24	12C	9"	4"	144"	24"
09-4A12C-S144-36	12C	9"	4"	144"	36"
09-6A12C-S144-06	12C	9"	6"	144"	6"
09-6A12C-S144-12	12C	9"	6"	144"	12"
09-6A12C-S144-18	12C	9"	6"	144"	18"
09-6A12C-S144-24	12C	9"	6"	144"	24"
09-6A12C-S144-36	12C	9"	6"	144"	36"
09-6A20C-S144-06	20C	9"	6"	144"	6"
09-6A20C-S144-12	20C	9"	6"	144"	12"
09-6A20C-S144-18	20C	9"	6"	144"	18"
09-6A20C-S144-24	20C	9"	6"	144"	24"
09-6A20C-S144-36	20C	9"	6"	144"	36"
09-6A20C-S240-06	20C	9"	6"	240"	6"
09-6A20C-S240-12	20C	9"	6"	240"	12"
09-6A20C-S240-18	20C	9"	6"	240"	18"
09-6A20C-S240-24	20C	9"	6"	240"	24"
09-6A20C-S240-36	20C	9"	6"	240"	36"

## HORIZONTAL CROSSES

PART NO.	HEIGHT	RADIUS	WIDTH
LD-4A-HX12-06	4"	12"	6"
LD-4A-HX12-12	4"	12"	12"
LD-4A-HX12-18	4"	12"	18"
LD-4A-HX12-24	4"	12"	24"
LD-4A-HX12-36	4"	12"	36"
LD-6A-HX12-06	6"	12"	6"
LD-6A-HX12-12	6"	12"	12"
LD-6A-HX12-18	6"	12"	18"
LD-6A-HX12-24	6"	12"	24"
LD-6A-HX12-36	6"	12"	36"



HX


## 90° HORIZONTAL ELBOWS

PART NO.	HEIGHT	RADIUS	WIDTH
LD-4A-90HB12-06	4"	12"	6"
LD-4A-90HB12-12	4"	12"	12"
LD-4A-90HB12-18	4"	12"	18"
LD-4A-90HB12-24	4"	12"	24"
LD-4A-90HB12-36	4"	12"	36"
LD-4A-90HB24-06	4"	24"	6"
LD-4A-90HB24-12	4"	24"	12"
LD-4A-90HB24-18	4"	24"	18"
LD-4A-90HB24-24	4"	24"	24"
LD-4A-90HB24-36	4"	24"	36"
LD-6A-90HB12-06	6"	12"	6"
LD-6A-90HB12-12	6"	12"	12"
LD-6A-90HB12-18	6"	12"	18"
LD-6A-90HB12-24	6"	12"	24"
LD-6A-90HB12-36	6"	12"	36"
LD-6A-90HB24-06	6"	24"	6"
LD-6A-90HB24-12	6"	24"	12"
LD-6A-90HB24-18	6"	24"	18"
LD-6A-90HB24-24	6"	24"	24"
LD-6A-90HB24-36	6"	24"	36"



## HORIZONTAL TEES

PART NO.	HEIGHT	RADIUS	WIDTH
LD-4A-HT12-06	4"	12"	6"
LD-4A-HT12-12	4"	12"	12"
LD-4A-HT12-18	4"	12"	18"
LD-4A-HT12-24	4"	12"	24"
LD-4A-HT12-36	4"	12"	36"
LD-4A-HT24-06	4"	24"	6"
LD-4A-HT24-12	4"	24"	12"
LD-4A-HT24-18	4"	24"	18"
LD-4A-HT24-24	4"	24"	24"
LD-4A-HT24-36	4"	24"	36"
LD-6A-HT12-06	6"	12"	6"
LD-6A-HT12-12	6"	12"	12"
LD-6A-HT12-18	6"	12"	18"
LD-6A-HT12-24	6"	12"	24"
LD-6A-HT12-36	6"	12"	36"
LD-6A-HT24-06	6"	24"	6"
LD-6A-HT24-12	6"	24"	12"
LD-6A-HT24-18	6"	24"	18"
LD-6A-HT24-24	6"	24"	24"
LD-6A-HT24-36	6"	24"	36"

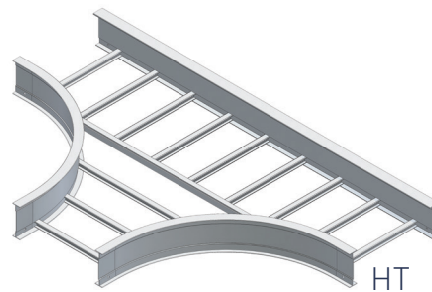


# PRODUCT SELECTION GUIDE

## 90° VERTICAL OUTSIDE ELBOWS

PART NO.	HEIGHT	RADIUS	WIDTH
LD-4A-90VO12-06	4"	12"	6"
LD-4A-90VO12-12	4"	12"	12"
LD-4A-90VO12-18	4"	12"	18"
LD-4A-90VO12-24	4"	12"	24"
LD-4A-90VO12-36	4"	12"	36"
LD-4A-90VO24-06	4"	24"	6"
LD-4A-90VO24-12	4"	24"	12"
LD-4A-90VO24-18	4"	24"	18"
LD-4A-90VO24-24	4"	24"	24"
LD-4A-90VO24-36	4"	24"	36"
LD-6A-90VO12-06	6"	12"	6"
LD-6A-90VO12-12	6"	12"	12"
LD-6A-90VO12-18	6"	12"	18"
LD-6A-90VO12-24	6"	12"	24"
LD-6A-90VO12-36	6"	12"	36"
LD-6A-90VO24-06	6"	24"	6"
LD-6A-90VO24-12	6"	24"	12"
LD-6A-90VO24-18	6"	24"	18"
LD-6A-90VO24-24	6"	24"	24"
LD-6A-90VO24-36	6"	24"	36"



## 90° VERTICAL INSIDE ELBOWS

PART NO.	HEIGHT	RADIUS	WIDTH
LD-4A-90VI12-06	4"	12"	6"
LD-4A-90VI12-12	4"	12"	12"
LD-4A-90VI12-18	4"	12"	18"
LD-4A-90VI12-24	4"	12"	24"
LD-4A-90VI12-36	4"	12"	36"
LD-4A-90VI24-06	4"	24"	6"
LD-4A-90VI24-12	4"	24"	12"
LD-4A-90VI24-18	4"	24"	18"
LD-4A-90VI24-24	4"	24"	24"
LD-4A-90VI24-36	4"	24"	36"
LD-6A-90VI12-06	6"	12"	6"
LD-6A-90VI12-12	6"	12"	12"
LD-6A-90VI12-18	6"	12"	18"
LD-6A-90VI12-24	6"	12"	24"
LD-6A-90VI12-36	6"	12"	36"
LD-6A-90VI24-06	6"	24"	6"
LD-6A-90VI24-12	6"	24"	12"
LD-6A-90VI24-18	6"	24"	18"
LD-6A-90VI24-24	6"	24"	24"
LD-6A-90VI24-36	6"	24"	36"

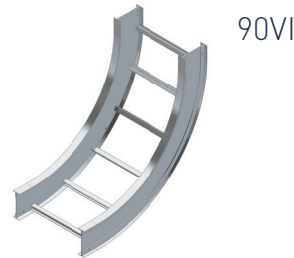

## CLAMPS

PART NO.	PART NAME
A-A840-01-ZN	Tin Plated Ground Clamp, Zinc Plated Hardware
Z-1893-01-ZN	Hold Down Expansion Clamp Kit, Zinc Plated Steel-Includes 3/8"x1 1/2" Hex Head Bolt & 3/8" Flanged Hex Nut
Z-1893-02	Zinc Hold Down Expansion Clamp Kit, No Hardware
Z-1893-03-ZN	Hold Down Expansion Clamp Kit, Zinc Plated Steel-Includes 3/8"x1 1/2" Hex Head Bolt & 3/8" Channel Nut w/ Spring
ABJ-2000-GE	Laminated Bonding Jumper - Includes Hardware
A-1893-01-ZN	Aluminum -Includes 3/8"x1 1/2" Hex Head Bolt & 3/8" Flanged Hex Nut
A-1893-02	Aluminum Hold Down Expansion Clamp Kit, No Hardware
A-1893-03-ZN	Aluminum -Includes 3/8"x1 1/2" Hex Head Bolt & 3/8" Channel Nut w/ Spring

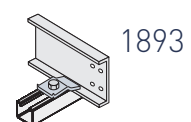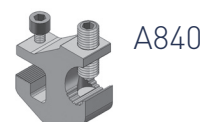

# PRODUCT SELECTION GUIDE

## HANGER KITS


PART NO.	PART NAME	LENGTH
M-0393-16-ZN	Single Hanger Channel Kit	16"
M-0393-22-ZN	Single Hanger Channel Kit	22"
M-0393-28-ZN	Single Hanger Channel Kit	28"

## CABLE DROPOUT KITS

PART NO.	WIDTH
A-DO-06-S6	6"
A-DO-12-S6	12"
A-DO-18-S6	18"
A-DO-24-S6	24"
A-DO-36-S6	36"


## DIVIDER KITS

PART NO.	PART NAME	HEIGHT	LENGTH
4A-0012-99-S6	Straight Divider Kit	4"	12'
4A-0606-99-S6	Flexible Divider Kit	4"	6'
6A-0012-99-S6	Straight Divider Kit	6"	12'
6A-0606-99-S6	Flexible Divider Kit	6"	6'
4A-DIV-90V012-S6	Outside Vertical Elbow Divider	4"	12'
4A-DIV-90V024-S6	Outside Vertical Elbow Divider	4"	24'
4A-DIV-90V112-S6	Inside Vertical Elbow Divider	4"	12'
4A-DIV-90V124-S6	Inside Vertical Elbow Divider	4"	24'
6A-DIV-90V012-S6	Outside Vertical Elbow Divider	6"	12'
6A-DIV-90V024-S6	Outside Vertical Elbow Divider	6"	24'
6A-DIV-90V112-S6	Inside Vertical Elbow Divider	6"	12'
6A-DIV-90V124-S6	Inside Vertical Elbow Divider	6"	24'

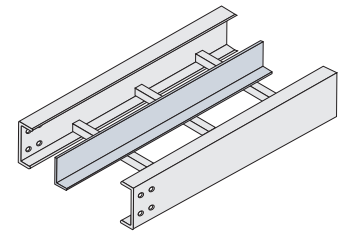


## SPLICE KITS

PART NO.	PART NAME	HEIGHT
4A-SSP-GE	Straight Splice Kit	4"
4A-FSP-GE	Fitting Splice Kit	4"
6A-SSP-GE	Straight Splice Kit	6"
6A-FSP-GE	Fitting Splice Kit	6"
4A-EXSP-GE	Expansion Splice Kit	4"
6A-EXSP-GE	Expansion Splice Kit	6"
4A-HASP-GE	Horz Adj Splice Kit	4"
6A-HASP-GE	Horz Adj Splice Kit	6"
4A-VASP-GE	Vert Adj Splice Kit	4"
6A-VASP-GE	Vert Adj Splice Kit	6"
4A-SSP-S6-UPCHG	Straight Splice Kit with Stainless Steel Hardware	4"
4A-FSP-S6-UPCHG	Fitting Splice Kit with Stainless Steel Hardware	4"
6A-SSP-S6-UPCHG	Straight Splice Kit with Stainless Steel Hardware	6"
6A-FSP-S6-UPCHG	Fitting Splice Kit with Stainless Steel Hardware	6"

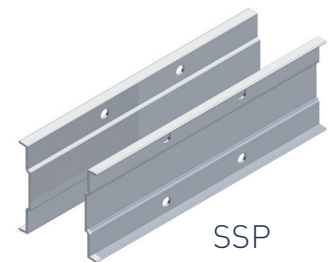

SSP

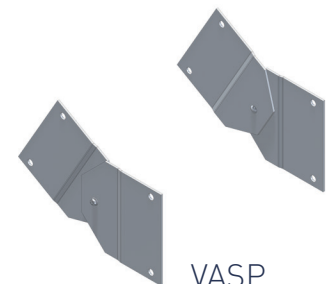

VASP



### **MORE INFO VISIT:**

[www.legrand.us/TrayRightAway](http://www.legrand.us/TrayRightAway)

### **TO ORDER:**

Just ask your sales rep to mark "Tray Right Away" on your quote.

### **ORDER NOW:**

Contact our customer service team:

1.800.658.4641 opt 1

Fax: 800.223.4196

Mon - Fri: 8am - 7pm EST

(excluding holidays)

[US-MAS-SharedMail-Cablofil-Pricing@Legrand.us](mailto:US-MAS-SharedMail-Cablofil-Pricing@Legrand.us)

designed to be better.™



#### **Electrical Wiring Systems**

8319 State Route 4  
Mascoutah, IL 62258  
800.658.4641  
[www.legrand.us](http://www.legrand.us)

Canada  
1.800.723.5175; 905.738.9195  
[www.legrand.ca](http://www.legrand.ca)

Costa Rica  
+506.298.56.04; +506.239.71.13  
[www.legrand.cr](http://www.legrand.cr)

FOLLOW US

