



PTTR8200W

PTTR8300W

PlugTail® Hard Use Hospital Grade Tamper-Resistant Receptacles. The fastest, most consistent and reliable wiring devices — ever.

PTTR8200, PTTR8300

Factory-terminated devices and connectors mean that device installation is the same regardless of skill level of the installer. The UL-Listed connectors are keyed to ensure proper wiring installation into each hospital grade receptacle. The connector simply snaps into the back of the device — no fussing with wires, stripping, or tightening screws. PlugTail devices are finger safe with no exposed terminals, so taping is not required. Now device installation is a snap!

PlugTail...The toughest and safest hospital grade receptacle

Features & Benefits


Auto-ground clip assures positive ground.

.036 inch thick, brass, triple-wipe power contacts for lasting retention.


Plated steel strap design for maximum durability and corrosion resistance.



PTTR8300W

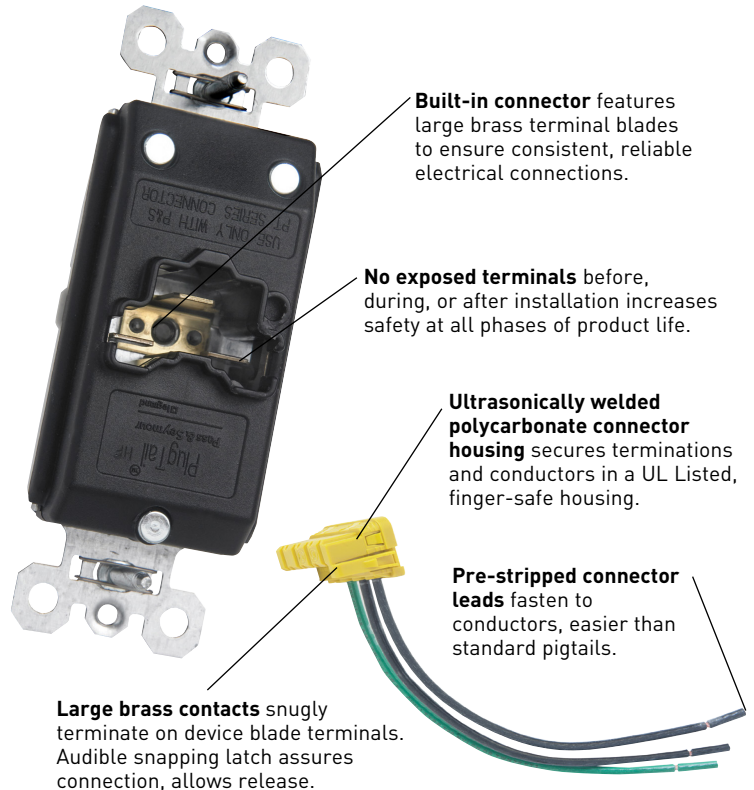

Compliance

 cUL Listed, File Number E140596, Standard UL498. UN SPSC: 3912406
Federal Specification WC596, Hospital Grade, CSA Listing: C22.2 No. 42.

Technical Information

Performance

Electrical

Dielectric Withstand Voltage	Withstands 2000V minimum
Maximum Working Voltage	125V
Current Interrupting	Certified for current interrupting at full-rated current (receptacle only)
Temperature Rise	Maximum 30°C temperature rise at full-rated current after 50 cycles of overload at 150% of rated current with direct current

Mechanical

PlugTail Connector Identification	#12 AWG, THHN, copper conductor, 6" leads, stripped, solid or stranded, for use with PlugTail Receptacles only
Product Identification	Ratings are permanent part of the device

Environmental

Flammability	UL94 V2
Operating Temperature	Maximum continuous +60°C, minimum -40°C without impact

Materials

Face	Nylon
Body	PVC
Contacts	.036 688 Brass
Mounting Strap	.042 Zinc-Plated Steel
Assembly Drive Screw	Zinc-Plated Steel
Auto-Ground Clip	Steel
Mounting Screws	Tri-Drive Steel

PlugTail Connector Materials

Housing	Polycarbonate
Contacts	.036 688 Brass

Warranty


1 Year

Country of Origin


Mexico

Buy America Act Status

Trade Agreement Act Compliant

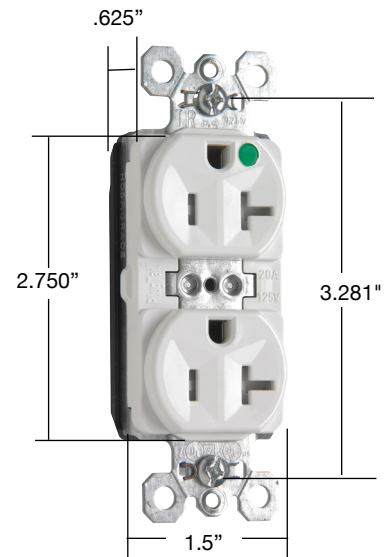

PTTR8200W

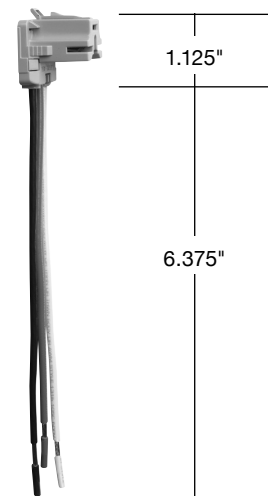

PTR65TR

Ordering Information

PlugTail® Hard Use Hospital Grade Tamper-Resistant Receptacles

Catalog Number	Rating			NEMA Config. No.	3rd Party Compliance
	A	VAC	Color		cULus
PTTR8200I	15	125	Ivory	5-15R	•
PTTR8200RED	15	125	Red	5-15R	•
PTTR8200W	15	125	White	5-15R	•
PTTR8300I	20	125	Ivory	5-20R	•
PTTR8300GRY	20	125	Gray	5-20R	•
PTTR8300RED	20	125	Red	5-20R	•
PTTR8300W	20	125	White	5-20R	•
PTTR8300BK	20	125	Black	5-20R	•
PTTR8300LA	20	125	Light Almond	5-20R	•
PTTR8300	20	125	Brown	5-20R	•




NEMA
5-15R



NEMA
5-20R

PlugTail® Connectors – Right Angle

Catalog Number	Wire Type	Length
PTRA6STR	#12 AWG Stranded	6 inches
PTRA6SOL	#12 AWG Solid	6 inches

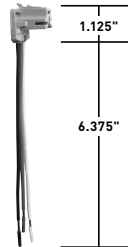

PTRA6STR

Also available

- SPD & Isolated Ground Devices
- Ground Continuity Monitoring (GCM)
- Straight Blade Plugs & Connectors
- USB Charging Devices
- Turnlok® Locking Devices
- Weatherproof Boxes & Covers
- IEC 309 Industrial Products
- Flexcor® Wire Mesh Grips
- Bulk Solutions
- SteriGuard® Antimicrobial Devices

All brand and product names referenced in this document are registered trademarks or trademarks of their respective holders.



Legrand, North America
60 Woodlawn Street
West Hartford, CT 06110
1.877.BY.LEGRAND (295.3472)
www.legrand.us
905.738.9195
www.legrand.ca

