

PULSAR PLUS

Small is powerful

The smart & powerful EV charger for your home



Pulsar Plus

Smart EV charging technology made simple.



Wallbox Pulsar Plus offers the best of both **small size and powerful performance** for faster electric vehicle charging at home.

Designed for easy installation, **Pulsar Plus can charge any electric car on the market** today and is future-ready to handle tomorrow's more powerful EV batteries. Home charging is simple and efficient with the integrated **myWallbox app**, which allows you to control your charger from your smart devices via **WiFi or Bluetooth**.



Get Pulsar Plus and start charging smarter.

PULSAR PLUS

Everything you need for smart EV charging at home



Compact design, powerful performance

240V, Level 2 charging technology in an incredibly small size. Adjustable capacity from 16A to 40A or 48A depending on model.



Connected and Smart

Connect Pulsar Plus to your smart devices using the myWallbox app to wirelessly control and monitor your charger via Wi-Fi or Bluetooth.



Power Sharing

Connect two or more Pulsar Plus chargers to the same electrical circuit to safely charge multiple EVs at one time.



Onboard Intelligence

Pulsar Plus lets you plug in, charge, and manage your schedules even when you can't connect to the internet.



Safe and Reliable

UL listed for electrical safety, NEMA Type 4 rated for dust/water resistance, backed by a 3-year warranty.



Rebate Eligible

Pulsar Plus is widely eligible for federal, state, and local tax credits and rebates where available.



PULSAR PLUS

One platform, multiple ways to access your charger

Use your smart devices with myWallbox to connect and control your charger

- ✓ Manage charging and monitor the status of your EV remotely from anywhere
- ✓ Set and change charging schedules
- ✓ Remote charger locking and unlocking
- ✓ Manage multiple users and multiple chargers
- ✓ Real-time charging statistics
- ✓ Real-time notifications



PULSAR PLUS

One charger, many possibilities

Compatible with all EVs


Charge any EV currently available, including Teslas (with the Tesla-provided J1172 adapter).

Easy and Convenient

Pulsar Plus is ready for easy installation by your professional electrician or a Wallbox-certified installer.

Indoors and Outdoors

Pulsar Plus is Type 4 rated for dust and water resistance, making it suitable for indoor or outdoor installation.

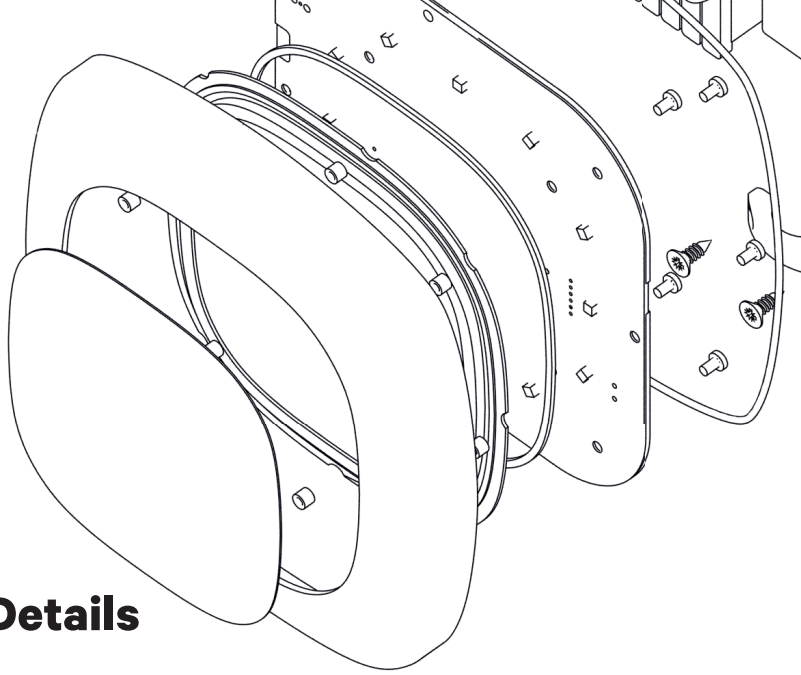

Product Details

GENERAL SPECIFICATIONS

Charging mode:	AC Level 2
Connector type:	Type 1 (SAE J1772)
Dimensions (without cable):	7.8"x7.9"x3.9"
Colour:	Matte Black
Weight:	4.4 lbs
Cable length:	25ft

CONNECTIVITY & USER INTERFACE

Connectivity:	Wi-Fi / Bluetooth
User Identification:	myWallbox app & portal
User Interface:	myWallbox app & portal
Charger Status Information:	Halo RGB LED / myWallbox app & portal
Voice Control:	Amazon Alexa and Google Assistant

ELECTRICAL SPECIFICATIONS

Models/ Rated Current:	40A 48A
Charging Power:	96kW 115kW
Power Input/ Connection:	NEMA 14-50 or Hardwired (40A) Hardwired (48A)
Rated Voltage AC ±10%:	240/208V (Level 2)
Configurable Current:	6A to rated current
Electrical Safety Certification:	UL 2594, UL 2231
EMC Compliance:	FCC Part 15 Class B
Environmental Rating:	NEMA Type 4 per UL 50E

Get **Pulsar Plus** and
start charging smarter



www.wallbox.com

Copyright 2020, Wallbox USA Inc.

wallbox 