



Ceiling Opening 5 3/8" Diameter

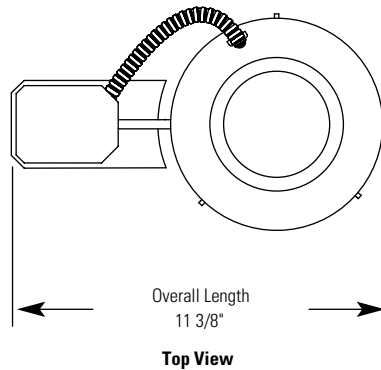

Overall Length
11 3/8"

Top View

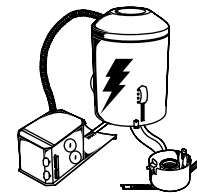

Frame-In Kit



Reflector Trim

Project: _____
 Location: _____
 Cat.No: _____
 Type: _____
 Lamps: _____ Qty: _____
 Notes: _____

5" Aperture: Complete Fixture consists of Reflector Trim & Frame-In Kit. Select each separately.

Frame-In Kit	Reflector Trims — See Individual Reflector Trim Specification Sheets								
	Open Downlight					Adjustable		Enclosed Diffuser	Open Wet Location
Reflector	Cone	Satin Cone	Baffles	Basic White	Eyeball				
1004ICR	1045	1012	1008	1005	1071	1022	1021*	1081CD	1085*
	1046	1012NM	1008NM	1005NM		1022WH			
	1046CD	1013	1010	1005BNM		1082			
		1013BK	1010NM	1005WH		1088			
		1013WH		1076		1088GW			
		1013NM		1076WH		1088WH			
		1013CD							
		1013BKNM							
		1013CDNM							

* For Non-IC applications only.

Features

- Housing:** .032 (#20 ga.) Aluminum. U.L. listed convertible IC/NON-IC. Integral retaining spring secures housing to ceilings up to 2" thick. Removable for access to junction box and ceiling plenum.
- Junction Box:** 2 1/2" X 2 1/2" X 3 1/2" (21 cu. in.). .032 (#22 ga.) galvanized steel. U.L. listed for 90°C supply wire. Integral cable clamps permit attachment of non-metallic (#12 or #14 ga.) Romex® cable without tools or additional connectors.
- Socket Housing:** Impact extruded aluminum or galvanized steel. Attached trim retaining spring secures trim to any height on housing wall.
- Socket:** Porcelain medium base; nickel plated screw shell. Pre-wired with #18 ga. SF1 (300 VOLT 200°C) leads to junction box.
- Thermal Protector:** Meets NEC and U.L. requirements. Located inside housing.

1004ICR Lytening INC 5"

IC/Non-IC Remodeler

Options & Accessories

AirSeal® Kit: LAS56R

Labels

UL (Type IC/NON-IC Convertible; Suitable for Damp Locations).

Romex® is a registered trademark of General Cable Industries Inc.

