



DL-LED24

LED Dock Light



SPECIFICATIONS*

Watts	23.83
Lumens	2818.5
Efficacy	118.28
Replaces Up To	100W MH
Colour Temp	4K
Operating Temp	-30°C to 40°C
Voltage	120V
LED Life	100,000 Hours
Housing Material	Die Cast Aluminum
Lens Material	Polycarbonate
Power Factor	0.9857
Total Harmonic Distortion	13.1
Mounting	Yoke/Arm



DESCRIPTION

The DL-LED24 is a dock light with an adjustable head that replaces a 100W metal halide fixture. The fixture has air flow fins at the back for heat dissipation. The DL-LED 24 is suitable for outdoor locations and is rated IP66.

APPLICATIONS



Loading Docks

FEATURES

- Die cast aluminum housing with impact resistant clear polycarbonate lens.
- Retrofits to most existing dock light arms.
- Steel yoke can be rotated 180° to direct light wherever needed.


MODEL SPECIFICATIONS

MODEL DESCRIPTION	VOLTAGE (V)	INPUT POWER (W)	LIGHT OUTPUT	EFFICACY (Lm/W)	THD	PF	CCT (K)	CRI
DL-LED24-A-4K-N-XXX-LH	120	23.83	2818.5	118.28	13.1	0.9857	4000	72.2

LEGEND

- A - 120V
- 4K - 4000K
- XXX - HOUSING FINISH
- LH - LIGHT HEAD


DIMENSIONS

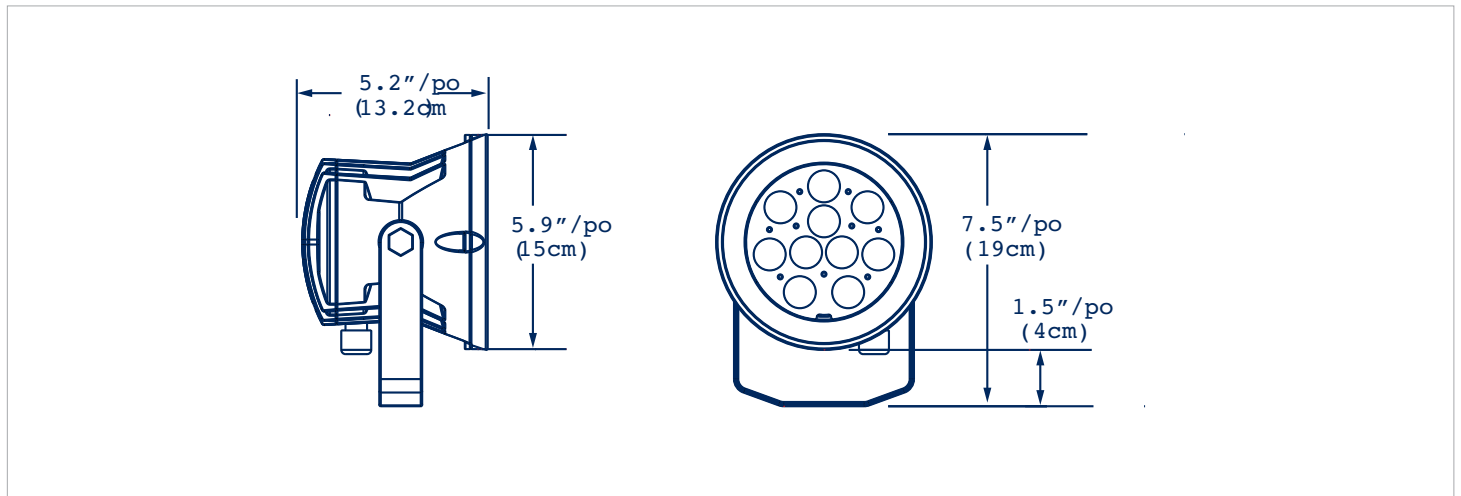

ACCESSORIES (SOLD SEPARATELY)

Extendable Arms (42" and 60") Optional

- 1 1/2" square steel tubes with 3-conductor AC 6' cord
- On/off rocker switch and receptacle
- 42" (16" + 24") and 60" (34"+24") arm length

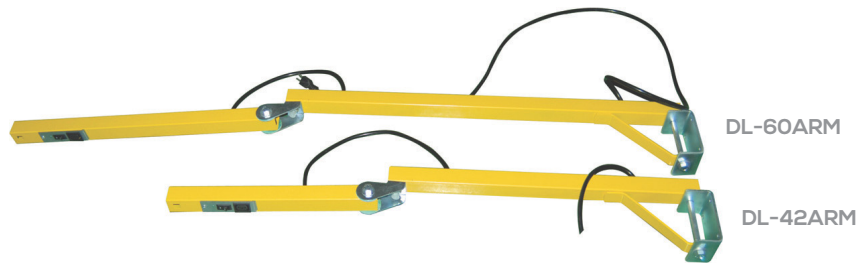

ORDERING GUIDE

DL					
WATTS	VOLTAGE	COLOUR TEMP.	FINISH	MOUNTING	
LED24	A - 120V*	4K - 4000K*	YLW - YELLOW*	LH - LIGHT HEAD	

*Standard Configuration.

ACCESSORIES ORDERING GUIDE

CHECK THE ACCESSORIES YOU WISH TO ORDER:

DL-42-ARM - 42" ARTICULATED ARM

DL-60-ARM - 60" ARTICULATED ARM