



Lithonia Basic Retrofit


LBR Series

- Easy install-from-below with mousetrap springs and optional quick disconnect plugs
- Switchable CCTs and lumens
- Aperture sizes including 4", 6", and 8", with available goof rings to fit 5", 7", 9", and 10" ceiling cutouts
- New construction frame available
- Glare control with deep source regression
- Up to 114 LPW
- Available with battery pack and optional wet location listed
- Configurations available in Contractor Select™
- MVOLT (120-277V) 0-10V phase dimming (120V) all-in-one driver (DALI driver also available)



Make the Switch with Retrofit.

Switchable CCTs & Lumens

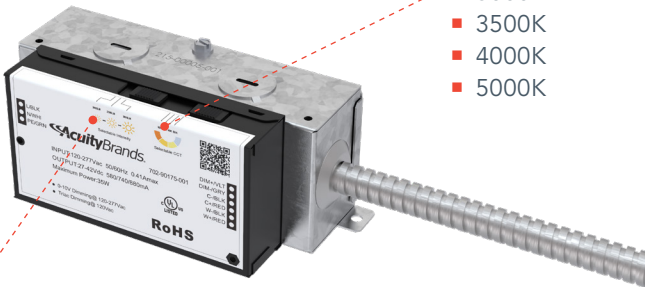


CCTs

- 3000K
- 3500K
- 4000K
- 5000K

Lumen Packages

- 500, 750, 1000LM
- 1000, 1500, 2000LM
- 2000, 2500, 3000LM

Deep Source Regression

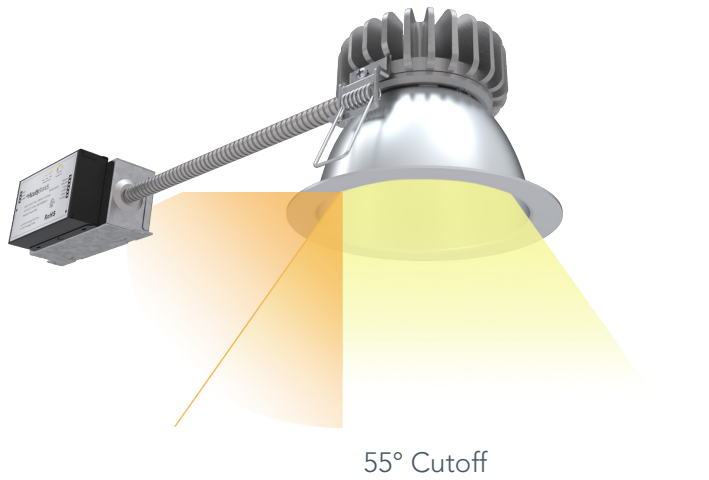

55° Cutoff

Options



Wallwash

Additional wallwash and square trims are available



Smash plates and goof rings available for extra flexibility



Available with new construction frame and quick disconnection options

Start Saving



Energy Savings
Reduce between 50-80% energy consumption compared to traditional sources



Low Labor Costs
Minimum install and cleanup time



Environmental Impact
Last up to 25 times longer than traditional sources

