



LBR Series


New Construction Downlight

- Switchable CCTs and lumens
- Aperture sizes including 4", 6", 8", and 10"
- Glare control with deep source regression
- Up to 114 LPW
- Available with battery pack, IOTA emergency transfer system (ETS), 347V step-down transformer and optional wet location (IP55) listed
- nLight® wired or wireless lighting controls and SensorSwitch™ JOT single room controls
- 10% and 1% dimming, MVOLT 120-277V, 0-10V and phase dimming in an all-in-one driver or a separate DALI driver



Make the Switch to LBR.

Switchable CCTs & Lumens

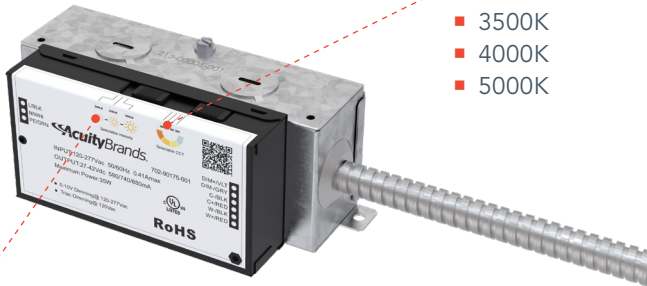


- CCTs
- 3000K
 - 3500K
 - 4000K
 - 5000K

Lumen Packages


- 500, 750, 1000LM
- 1000, 1500, 2000LM
- 2000, 2500, 3000LM
- 4000, 4500, 5000LM

Deep Source Regression

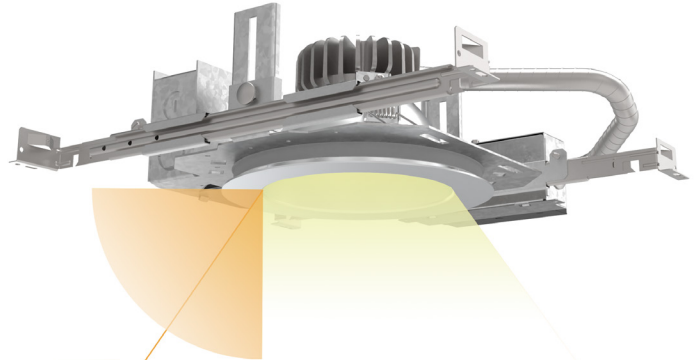

55° Cutoff

Options

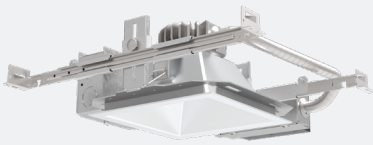

Square trims for 4" and 6" aperture sizes



Choose from multiple distribution options



[Retrofit and remodel options are available for renovation projects](#)



Lighting Controls

sensorswitch

SensorSwitch™ JOT is a wireless, app free solution for single room controls

nLIGHT

The nLight® platform offers wired or wireless networked lighting controls solution

Visit www.lithonia.com for more information