


**SKU:** GT-6

**UPC:** 0783669004892

**Features & Benefits:**

**Description:**Permaground Copper Ground Clamp, Conductor Range 250-2/0 Sol, 2 Conductors, Pipe Size 3/8in, Perpendicular Orientation, UL

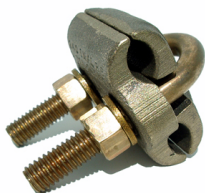

## Specs

### Additional Class Attributes

Connection	Mechanical
Number of Conductors	2
Number of Ports / Wireways	2
Wire Orientation	Perpendicular

### Conductor Ranges

Conductor Range AL Solid (Secondary, tap, load)	NA
Conductor Range AL Stranded (Primary, run, main, line)	250 kcmil - 2/0 Str
Conductor Range AL Stranded (Secondary, tap, load)	NA
Conductor Range CU Solid (Primary, run, main, line)	4/0 Sol - 2/0 Sol
Conductor Range CU Solid (Secondary, tap, load)	NA
Conductor Range CU Stranded (Primary, run, main, line)	250 kcmil - 2/0 Str
Conductor Range CU Stranded (Secondary, tap, load)	NA
Conductor Range AL Solid (Primary, run, main, line)	4/0 Sol - 2/0 Sol
NPS/IPS Pipe Size	3/8

### Dimensions

Drive Size Main	3/8
Drive Type Main	External Hex
Height (IN)	2.625
Height BX (IN)	6
Length (IN)	1.875
Weight (LB)	0.675
Weight BX (LB)	34.2396
Width (IN)	2.5
Width BX (IN)	7.5

### Material and Finish

Conductor Material	Copper
Connector Finish	NA
Insulation	NA
Material	Copper

## Additional Technical Specifications

Conductor Type	Solid
----------------	-------

## Bolt and Screw Sizes

Clamping Bolt Size	1/4
Number of Wire Binding Screws per Port	0
Wire Binding Screw Size	NA

## General

Bag Quantity	1
Carton Quantity Description	STD PACK QTY 50
Direct Burial	Yes
Dual Rated	No
NEMA Code	S-573-2
UPC Code	78366900489

## Testing Standards

CSA File Number	NA
Prop65 Compliance	This product is in compliance with Prop65. It is not known to contain any chemicals associated with this regulation
UL Control Number	8M24
UL / CULUS Specification	UL/cUL 467 Listed
UL File Number	E158587