

LED-HWB-24V-36W

36W Indoor LED Hardwire Box, 24V
Cabinet, Cove & Display

Job Information		
Project Name		Type
Location		
Quantity		Date
Contact/Phone		
Notes		

Features

Features & Benefits

- Class II power supply.
- Short-circuit protection.
- Over-current protection.
- Over-voltage protection.
- Open-circuit protection.
- Constant voltage.

AC Input Details

- AC input voltage range: 100-240V.
- AC input current: 1500mA.
- Input frequency range: 50/60Hz.
- No load power consumption: <0.5W.
- Leakage current: <0.25mA.

DC Output Details

- DC voltage: 24V.
- DC current: 1500mA.
- Working efficiency:
 - * > 83% @ 115V AC.
 - * > 83% @ 230V AC.

Environmental Requirements

- Working temperature: 0-40%
- Operating humidity: 5-90% RH.
- Storage humidity: 5-90% RH.
- Suitable for indoor use only.

Linkage

- The LED driver is equipped with a 2.1 DC jack and 55" of 18AWG SPT cord on the output side for linking 24V LED tape and strip lights.
- Provided with push-in wire connectors for fast and easy wiring.

Construction

- 20 gauge painted steel box with dedicated compartment for hard-wiring (120V).
- Eight 7/8" knockouts for maximum flexibility in positioning and in-line installation.

Compatibility

Compatible with all Liteline® 24 volt LED lighting products.

SPECIFICATION	
Application	Undercabinet
Approved Location	Dry
Certification	cULus listed (driver)
Classification	Class 2
Colour	WH
Dimming	No
Link Connector	DC 2.1
Max. Op. Temp.	40°C (104°F)
Min. Start Temp.	0°C (32°F)
Power Factor	>0.5
Power Supply Type	Constant Voltage
Input	100-240V, 50/60Hz, 1.5A max
Output	24V DC, 1.5A
Warranty	3 Years
Wattage	36W




Description

LED-HWB-24V-36W is a Class 2, constant voltage, 24V, 36W max. LED driver with hardwire box; for use with 24V LED lighting products. Suitable for indoor use only.



Notes: Accessories should be ordered separately. For additional options please consult your Liteline representative. Due to our continued efforts to improve our products, product specifications are subject to change without notice.

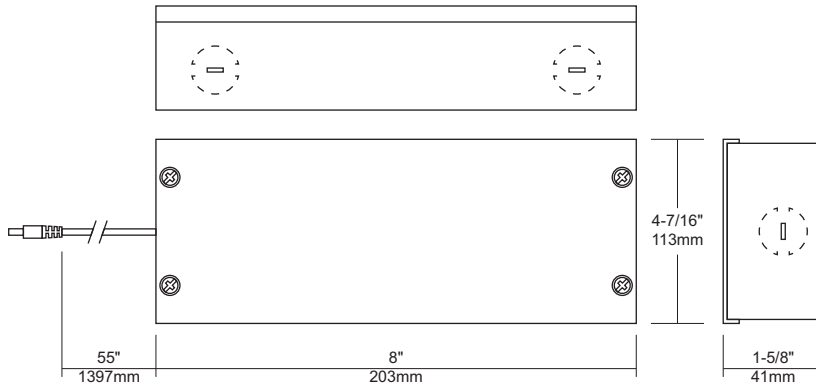

Ordering Guide



LED-HWB-24V-36W
36W indoor LED hardwire box, 24V.

Accessories



LED-SP-4
Optional harness for up to 4 runs, 24V.

