

## 15 and 20 Ampere, 125 Volts


**IP20**  
SUITABILITY




**15A 125V**  
NEMA 5-15R  
UL CSA  
0.5 HP




**20A 125V**  
NEMA 5-20R  
UL CSA  
1 HP

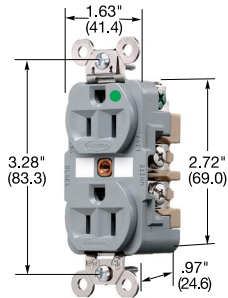


**HBL8200GY**

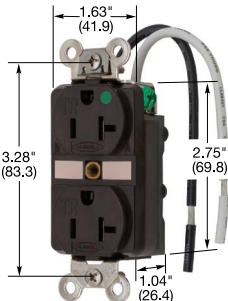


**HBL8300SGA**

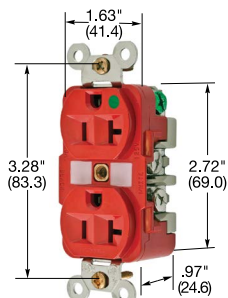

**HBL8300RMRI**

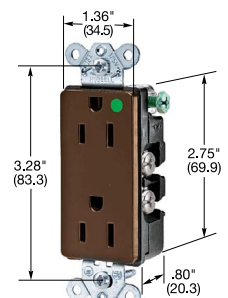

**HBL2172**

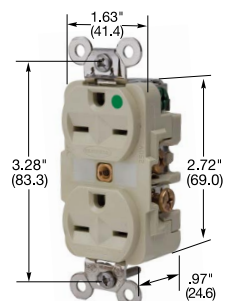

**HBL8600I**

Dimensions in Inches (mm)

### HBL® Extra Heavy Duty Max Hospital Grade Receptacles

#### Duplex

Flush, thermoplastic polyester face, back and side wired.

Color	Catalog Number
Black	<b>HBL8200BK</b>
Blue	-
Brown	<b>HBL8200</b>
Gray	<b>HBL8200GY</b>
Ivory	<b>HBL8200I</b>
Light Almond	<b>HBL8200LA</b>
Red	<b>HBL8200RED</b>
White	<b>HBL8200W</b>

Catalog Number
-
<b>HBL8300BL</b>
<b>HBL8300</b>
<b>HBL8300GY</b>
<b>HBL8300I</b>
<b>HBL8300LA</b>
<b>HBL8300RED</b>
<b>HBL8300W</b>

Flush, LED illuminated face, back and side wired.

Color	Catalog Number
Gray	<b>HBL8200ILGY</b>
Ivory	<b>HBL8200ILI</b>
Red	<b>HBL8200ILR</b>
White	<b>HBL8200ILW</b>

Catalog Number
<b>HBL8300ILGY</b>
<b>HBL8300ILI</b>
<b>HBL8300ILR</b>
<b>HBL8300ILW</b>



Tamper-Resistant receptacle with wire leads. Complies with requirements of NEC® article 517-18(c).

Color	Catalog Number
Brown	<b>HBL8200SGA</b>
Gray	<b>HBL8200SGGYA</b>
Ivory	<b>HBL8200SGIA</b>
Light Almond	-
Red	<b>HBL8200SGRA</b>
White	<b>HBL8200SGWA</b>

Catalog Number
<b>HBL8300SGA</b>
<b>HBL8300SGGYA</b>
<b>HBL8300SGIA</b>
<b>HBL8300SGLA</b>
<b>HBL8300SGRA</b>
<b>HBL8300SGWA</b>

Isolated ground<sup>A</sup>

Color	Catalog Number
Orange	<b>IG8200</b>
Red	<b>IG8200R</b>

Catalog Number
<b>IG8300</b>
<b>IG8300R</b>

#### MRI Receptacle, Duplex

MRI receptacle, flush, thermoplastic polyester face, back and side wired. 100% non-ferrous.

Color	Catalog Number
Ivory	<b>HBL8200IMRI</b>
Light Almond	<b>HBL8200LAMRI</b>
Red	<b>HBL8200RMRI</b>
White	<b>HBL8200WMRI</b>

Catalog Number
<b>HBL8300IMRI</b>
<b>HBL8300LAMRI</b>
<b>HBL8300RMRI</b>
<b>HBL8300WMRI</b>

#### Slender/Compact, Duplex

Flush, thermoplastic polyester face, back, and side wired, Fed. Spec. verified.

Color	Catalog Number
Brown	<b>HBL8200H</b>
Gray	<b>HBL8200HG</b>
Green	-
Ivory	<b>HBL8200HI</b>
Light Almond	<b>HBL8200HLA</b>
Red	<b>HBL8200HRED</b>
White	<b>HBL8200HW</b>

Catalog Number
<b>HBL8300H</b>
<b>HBL8300HG</b>
<b>HBL8300HGN</b>
<b>HBL8300HI</b>
<b>HBL8300HLA</b>
<b>HBL8300HRED</b>
<b>HBL8300HW</b>

#### Style Line® Decorator\*

Flush, nylon face, back and side wired.

Color	Catalog Number
Brown	<b>HBL2172</b>
Gray	<b>HBL2172GY</b>
Ivory	<b>HBL2172I</b>
Red	<b>HBL2172R</b>
White	<b>HBL2172WA</b>

Catalog Number
<b>HBL2182</b>
<b>HBL2182GY</b>
<b>HBL2182I</b>
<b>HBL2182R</b>
<b>HBL2182WA</b>

Isolated ground<sup>A</sup>

Color	Catalog Number
Ivory	-
Orange	-
White	-

Catalog Number
<b>IG2182I</b>
<b>IG2182</b>
<b>IG2182WA</b>

#### Single

Flush, nylon face, back and side wired, Fed. Spec. verified.

Color	Catalog Number
Brown	<b>HBL8210</b>
Gray	<b>HBL8210GY</b>
Ivory	<b>HBL8210I</b>
Red	<b>HBL8210R</b>
White	<b>HBL8210W</b>

Catalog Number
<b>HBL8310</b>
<b>HBL8310GY</b>
<b>HBL8310I</b>
<b>HBL8310R</b>
<b>HBL8310W</b>

Panel mount on 1.94 in. (49.2) centers.

Color	Catalog Number
Brown	<b>HBL8284</b>
Ivory	<b>HBL8284I</b>

Catalog Number
-
<b>HBL8384I</b>

Isolated ground<sup>A</sup>

Color	Catalog Number
Orange	<b>IG8210</b>

Catalog Number
<b>IG8310</b>

### HBL® Extra Heavy Duty Max Hospital Grade Receptacles

#### 250 Volts Duplex

Flush, thermoplastic polyester face, back and side wired.

Color	Catalog Number
Brown	<b>HBL8600</b>
Ivory	<b>HBL8600I</b>

Catalog Number
<b>HBL8400</b>
<b>HBL8400I</b>

Note: <sup>A</sup>See section N for additional information on isolated ground devices.

\*Not Fed. Spec. Listed.

See pages A-47 and A-48 for accessories. See section O for wallplates.

See page Tech-10 for Tamper-Resistant description.

NEC® is a registered trademark of the National Fire Protection Association (NFPA).