




ITEM NUMBER	CATALOG NUMBER	TENSILE STRENGTH LB / N	MATERIAL	COLOR	FEATURE	BUNDLE DIA. MIN. IN [MM]	BUNDLE DIA. MAX. IN [MM]	L IN [MM]	W IN [MM]	MIN. INSTALL TEMP. °F / °C	MIN. OPER. TEMP. °F / °C	MAX. OPER. TEMP. °F / °C	PKG. QTY.	CTN. QTY.
10023292	CT18075C	18 / 80	NYLON 6/6	NATURAL	STANDARD	.06 [2]	.87 [22]	4.12 [105]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	10000
10023303	CT18075M	18 / 80	NYLON 6/6	NATURAL	STANDARD	.06 [2]	.87 [22]	4.12 [105]	.09 [2]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023304	CT18125C	18 / 80	NYLON 6/6	NATURAL	STANDARD	.06 [2]	1.50 [38]	6.18 [157]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	10000
10023307	CT18125C3	18 / 80	NYLON 6/6	ORANGE	STANDARD	.06 [2]	1.50 [38]	6.18 [157]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	10000
10023308	CT18125C4	18 / 80	NYLON 6/6	YELLOW	STANDARD	.06 [2]	1.50 [38]	6.18 [157]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	10000
10023315	CT18125M	18 / 80	NYLON 6/6	NATURAL	STANDARD	.06 [2]	1.50 [38]	6.18 [157]	.09 [2]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023316	CT18200C	18 / 80	NYLON 6/6	NATURAL	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	10000
10023317	CT18200C1	18 / 80	NYLON 6/6	BROWN	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	5000
10023318	CT18200C2	18 / 80	NYLON 6/6	RED	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	5000
10023321	CT18200C5	18 / 80	NYLON 6/6	GREEN	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	5000
10023322	CT18200C6	18 / 80	NYLON 6/6	BLUE	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	5000
10023327	CT18200M	18 / 80	NYLON 6/6	NATURAL	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023328	CT18075C00	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	.87 [22]	4.12 [105]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	10000
10023329	CT18075M00	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	.87 [22]	4.12 [105]	.09 [2]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023334	CT18075C0	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	.87 [22]	4.12 [105]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	10000
10023335	CT18075M0	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	.87 [22]	4.12 [105]	.09 [2]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023336	CT18125C0	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.50 [38]	6.18 [157]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	10000
10023337	CT18125M0	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.50 [38]	6.18 [157]	.09 [2]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023338	CT18200C0	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	100	10000
10023339	CT18200M0	18 / 80	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	2.10 [53]	8.18 [208]	.09 [2]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023669	CT18075MH4C	18 / 80	NYLON 6/6	NATURAL	MTG HOLE	.12 [3]	.75 [19]	4.62 [118]	.09 [2]	32 / 0	32 / 0	185 / 85	100	1000
10023670	CT18075MH4M	18 / 80	NYLON 6/6	NATURAL	MTG HOLE	.12 [3]	.75 [19]	4.62 [118]	.09 [2]	32 / 0	32 / 0	185 / 85	1000	1000
10023689	CT18075IDC	18 / 80	NYLON 6/6	NATURAL	IDENTIFICATION	.21 [6]	.82 [22]	4.03 [103]	.1 [2]	14 / -10	-40 / -40	185 / 85	100	5000
50027390	CTHS18075M	18 / 80	NYLON 6/6 HEAT STABILIZED	HS UV BLK	STANDARD	.06 [2]	.87 [22]	4.12 [105]	.09 [2]	-4 / -20	-40 / -40	257 / [125]	1000	10000

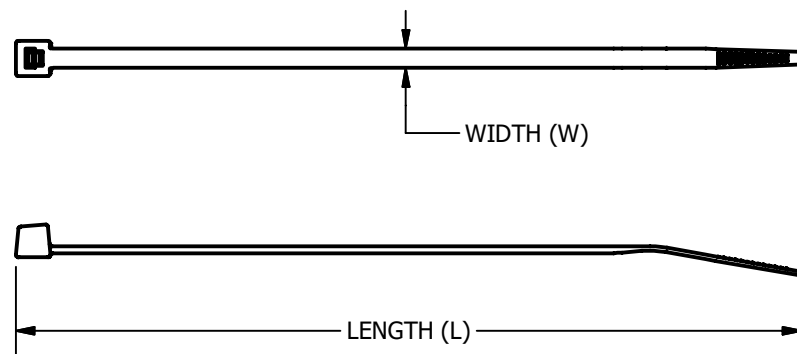

STANDARD

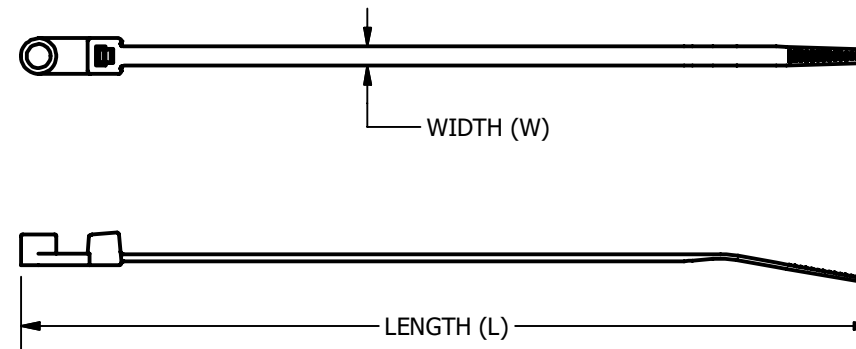

MTG HOLE

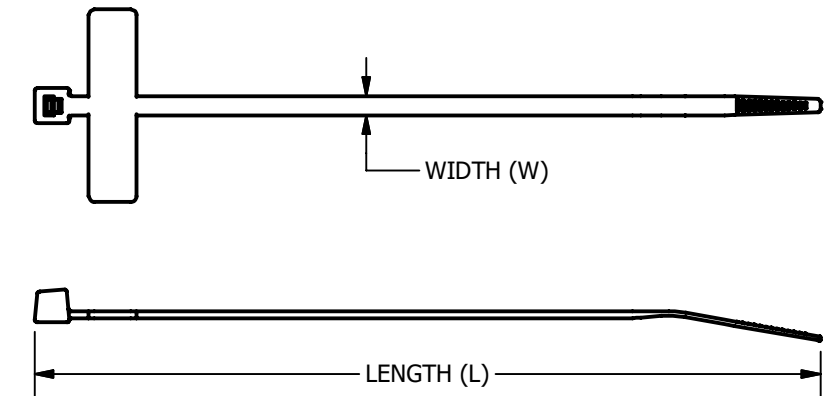

IDENTIFICATION


**NOTES:**

- DIMENSIONS IN BRACKETS [ ] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED AND ARE FOR REFERENCE ONLY.


REV	DATE	DESCRIPTION	EC	BY	C'H'K.
G	03/28/2022	PKG QTY UPDATED AS PER MU	220328018511	WP	YR

TO ORDER BURNDY® PRODUCTS CALL		UNIRAP™	
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)		ITEM NO: SEE TABLE CAT. NO: SEE TABLE	
CANADA: 1-800-387-6487		DRAWN BY: D DHEENA 03-08-2017 CHECKER: K BOUTIN 04-05-2017 DSN APRVL: A MONTMINY 03-29-2017 MFG APRVL: -- QA APRVL: B POST 03-20-2017 MKT APRVL: K BOUTIN 04-05-2017 PROD FAM: --	
FOR PRODUCT INFO: <a href="http://www.burndy.com">http://www.burndy.com</a>			
		DRAWING NO: 50080813 REV: G	
		PROJECT #: -- SIZE: B DOCUMENT TYPE: SALES REL LEVEL: Released	
		SHEET 1 OF 5	


ITEM NUMBER	CATALOG NUMBER	TENSILE STRENGTH LB / N	MATERIAL	COLOR	FEATURE	BUNDLE DIA. MIN. IN [MM]	BUNDLE DIA. MAX. IN [MM]	L IN [MM]	W IN [MM]	MIN. INSTALL TEMP. °F / °C	MIN. OPER. TEMP. °F / °C	MAX. OPER. TEMP. °F / °C	PKG. QTY.	CTN. QTY.
10023340	CT30125C	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	1.40 [36]	5.84 [148]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	10000
10023351	CT30125M	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	1.40 [36]	5.84 [148]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023388	CT30125C00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.40 [36]	5.84 [148]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	10000
10023389	CT30125M00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.40 [36]	5.84 [148]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023673	CT30125MH8C	40 / 180	NYLON 6/6	NATURAL	MTG HOLE	.11 [3]	1.40 [36]	6.12 [155]	.14 [4]	14 / -10	-40 / -40	185 / 85	100	10000
10023674	CT30125MH8M	40 / 180	NYLON 6/6	NATURAL	MTG HOLE	.11 [3]	1.40 [36]	6.12 [155]	.13 [3]	14 / -10	-40 / -40	185 / 85	1000	10000
10023676	CT30125MH8M0	40 / 180	NYLON 6/6	UV BLACK	MTG HOLE	.11 [3]	1.40 [36]	6.12 [155]	.13 [3]	14 / -10	-40 / -40	185 / 85	1000	10000
10023352	CT40200C	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	2.37 [60]	8.87 [225]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	10000
10023363	CT40200M	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	2.37 [60]	8.87 [225]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023364	CT40300C	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	3.37 [86]	10.96 [278]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	5000
10023375	CT40300M	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	3.37 [86]	10.96 [278]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023376	CT40400C	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	5000
10023387	CT40400M	40 / 178	NYLON 6/6	NATURAL	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023390	CT30125C0	40 / 178	NYLON 6/6	UVBLACK	STANDARD	.06 [2]	1.40 [36]	5.84 [148]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	10000
10023391	CT30125M0	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.40 [36]	5.84 [148]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023392	CT40200C00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	2.37 [60]	8.87 [225]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	10000
10023393	CT40200M00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	2.37 [60]	8.87 [225]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023394	CT40300C00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.37 [86]	10.96 [278]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	5000
10023395	CT40300M00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.37 [86]	10.96 [278]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023396	CT40400C00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	5000
10023397	CT40400M00	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023398	CT40200C0	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	2.37 [60]	8.87 [225]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	10000
10023399	CT40200M0	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	2.37 [60]	8.87 [225]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023400	CT40300C0	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.37 [86]	10.96 [278]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	5000
10023401	CT40300M0	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.37 [86]	10.96 [278]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023402	CT40400C0	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.14 [4]	-4 / -20	-40 / -40	185 / 85	100	5000
10023403	CT40400M0	40 / 178	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.14 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
50027391	CTHS40125M	40 / 178	NYLON 6/6 HEAT STABILIZED	HS UV BLACK	STANDARD	.06 [2]	1.40 [36]	5.84 [148]	.14 [4]	-4 / -20	-40 / -40	257 / [125]	1000	10000

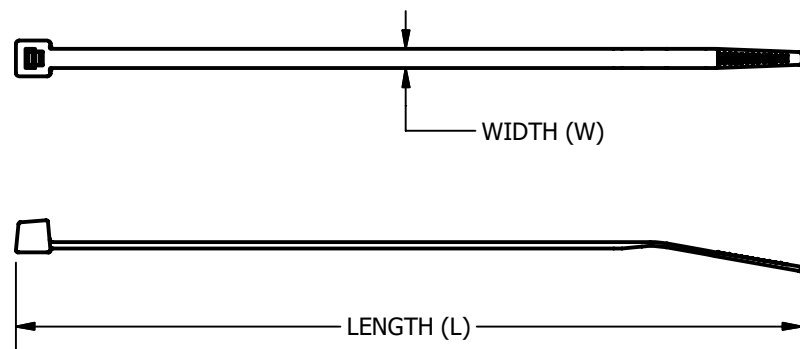

STANDARD

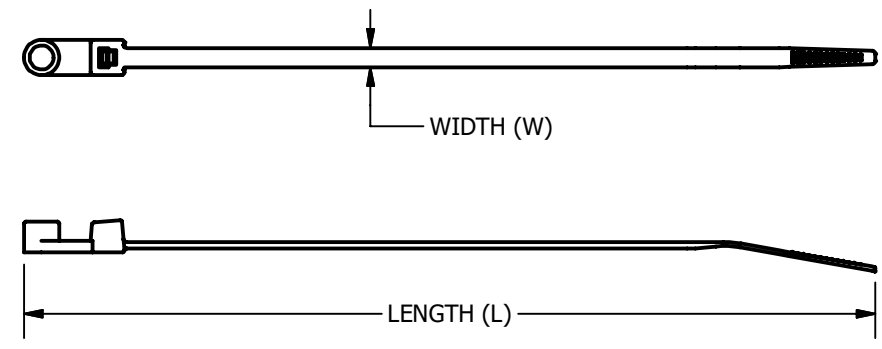

MTG HOLE

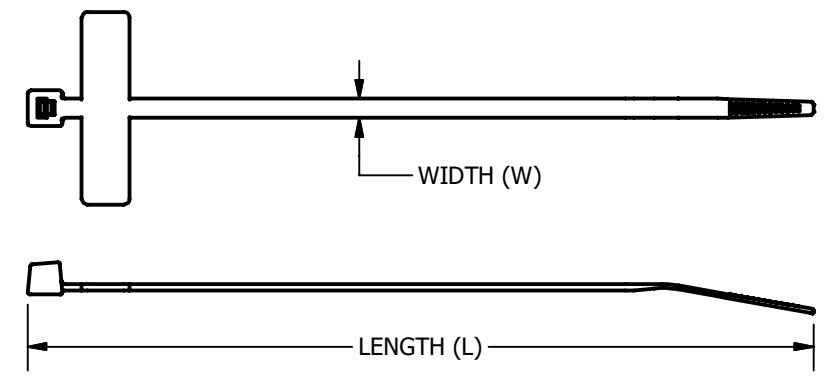

IDENTIFICATION


**NOTES:**

1. DIMENSIONS IN BRACKETS [ ] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED AND ARE FOR REFERENCE ONLY.


REV	DATE	DESCRIPTION	EC	BY	C'H'K.
G	03/28/2022	PKG QTY UPDATED AS PER MU	220328018511	WP	YR

TO ORDER BURNDY® PRODUCTS CALL		UNIRAP™	
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)		ITEM NO: SEE TABLE CAT. NO: SEE TABLE	
CANADA: 1-800-387-6487		DRAWN BY: D DHEENA 03-08-2017 CHECKER: K BOUTIN 04-05-2017 DSN APRVL: A MONTMINY 03-29-2017 MFG APRVL: -- QA APRVL: B POST 03-20-2017 MKT APRVL: K BOUTIN 04-05-2017	
FOR PRODUCT INFO: <a href="http://www.burndy.com">http://www.burndy.com</a>			
		PROJ. #:	SIZE
		DOCUMENT TYPE: SALES	50080813
		REL LEVEL: Released	B
		DRAWING NO	REV
			G
		SHEET 2 OF 5	


ITEM NUMBER	CATALOG NUMBER	TENSILE STRENGTH LB / N	MATERIAL	COLOR	FEATURE	BUNDLE DIA. MIN. IN [MM]	BUNDLE DIA. MAX. IN [MM]	L IN [MM]	W IN [MM]	MIN. INSTALL TEMP. °F / °C	MIN. OPER. TEMP. °F / °C	MAX. OPER. TEMP. °F / °C	PKG. QTY.	CTN. QTY.
10023404	CT50175C	50 / 222	NYLON 6/6	NATURAL	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	10000
10023405	CT50175C1	50 / 222	NYLON 6/6	BROWN	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023406	CT50175C2	50 / 222	NYLON 6/6	RED	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023407	CT50175C3	50 / 222	NYLON 6/6	ORANGE	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023408	CT50175C4	50 / 222	NYLON 6/6	YELLOW	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023409	CT50175C5	50 / 222	NYLON 6/6	GREEN	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023410	CT50175C6	50 / 222	NYLON 6/6	BLUE	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023411	CT50175C7	50 / 222	NYLON 6/6	PURPLE	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023412	CT50175C8	50 / 222	NYLON 6/6	GRAY	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023413	CT50175C10	50 / 222	NYLON 6/6	WHITE	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023415	CT50175M	50 / 222	NYLON 6/6	NATURAL	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
10043245	CT50175M1	50 / 222	NYLON 6/6	BROWN	STANDARD	.06 [2]	1.87 [47]	7.56 [1.92]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
10033460	CT50175M2	50 / 222	NYLON 6/6	RED	STANDARD	.06 [2]	1.87 [47]	7.56 [1.92]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
10045324	CT50175M3	50 / 222	NYLON 6/6	ORANGE	STANDARD	.06 [2]	1.87 [47]	7.56 [1.92]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
10045322	CT50175M4	50 / 222	NYLON 6/6	YELLOW	STANDARD	.06 [2]	1.87 [47]	7.56 [1.92]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
10087392	CT50175M5	50 / 222	NYLON 6/6	GREEN	STANDARD	.06 [2]	1.87 [47]	7.56 [1.92]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
10031723	CT50175M6	50 / 222	NYLON 6/6	BLUE	STANDARD	.06 [2]	1.87 [47]	7.56 [1.92]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
50101514	CT50175M8	50 / 222	NYLON 6/6	GRAY	STANDARD	.06 [2]	1.87 [47]	7.56 [1.92]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023416	CT50300C	50 / 222	NYLON 6/6	NATURAL	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023418	CT50300C2	50 / 222	NYLON 6/6	RED	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023427	CT50300M	50 / 222	NYLON 6/6	NATURAL	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023428	CT50400C	50 / 222	NYLON 6/6	NATURAL	STANDARD	.06 [2]	4.00 [102]	14.5 [368.3]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023430	CT50400C2	50 / 222	NYLON 6/6	RED	STANDARD	.06 [2]	4.00 [102]	14.5 [368.3]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023431	CT50400C3	50 / 222	NYLON 6/6	ORANGE	STANDARD	.06 [2]	4.00 [102]	14.5 [368.3]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023439	CT50400M	50 / 222	NYLON 6/6	NATURAL	STANDARD	.06 [2]	4.00 [102]	14.5 [368.3]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023440	CT50175C00	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	10000
10023441	CT50175M00	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023442	CT50300C00	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023443	CT50300M00	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023444	CT50400C00	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.5 [368.3]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023445	CT50400M00	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.5 [368.3]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023446	CT50175C0	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	10000
10023447	CT50175M0	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023448	CT50300C0	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023449	CT50300M0	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023450	CT50400C0	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.5 [368.3]	.18 [5]	-4 / -20	-40 / -40	185 / 85	100	5000
10023451	CT50400M0	50 / 222	NYLON 6/6	UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.5 [368.3]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	5000

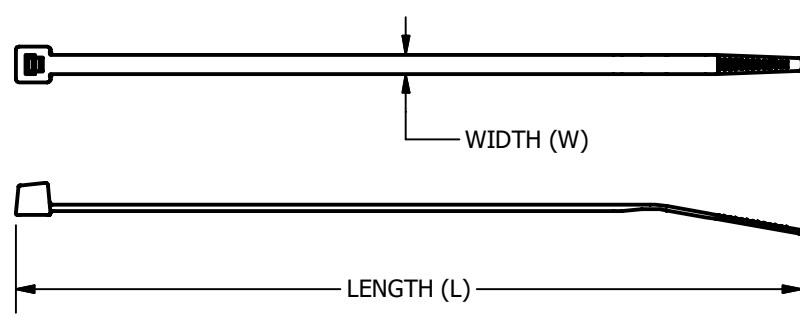

**STANDARD**

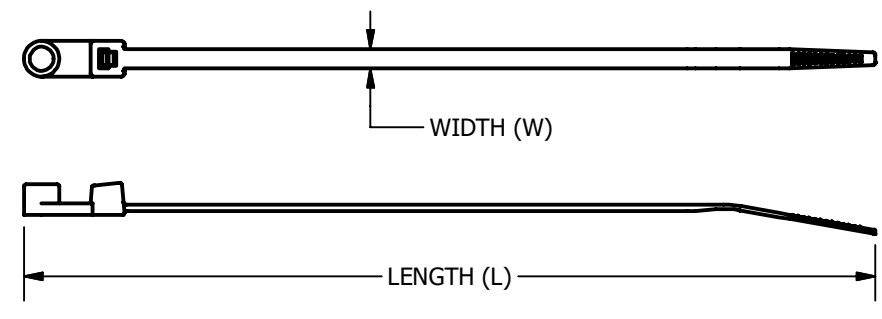

**MTG HOLE**

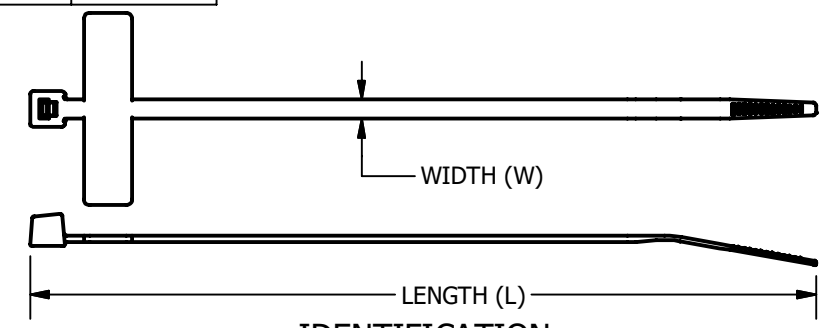

**IDENTIFICATION**

**NOTES:**

1. DIMENSIONS IN BRACKETS [ ] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED AND ARE FOR REFERENCE ONLY.


REV	DATE	DESCRIPTION	EC	BY	C'H'K.
G	03/28/2022	PKG QTY UPDATED AS PER MU	220328018511	WP	YR

TO ORDER BURNDY® PRODUCTS CALL  
 UNITED STATES  
 1-800-346-4175 (LONDONDERRY, NH)  
 CANADA:  
 1-800-387-6487  
 FOR PRODUCT INFO: <http://www.burndy.com>


UNIRAP™	
ITEM NO: SEE TABLE	
CAT. NO: SEE TABLE	
DRAWN BY: D DHEENA	03-08-2017
CHECKER: K BOUTIN	04-05-2017
DSN APRVL: A MONTMINY	03-29-2017
MFG APRVL: --	
QA APRVL: B POST	03-20-2017
MKT APRVL: K BOUTIN	04-05-2017
PROD FAM: --	
PROJECT #: --	SIZE
DOCUMENT TYPE: SALES	B
REL LEVEL: Released	
DRAWING NO	REV
50080813	G
SHEET 3 OF 5	




ITEM NUMBER	CATALOG NUMBER	TENSILE STRENGTH LB / N	MATERIAL	COLOR	FEATURE	BUNDLE DIA. MIN. IN [MM]	BUNDLE DIA. MAX. IN [MM]	L IN [MM]	W IN [MM]	MIN. INSTALL TEMP. °F / °C	MIN. OPER. TEMP. °F / °C	MAX. OPER. TEMP. °F / °C	PKG. QTY.	CTN. QTY.
10023657	CT50175PMC	49 / 220	NYLON 6/6	NATURAL	PUSH MOUNT	.13 [4]	1.97 [50]	7.99 [202]	.18 [5]	14 / -10	-40 / -40	185 / 85	100	5000
10023661	CT50175PMC0	49 / 220	NYLON 6/6	UV BLACK	PUSH MOUNT	.13 [4]	1.97 [50]	7.99 [202]	.18 [5]	14 / -10	-40 / -40	185 / 85	100	5000
10023677	CT50175MH10C	50 / 222	NYLON 6/6	NATURAL	MTG HOLE	.06 [2]	1.87 [48]	8.00 [203]	.17 [4]	-4 / -20	-40 / -40	185 / 85	100	5000
10023678	CT50175MH10M	50 / 222	NYLON 6/6	NATURAL	MTG HOLE	.06 [2]	1.87 [48]	8.00 [203]	.17 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
10023679	CT50175MH10C0	50 / 222	NYLON 6/6	UVBLACK	MTG HOLE	.06 [2]	1.87 [48]	8.00 [203]	.17 [4]	-4 / -20	-40 / -40	185 / 85	100	5000
10023680	CT50175MH10M0	50 / 222	NYLON 6/6	UV BLACK	MTG HOLE	.06 [2]	1.87 [48]	8.00 [203]	.17 [4]	-4 / -20	-40 / -40	185 / 85	1000	5000
50101399	CT50200MH10M0	50 / 222	NYLON 6/6	UV BLACK	MTG HOLE	.18 [5]	2.00 [51]	8.70 [221]	.30 [8]	-4/-20	-40/-40	185/85	1000	1000
10023681	CT50400MH10C	50 / 222	NYLON 6/6	NATURAL	MTG HOLE	.06 [2]	4.00 [102]	14.50 [368]	.17 [4]	-4 / -20	-40 / -40	185 / 85	100	5000
10023683	CT50400MH10C0	50 / 222	NYLON 6/6	UVBLACK	MTG HOLE	.06 [2]	4.00 [102]	14.50 [368]	.17 [4]	-4 / -20	-40 / -40	185 / 85	100	5000
10023691	CT50175IDC	49 / 220	NYLON 6/6	NATURAL	IDENTIFICATION	.49 [13]	2.00 [51]	7.50 [191]	.18 [5]	14 / -10	-40 / -40	185 / 85	100	5000
10023692	CT50175ID2L	50 / 222	NYLON 6/6	NATURAL	IDENTIFICATION	.37 [10]	1.75 [45]	7.40 [188]	.18 [5]	32 / 0	32 / 0	185 / 85	50	1000
10023693	CT50175ID3L	50 / 222	NYLON 6/6	NATURAL	IDENTIFICATION	.37 [10]	1.75 [45]	7.40 [188]	.18 [5]	32 / 0	32 / 0	185 / 85	50	1000
10023829	CT50175M02	50 / 222	NYLON 6/6	UV RED	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	10000
10023830	CT50400M02	50 / 222	NYLON 6/6	UV RED	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.18 [5]	-4 / -20	-40 / -40	185 / 85	1000	5000
50027392	CTHS50700M	50 / 222	NYLON 6/6 HEAT STABILIZED	HS UV BLACK	STANDARD	.06 [2]	1.87 [47]	7.56 [192]	.18 [5]	-4 / -20	-40 / -40	257 / 125	1000	10000
50027393	CTHS50300M	50 / 222	NYLON 6/6 HEAT STABILIZED	HS UV BLACK	STANDARD	.06 [2]	3.00 [76]	11.25 [286]	.18 [5]	-4 / -20	-40 / -40	257 / 125	1000	5000
50027394	CTHS50400M	50 / 222	NYLON 6/6 HEAT STABILIZED	HS UV BLACK	STANDARD	.06 [2]	4.00 [102]	14.25 [362]	.18 [5]	-4 / -20	-40 / -40	257 / 125	1000	5000
10023452	CT120200L	120 / 534	NYLON 6/6	NATURAL	STANDARD	.18 [5]	2.00 [51]	8.70 [221]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	3000
10023463	CT120200D	120 / 534	NYLON 6/6	NATURAL	STANDARD	.18 [5]	2.00 [51]	8.70 [221]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	3000
10023464	CT120300L	120 / 534	NYLON 6/6	NATURAL	STANDARD	.18 [5]	3.00 [76]	12.00 [305]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	2000
10023475	CT120300D	120 / 534	NYLON 6/6	NATURAL	STANDARD	.18 [5]	3.00 [76]	12.00 [305]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	2000
10023476	CT120400L	120 / 534	NYLON 6/6	NATURAL	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	2000
10023487	CT120400D	120 / 534	NYLON 6/6	NATURAL	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	2000
50034735	CT120800L	120 / 534	NYLON 6/6	NATURAL	STANDARD	.18 [5]	9.00 [229]	30.87 [784]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	500
10023500	CT120400L00	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	2000
10023501	CT120400D00	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	2000
50034736	CT120800L00	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	9.00 [229]	30.87 [784]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	500

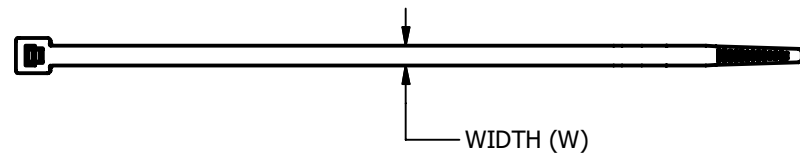

STANDARD

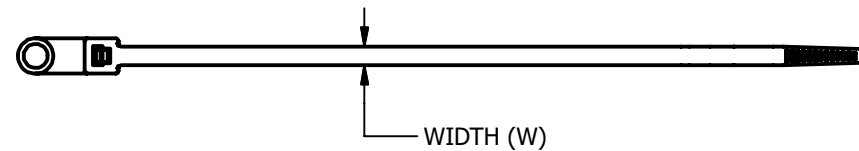

MTG HOLE

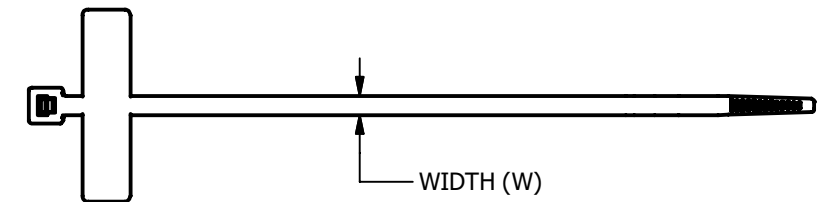

IDENTIFICATION

NOTES:

1. DIMENSIONS IN BRACKETS [ ] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED AND ARE FOR REFERENCE ONLY.

REV	DATE	DESCRIPTION	EC	BY	C'H'K.
G	03/28/2022	PKG QTY UPDATED AS PER MU	220328018511	WP	YR

TO ORDER BURNDY® PRODUCTS CALL

UNITED STATES  
1-800-346-4175 (LONDONDERRY, NH)




CANADA:  
1-800-387-6487

FOR PRODUCT INFO: <http://www.burndy.com>

UNIRAP™	
ITEM NO: SEE TABLE	
CAT. NO: SEE TABLE	
DRAWN BY: D DHEENA 03-08-2017	
CHECKER: K BOUTIN 04-05-2017	
DSN APRVL: A MONTMINY 03-29-2017	
MFG APRVL: --	
QA APRVL: B POST 03-20-2017	
MKT APRVL: K BOUTIN 04-05-2017	
PROD FAM: --	
PROJECT #: --	SIZE
DOCUMENT TYPE: SALES	B
REL LEVEL: Released	
DRAWING NO	REV
50080813	G
SHEET 4 OF 5	



ITEM NUMBER	CATALOG NUMBER	TENSILE STRENGTH LB / N	MATERIAL	COLOR	FEATURE	BUNDLE DIA. MIN. IN [MM]	BUNDLE DIA. MAX. IN [MM]	L IN [MM]	W IN [MM]	MIN. INSTALL TEMP. °F / °C	MIN. OPER. TEMP. °F / °C	MAX. OPER. TEMP. °F / °C	PKG. QTY.	CTN. QTY.
10023504	CT120200L0	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	2.00 [51]	8.70 [221]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	3000
10023505	CT120200D0	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	2.00 [51]	8.70 [221]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	3000
10023506	CT120300L0	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	3.00 [76]	12.00 [305]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	2000
10023507	CT120300D0	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	3.00 [76]	12.00 [305]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	2000
10023508	CT120400L0	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	2000
10023509	CT120400D0	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	2000
50056948	CT120400M0	120 / 534	NYLON 6/6	UV BLACK	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	1000	2000
50101517	CT120400M2	120 / 534	NYLON 6/6	RED	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	1000	2000
50101518	CT120400M3	120 / 534	NYLON 6/6	ORANGE	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	1000	2000
50101519	CT120400M4	120 / 534	NYLON 6/6	YELLOW	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	1000	2000
50101520	CT120400M5	120 / 534	NYLON 6/6	GREEN	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	1000	2000
50101521	CT120400M6	120 / 534	NYLON 6/6	BLUE	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	1000	2000
50101522	CT120400M8	120 / 534	NYLON 6/6	GRAY	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	185 / 85	1000	2000
50081667	CT120400MH14C	120 / 534	NYLON 6/6	NATURAL	MTG HOLE	.18 [5]	4.06 [103]	15.70 [399]	.30 [8]	-4 / -20	-40 / -40	185 / 85	100	2000
10023685	CT120400MH14L	120 / 534	NYLON 6/6	NATURAL	MTG HOLE	.18 [5]	4.06 [103]	15.70 [399]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	2000
10023686	CT120400MH14D	120 / 534	NYLON 6/6	NATURAL	MTG HOLE	.18 [5]	4.06 [103]	15.70 [399]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	2000
10023687	CT120400MH14L0	120 / 534	NYLON 6/6	UV BLACK	MTG HOLE	.18 [5]	4.06 [103]	15.70 [399]	.30 [8]	-4 / -20	-40 / -40	185 / 85	50	2000
10023688	CT120400MH14D0	120 / 534	NYLON 6/6	UV BLACK	MTG HOLE	.18 [5]	4.06 [103]	15.70 [399]	.30 [8]	-4 / -20	-40 / -40	185 / 85	500	1000
50034737	CT175500Q	180 / 800	NYLON 6/6	NATURAL	STANDARD	.35 [9]	6.44 [164]	21.75 [552]	.34 [9]	14 / -10	-40 / -40	185 / 85	25	1000
10023523	CT175600Q	175 / 778	NYLON 6/6	NATURAL	STANDARD	1.50 [38]	7.18 [182]	25.50 [647.7]	.34 [9]	-4 / -20	-40 / -40	185 / 85	50	500
10023534	CT175900Q	175 / 778	NYLON 6/6	NATURAL	STANDARD	1.50 [38]	9.75 [248]	33.21 [844]	.34 [9]	-4 / -20	-40 / -40	185 / 85	25	500
10023545	CT1751100Q	175 / 778	NYLON 6/6	NATURAL	STANDARD	1.50 [38]	11.00 [279]	37.25 [946]	.34 [9]	-4 / -20	-40 / -40	185 / 85	50	500
50034738	CT1751500Q	175 / 778	NYLON 6/6	NATURAL	STANDARD	1.50 [38]	14.50 [368]	48.56 [1233]	.34 [9]	-4 / -20	-40 / -40	185 / 85	25	500
10023569	CT175900Q00	175 / 778	NYLON 6/6	UV BLACK	STANDARD	1.50 [38]	9.75 [248]	33.21 [844]	.34 [9]	-4 / -20	-40 / -40	185 / 85	25	500
50034739	CT175500Q0	180 / 800	NYLON 6/6	UV BLACK	STANDARD	.35 [9]	6.44 [164]	21.75 [552]	.34 [9]	14 / -10	-40 / -40	185 / 85	25	1000
10023571	CT175600Q0	175 / 778	NYLON 6/6	UV BLACK	STANDARD	1.50 [38]	7.18 [182]	25.50 [647.7]	.34 [9]	-4 / -20	-40 / -40	185 / 85	50	500
50034740	CT175800Q0	175 / 778	NYLON 6/6	UV BLACK	STANDARD	1.50 [38]	9.75 [248]	33.21 [844]	.34 [9]	-4 / -20	-40 / -40	185 / 85	25	500
10023573	CT1751100Q0	175 / 778	NYLON 6/6	UV BLACK	STANDARD	1.50 [38]	11.00 [279]	37.25 [946]	.34 [9]	-4 / -20	-40 / -40	185 / 85	50	500
10023574	CT1751400Q0	175 / 778	NYLON 6/6	UV BLACK	STANDARD	1.50 [38]	14.50 [368]	48.56 [1233]	.34 [9]	-4 / -20	-40 / -40	185 / 85	50	500
10023575	CT250600Q	250 / 1112	NYLON 6/6	NATURAL	STANDARD	.35 [9]	6.61 [168]	22.80 [581]	.50 [13]	14 / -10	-40 / -40	185 / 85	25	500
10023586	CT250800Q	250 / 1112	NYLON 6/6	NATURAL	STANDARD	.35 [9]	8.50 [216]	29.00 [737]	.50 [13]	14 / -10	-40 / -40	185 / 85	25	500
10023597	CT2501000Q	250 / 1112	NYLON 6/6	NATURAL	STANDARD	.35 [9]	10.35 [263]	34.90 [887]	.50 [13]	14 / -10	-40 / -40	185 / 85	25	500
10023619	CT250600Q0	250 / 1112	NYLON 6/6	UV BLACK	STANDARD	.35 [9]	6.61 [168]	22.80 [581]	.50 [13]	14 / -10	-40 / -40	185 / 85	25	500
50101515	CT250600C	250 / 1112	NYLON 6/6	NATURAL	STANDARD	.35 [9]	6.61 [168]	22.80 [581]	.48 [13]	14/-10	-40 / -40	185 / 85	100	500
50101516	CT250600C0	250 / 1112	NYLON 6/6	UV BLACK	STANDARD	.35 [9]	6.61 [168]	22.80 [581]	.48 [13]	14/-10	-40 / -40	185 / 85	100	500
10023620	CT250800Q0	250 / 1112	NYLON 6/6	UV BLACK	STANDARD	.35 [9]	8.50 [216]	29.00 [737]	.50 [13]	14 / -10	-40 / -40	185 / 85	25	500
50027395	CTHS120400M	120 / 534	NYLON 6/6 HEAT STABILIZED	HS UV BLACK	STANDARD	.18 [5]	4.00 [102]	15.09 [383]	.30 [8]	-4 / -20	-40 / -40	257 / 125	1000	2000

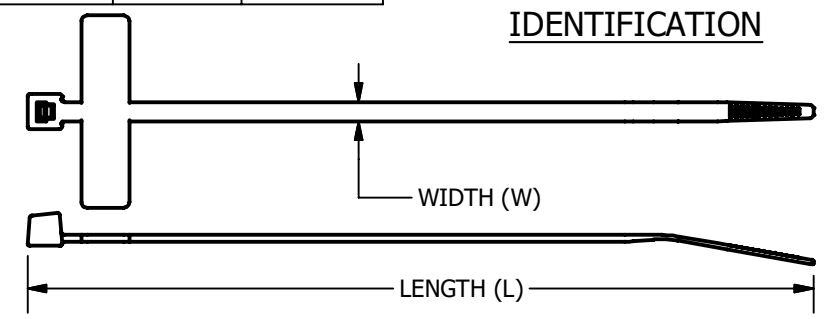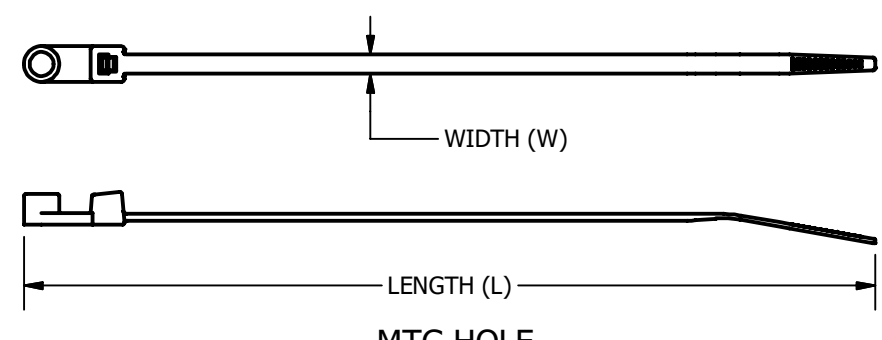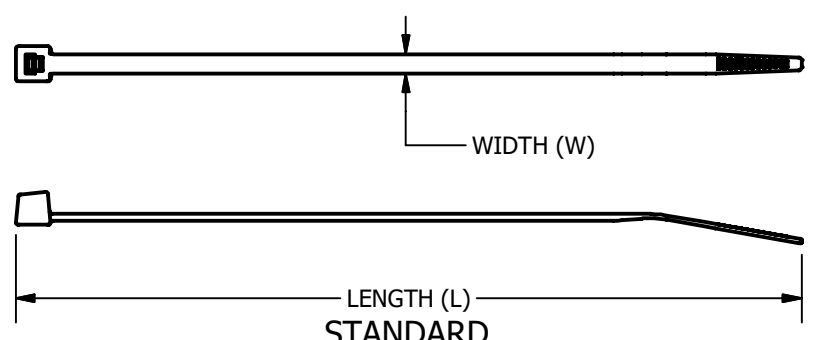

**IDENTIFICATION**

**NOTES:**  
1. DIMENSIONS IN BRACKETS [ ] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED AND ARE FOR REFERENCE ONLY.

TO ORDER BURNDY® PRODUCTS CALL		UNIRAP™	
UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)		ITEM NO: SEE TABLE CAT. NO: SEE TABLE	
CANADA: 1-800-387-6487		DRAWN BY: D DHEENA 03-08-2017 CHECKER: K BOUTIN 04-05-2017 DSN APRVL: A MONTMINY 03-29-2017 MFG APRVL: -- QA APRVL: B POST 03-20-2017 MKT APRVL: K BOUTIN 04-05-2017	
FOR PRODUCT INFO: <a href="http://www.burndy.com">http://www.burndy.com</a>			
REV	DATE	DESCRIPTION	EC
G	03/28/2022	PKG QTY UPDATED AS PER MU	220328018511
BY	C'H'K.	PROJECT #:	SIZE
WP	YR	SALES	B
		REL LEVEL: Released	
		DRAWING NO	REV
		50080813	G
		SHEET 5 OF 5	

REV	DATE	DESCRIPTION	EC	BY	C'H'K.
G	03/28/2022	PKG QTY UPDATED AS PER MU	220328018511	WP	YR