


REV.	DATE	DESCRIPTION	ECO	BY	C'H'K.
C	05/03/2017 10:15:00 AM	LOGO UPDATION	46639	BK	MB

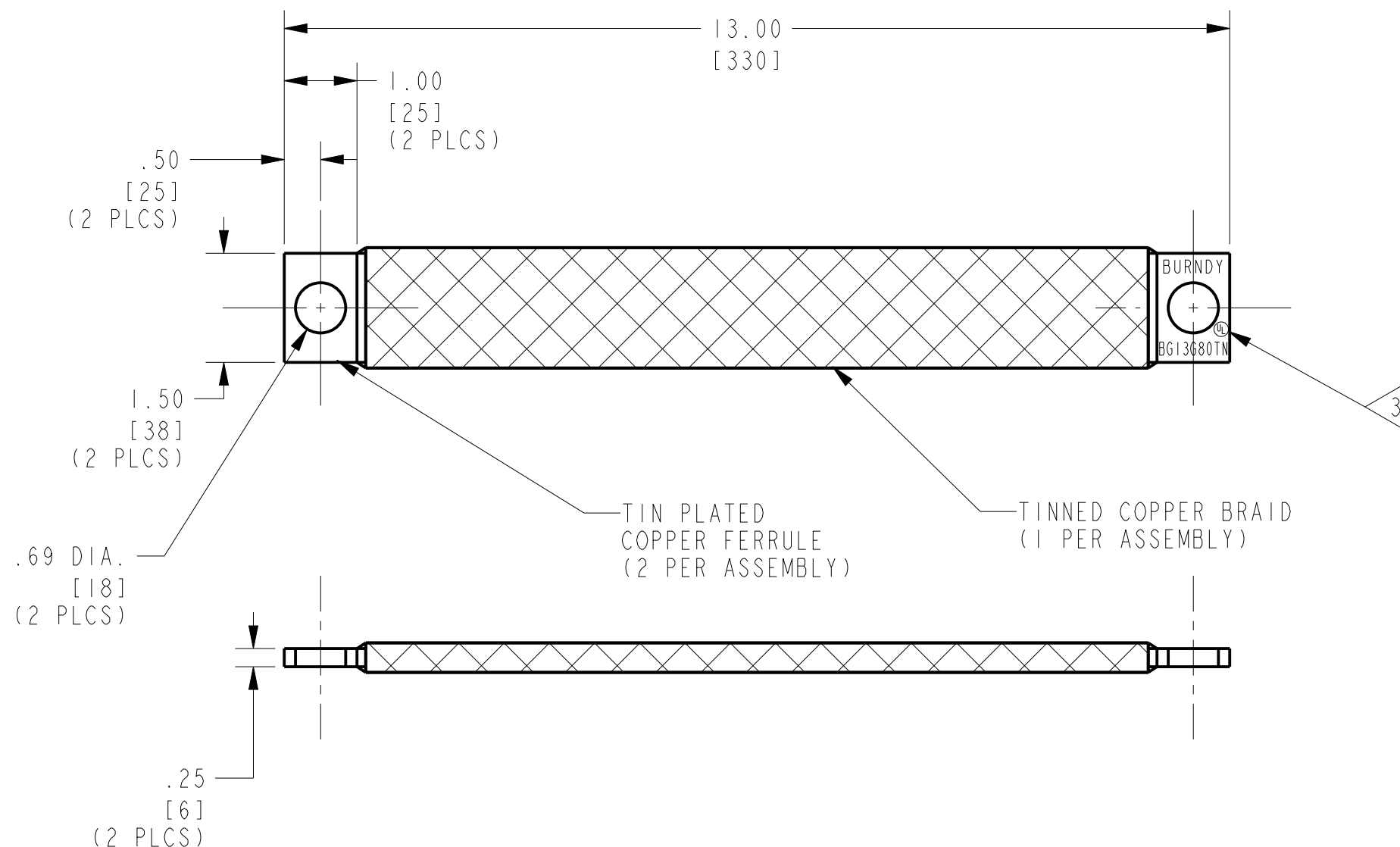

NOTES:

- APPROXIMATE AMP RATING: INDOOR = 415, OUTDOOR = 495. THIS RATING MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID AND OTHER SERVICE CONDITIONS.
- DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.

3 'UL' SYMBOL PER INTERNAL SPECIFICATION L4219, LOCATION AND SIZE TO BE SETERMINED BY MANUFACTURING.

TO ORDER BURNDY® PRODUCTS CALL		BRAID, FLEXIBLE	
UNITED STATES:		ITEM NO: 10045289	
1-800-346-4175 (LONDONDERRY, NH)		CAT. NO: BG13G80TN	
CANADA:		DRAWN BY: R. BOISVERT 10/13/04	
1-800-361-6975 (QUEBEC)		CHECKER: P. LAPONTUS 10/15/04	
1-800-387-6487 (ALL OTHER PROVINCES)		DSN APPVL: J. MICHAUD 10/06/04	
FOR PRODUCT INFO: http://www.burndy.com		MFG APPVL: N/A	
		QA APPVL: J. BRODEUR 10/04/04	
		MKT APPVL: R. BROOKS 10/04/04	
		SCALE: 1:2	
		DRAWING NO	
		REV	
		PROJECT #: --	
		SIZE	
		DOCUMENT TYPE: --	
		REL LEVEL: Released	
		B	
		10045683	
		SHEET 1 OF 1	
		C	