


DRAWING NO. 30019447		4	
CATALOG NUMBER	3 4 5 6	ITEM NUMBER	L
BE12		332245	12.00 [305]
BE15		332258	15.00 [381]
BE18		332255	18.00 [457]
BE22		S03563	22.00 [559]
BE24		33264V	24.00 [610]
BE36		33289A	36.00 [914]
BE42TN		25017920	42.00 [1067]
BE54		33212J	54.00 [1372]
BE61		S04012	61.00 [1549]
BE120		33289B	120.00 [3048]

REV	DATE	DESCRIPTION	ECO	BY	C'K.
A	09/06/2011 00:00:00 AM	NEW DRAWING RELEASE	25535	MA	BT

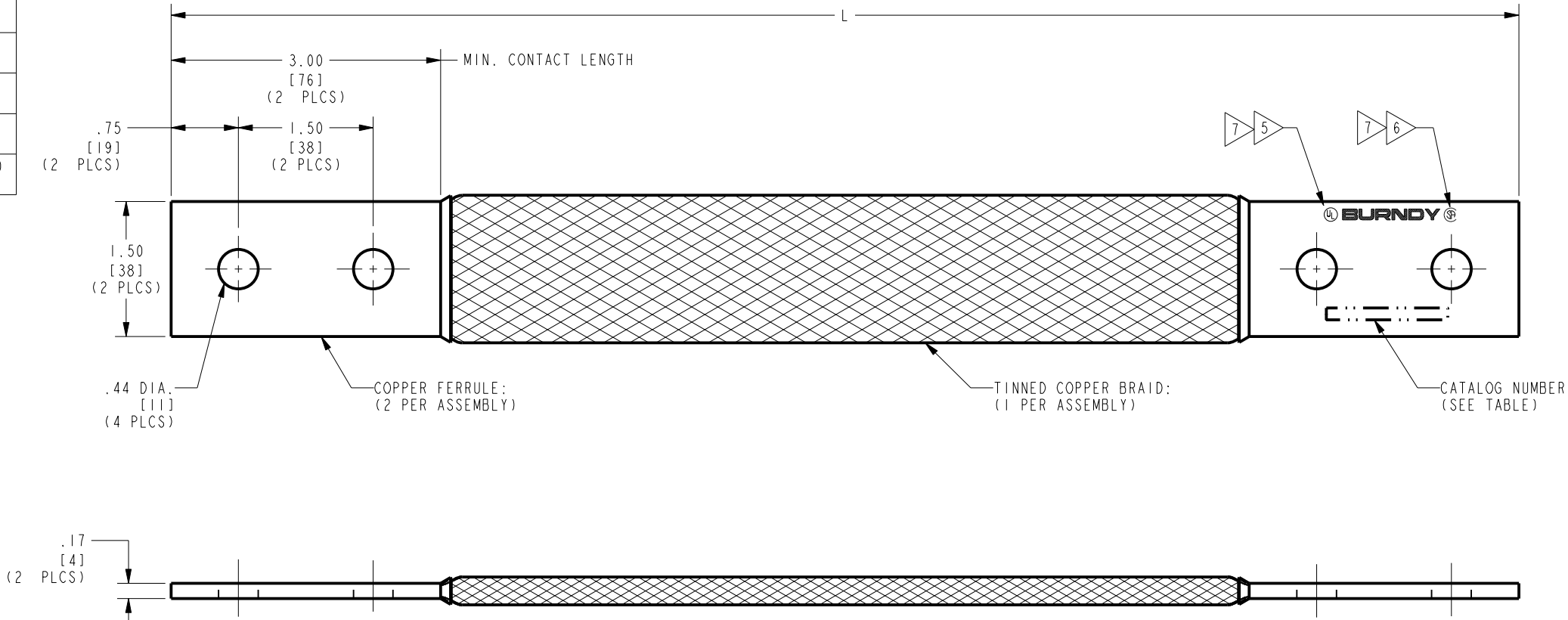

NOTES:

1. APPROXIMATE AMP RATING: 340 INDOOR, 405 OUTDOOR
THIS RATING MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION
OF THE BRAID AND OTHER SERVICE CONDITIONS.
2. DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST
MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.

3 CAN BE ORDERED WITH PLATED FERRULES BY ADDING SUFFIX AS SHOWN BELOW:
"NK" - FOR NICKEL PLATING
"SV" - FOR SILVER PLATING
"TN" - FOR TIN PLATING
"W" - FOR HOT TIN DIPPED

4 CAN BE ORDERED WITH UNDRILLED FERRULES BY ADDING SUFFIX "U".

5 ALL SIZES ARE LISTED TO UL 467 GROUNDING & BONDING EQUIPMENT STANDARDS.

6 ALL SIZES ARE LISTED TO CSA C22.2 NO.41 GROUNDING & BONDING EQUIPMENT STANDARDS.

7 BRAID SIZES MAY BE DESIGNATED BY SUFFIXES REPRESENTING VARIATIONS IN LENGTH,
QUANTITY & SIZE OF MOUNTING HOLES, PAD SIZE AND FINISH. (REF. NOTES 5)

TO ORDER BURNDY® PRODUCTS CALL
UNITED STATES:
1-800-346-4175 (LONDONDERRY, NH)
CANADA:
1-800-361-6975 (QUEBEC)
1-800-387-6487 (ALL OTHER PROVINCES)
FOR PRODUCT INFO: <http://www.burndy.com>

BRAID	
ITEM NO: SEE TABLE	
CAT. NO: BE-- (TABLE)	
DRAWN BY: M. AYYAPPAN	09/06/11
CHECKER: E. MARTIN	09/02/11
DSN APPVL: E. MARTIN	09/02/11
MFG APPVL: O. GUALBERTO	09/19/11
QA APPVL: J. MEDINA	10/03/11
MKT APPVL: P. THERRIEN	09/02/11
PROD FAM: --	SCALE: 1:1
PROJECT #: --	DRAWING NO
DOCUMENT TYPE: Sales	30019447
REL LEVEL: Released	SHEET 1 OF 1

BURNDY