
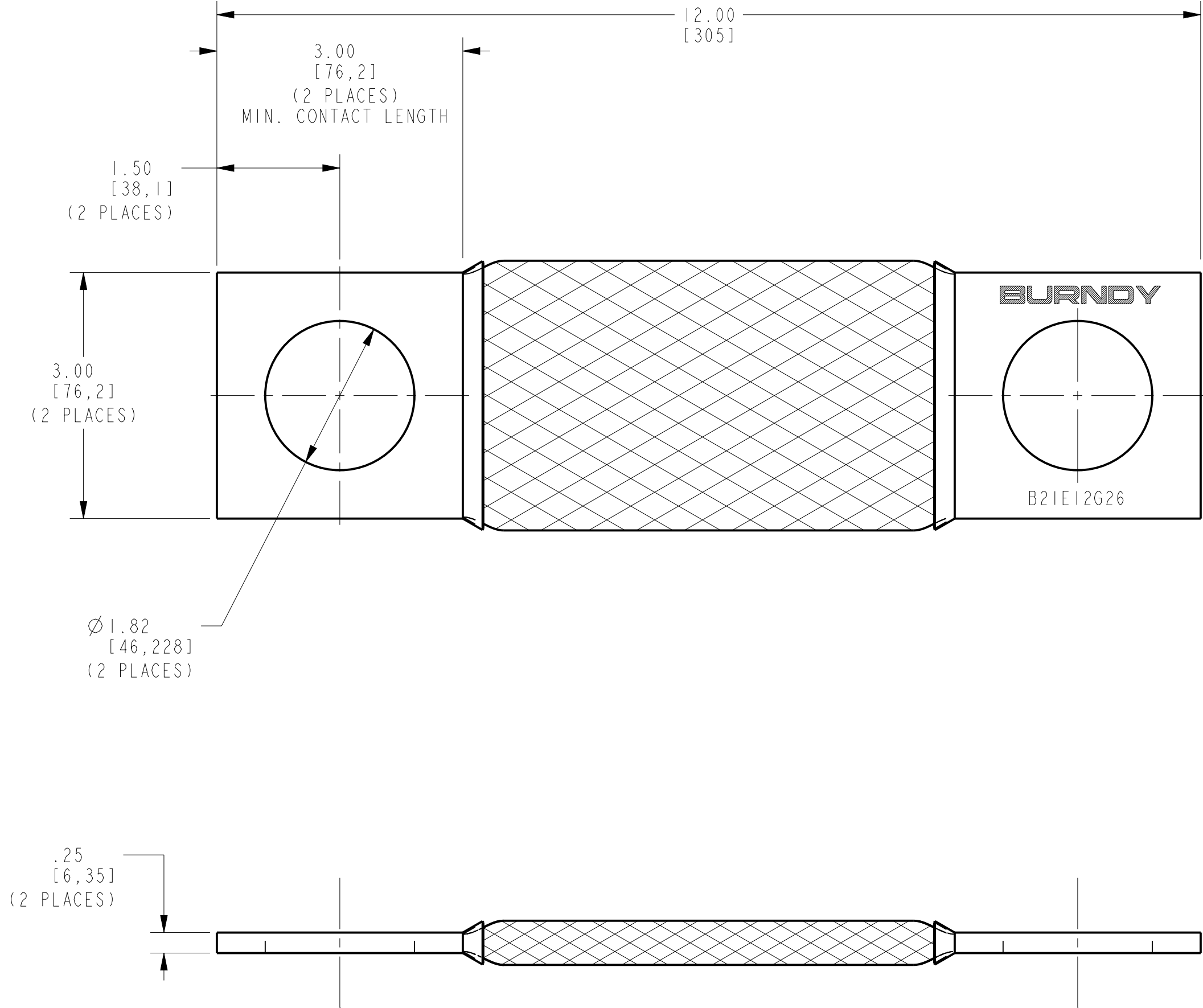


REV	DATE	DESCRIPTION	ECO	BY	C'K.
B	05/05/2017 15:38:00 PM	LOGO UPDATED	46677	SM	MB

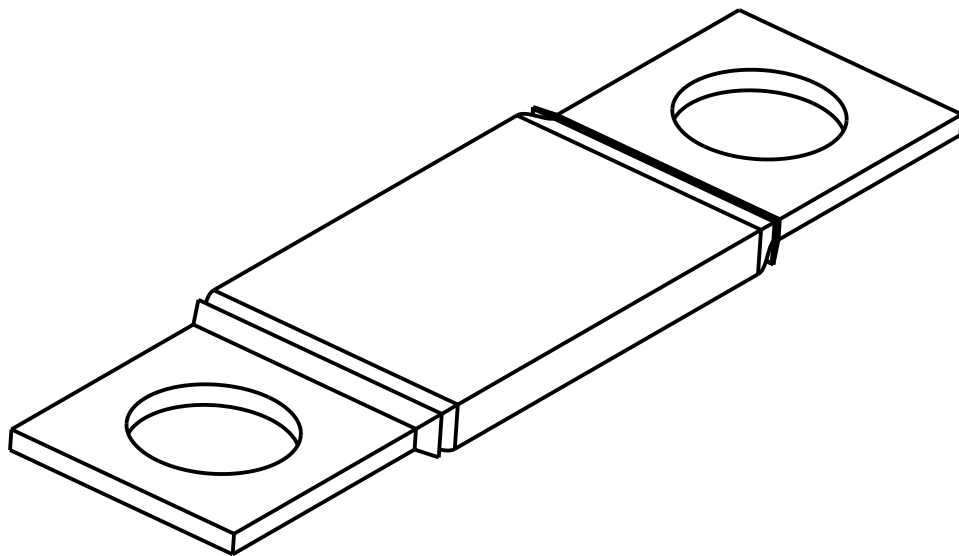

NOTES:

- DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED, AND ARE FOR REFERENCE ONLY.
- APPROXIMATE AMP RATING: 580 A
THIS RATING MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID AND OTHER SERVICE CONDITIONS.

TO ORDER BURNDY® PRODUCTS CALL

UNITED STATES:
1-800-346-4175 (LONDONDERRY, NH)

CANADA:
1-800-361-6975 (QUEBEC)
1-800-387-6487 (ALL OTHER PROVINCES)

FOR PRODUCT INFO: <http://www.burndy.com>

BRAID	
ITEM NO: 10102102	
CAT. NO: B21E12G26	
DRAWN BY: R. BOISVERT	09/08/09
CHECKER: J. PARKER	09/10/09
DSN APPVL: J. PARKER	08/20/09
MFG APPVL: C. MARTINEZ	09/03/09
QA APPVL: J. BRODEUR	09/01/09
MKT APPVL: P. THERRIEN	08/20/09
PROD FAM: --	SCALE: 3:4
PROJECT #: --	DRAWING NO
DOCUMENT TYPE: Sales	REV
REL LEVEL: Released	

BURNDY

10105636

SHEET 1 OF 1