


CATALOG NO.	L	L1
BE12D80G201	12.80 [325]	11.80 [300]
BE24D60G201	24.60 [625]	23.60 [599]

REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
A	04/29/13	FOCUS REQUEST	31409	GN	MB

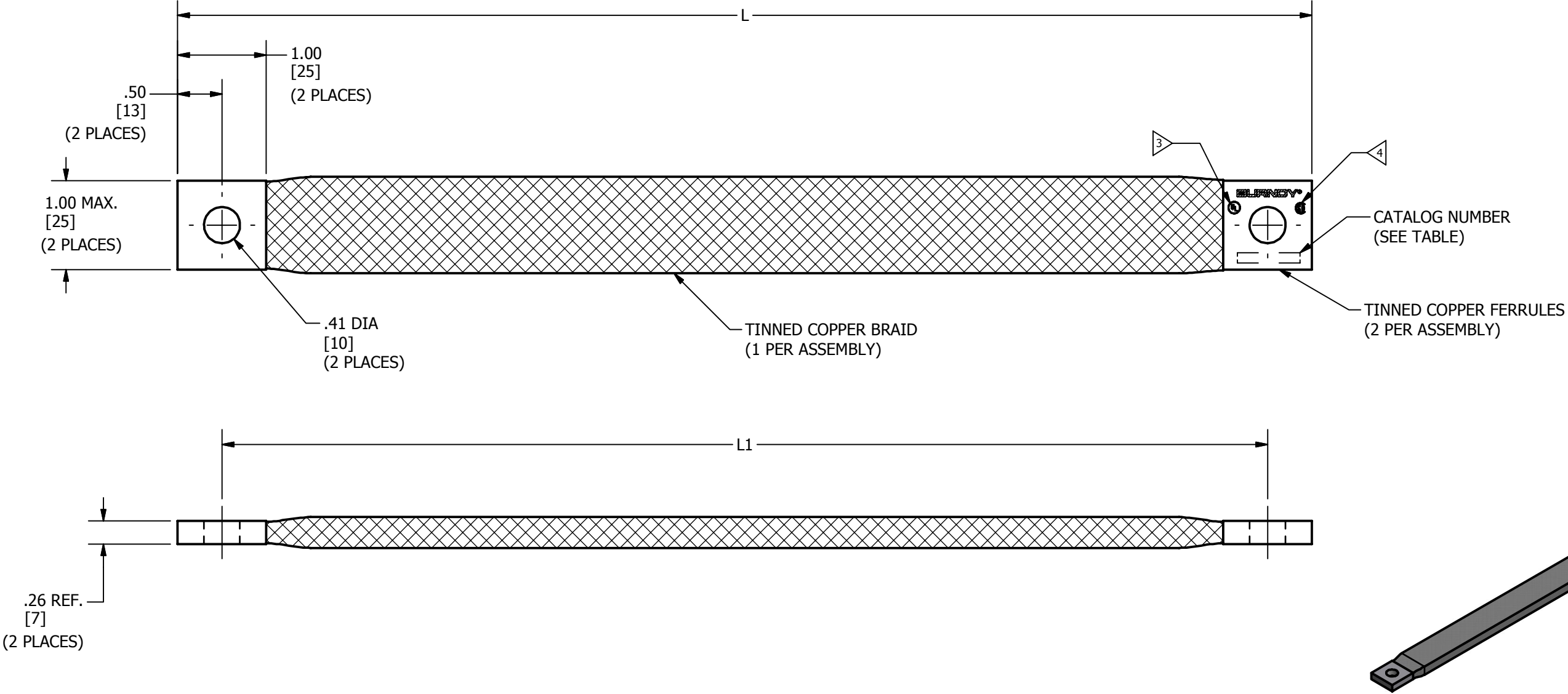

NOTES:

1. APPROXIMATE AMP RATING: 340A INDOOR, 405A OUTDOOR. THIS RATING MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID, AND OTHER SERVICE CONDITIONS.
2. DIMENSIONS IN BRACKETS [ ] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.
3. ALL SIZES ARE LISTED TO UL 467 GROUNDING & BONDING EQUIPMENT STANDARDS.
4. ALL SIZES ARE LISTED TO CSA 22.2 NO.41 GROUNDING & BONDING EQUIPMENT STANDARDS.

TO ORDER BURNDY® PRODUCTS CALL  UNITED STATES 1-800-346-4175 (LONDONDERRY, NH)  CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES)  FOR PRODUCT INFO: <a href="http://www.burndy.com">http://www.burndy.com</a>		BRAID	
		ITEM NO: SEE TABLE	
		CAT. NO: SEE TABLE	
		DRAWN BY: GNATH 04/29/13	
		CHECKER: --	
		DSN APRVL: --	
		MFG APRVL: --	
		QA APRVL: --	
		MKT APRVL: --	
		PROD FAM: MECHANICAL GROUNDING	DRAWING NO
		PROJECT #: --	50020483
		DOCUMENT TYPE: SALES	REV
		REL LEVEL: Released	A