

REV	DATE	DESCRIPTION	ECO	BY	C.H.K.
A	2020-08-14 00:00:00 EDT	DRAWING RELEASED	54086	MM	NJS

D

D

C

C



B

B

A

A

CAT NO	CONDUCTOR		METRIC WIRE (mm ²)	B	L	O.D	INDEX NO	INSTALLATION DATA														
	COPPER CABLE SIZE	STR						HYSPRESS™ DIE SETS WITH NO. OF CRIMPS EACH END														
								MD6		Y35		Y46		Y488		Y60		KEARNEY		NICOPRESS		
YDS8C	#8 STR (Ø.146)	7	6	.76	1.78	.27	171	W171	1	U171	1	---	---	---	---	---	---	---	---	---	---	---
YDS6C	#6 STR (Ø.183)	7	10	1.26	2.77	.32	161	W161	2	U161	1	---	---	---	---	---	---	---	---	---	K5/16	N-J
YDS4C	#4 STR (Ø.232)	7	23	1.15	2.55	.40	162	W162	4	U162	1	---	---	---	---	---	---	---	---	---	K 3/8	N-P
YDS3C-3	#3 STR (Ø.286)	3	--	2.50	5.25	.50	163	W163	9	U163	3	---	---	---	---	---	---	---	---	---	---	---
YDS2C	#2 STR (Ø.291)	7	38	1.72	3.69	.50	163	W163	6	U163	2	---	---	---	---	---	---	---	---	---	K 1/2	N-T
YDS2C-3	#2 STR (Ø.320)	3	--	1.72	3.69	.53	163	W163	6	U163	2	---	---	---	---	---	---	---	---	---	---	---
YDS1C	#1 STR (Ø.330)	7,19	42	2.05	4.29	.56	164	W164	6	U164	3	---	---	---	---	---	---	---	---	---	---	---
YDS1C-3	#1 STR (Ø.360)	3	--	2.97	6.18	.68	166,459	W166	12	U166/U459	6	---	---	---	---	---	---	---	---	---	---	---
YDS25	#1/0 STR (Ø.373)	7,19	--	2.59	5.38	.63	165	W165	6	U165	6	---	---	---	---	---	---	---	---	---	K 19/32-K 5/8-1	---
YDS26	2/0 STR (Ø.414) (Ø.418)	7 19	70	2.85	5.95	.71	166	W166	12	U166	6	---	---	---	---	---	---	---	---	---	K 5/8-1	---
YDS26	115kcmil *7*8(Ø.386)	7	--	2.85	5.95	.71	166	W166	12	U166	6	---	---	---	---	---	---	---	---	---	K 5/8-1	---
YDS26	2/0 STR(Ø.437)MAX	7,12,19	--	2.85	5.95	.71	166	W166	12	U166	6	---	---	---	---	---	---	---	---	---	K 5/8-1	---
YDS26-11	2/0 STR(Ø.440)	11	--	3.02	6.31	.71	263	---	---	U236	6	---	---	---	---	---	---	---	---	---	---	---
YDS27	3/0 STR(Ø.470)	7,19	--	3.29	6.83	.79	167	---	---	U167	7	---	---	---	---	---	---	---	---	---	K 7/37	---
YDS28	4/0 STR(Ø.528)	7,19	98	3.27	6.91	.89	168	---	---	U168	9	---	---	---	---	L168	3	---	---	---	K 781	---
YDS28	4/0 STR(Ø.552)	7,12,19	--	3.27	6.91	.89	168	---	---	U168	9	---	---	---	---	L168	3	---	---	---	K 781/840	---
YDS29	250 kcmil (Ø.575)	7,19,37	--	3.54	7.47	.95	169	---	---	U169	9	---	---	---	---	L169	3	---	---	---	K 840	---
YDS29-12	250 kcmil (Ø.600)	12	--	3.55	7.47	.96	169	---	---	U169	9	---	---	---	---	C169	3	L169	3	---	---	---
YDS30	300 kcmil (Ø.630)	19,37	--	3.86	8.09	1.05	170	---	---	U170	13	---	---	---	---	L170	3	---	---	---	K1 1/8-7	---
YDS31	350 kcmil (Ø.710)	12,19,37	--	5.04	10.20	1.17	267	---	---	U267	12	---	---	---	---	L267	4	---	---	---	---	---
YDS32	400 kcmil (Ø.728)	19,37	--	6.25	12.83	1.24	209	---	---	U209	15	---	---	---	---	L209	5	---	---	---	---	---
YDS34	500 kcmil (Ø.814)	19,37	--	5.75	11.62	1.38	210	---	---	U210	15	---	---	---	---	L210	5	---	---	---	---	---
YDS36	600 kcmil (Ø.893)	37,61	--	6.17	13.46	1.55	576	---	---	---	---	---	---	---	---	C576	7	L576	7	---	---	---
YDS39	750 kcmil (Ø.998)	37,61	--	6.01	12.78	1.70	627	---	---	---	---	---	---	---	---	---	L627	7	---	---	---	---
YDS44	1000 kcmil (Ø1.152)	37,61	--	7.56	15.25	2.00	345	---	---	---	---	---	---	---	---	---	L345	10	---	---	---	---

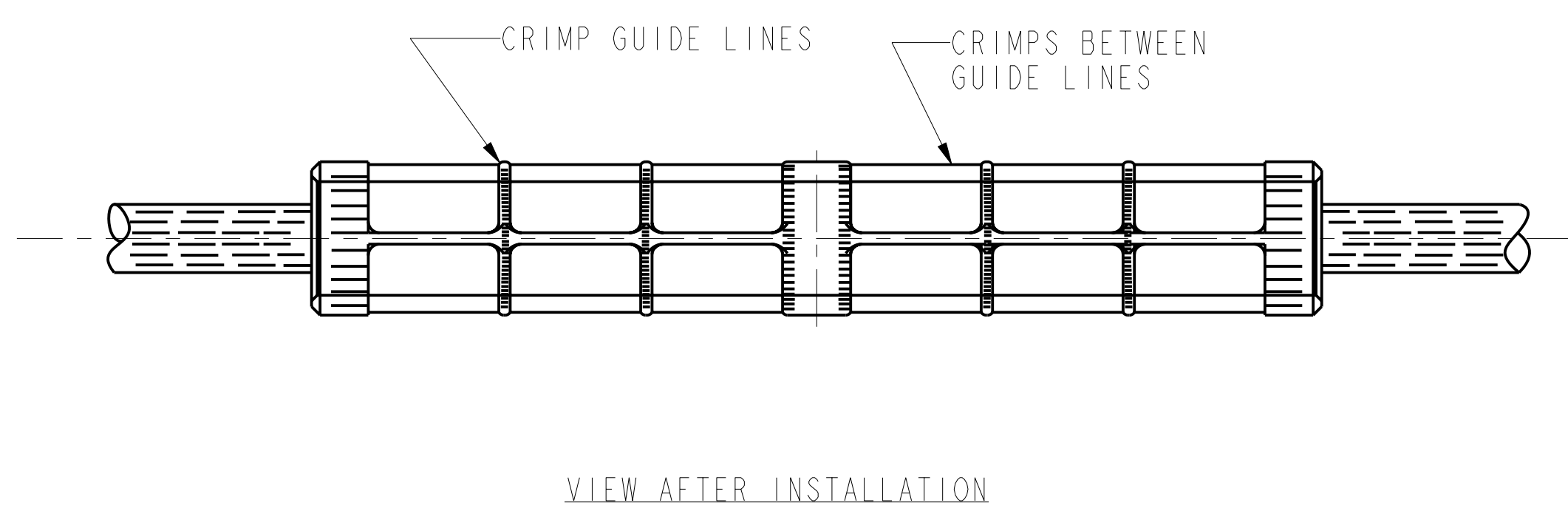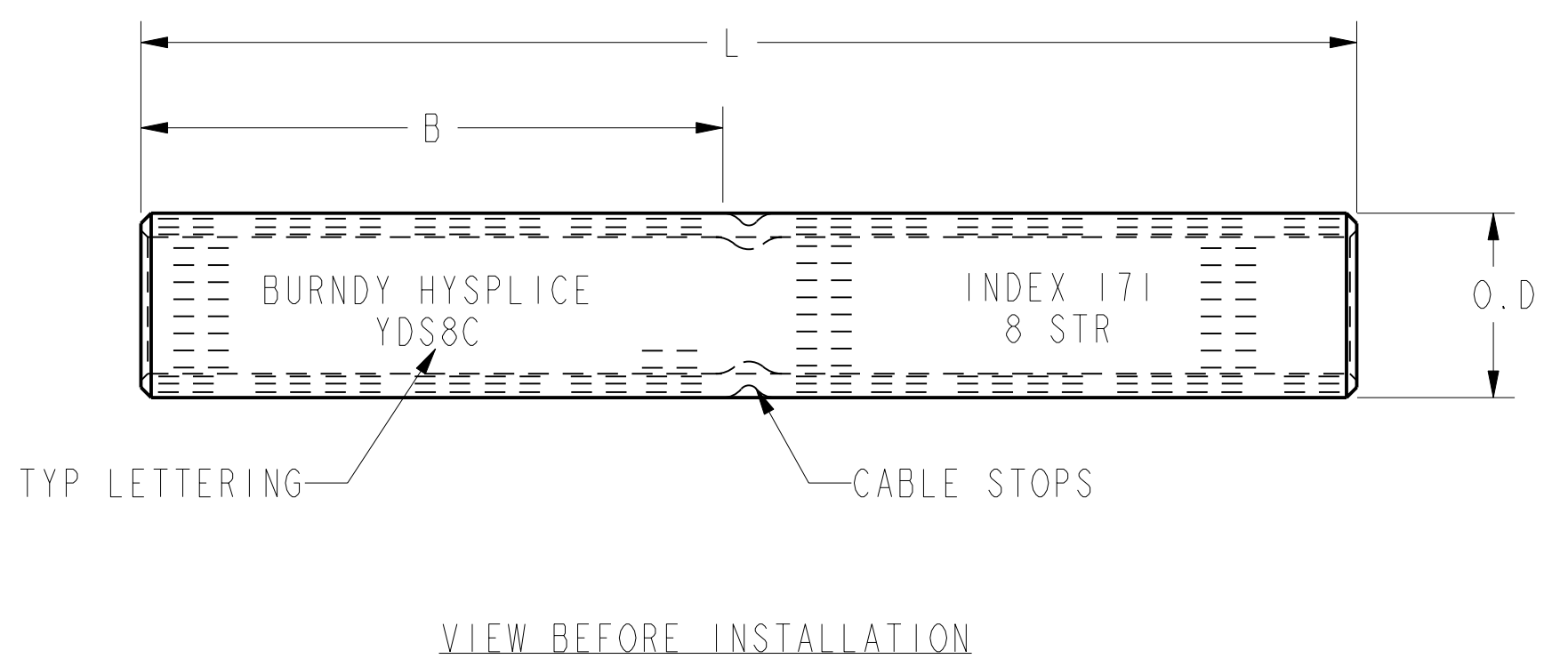

- NOTES:
- U DIES MAY BE USED WITH P-U ADP U DIE ADAPTOR.
 - MATERIAL: COPPER TUBE.
 - BARRELS LINED WITH PENETROX™.

REFERENCE: SD15142M

TO ORDER BURNDY® PRODUCTS CALL		HYSPLICE™ TENSION (COPPER) WITH METRIC REF	
UNITED STATES		ITEM NO: NA	
1-800-346-4175 (LONDONDERRY, NH)		CAT. NO: YDS (TABLE)	
CANADA:		DRAWN BY: M MOHAN 08/17/20	
1-800-361-6975 (QUEBEC)		CHECKER: NJ SUDHAKAR 08/17/20	
1-800-387-6487 (ALL OTHER PROVINCES)		DSN APPVL: D DOBRINSKI 08/15/20	
FOR PRODUCT INFO: http://www.burndy.com		MFG APPVL: --	
		GA APPVL: T WATTS 08/14/20	
		MKT APPVL: J HALL 08/14/20	
		PROD FAM: --	
		SCALE: NTS	
		DRAWING NO	
		REV	
		PROJECT #: --	
		SIZE	
		50115709	
		DOCUMENT TYPE: Sales	
		SHEET 1 OF 1	
		REL LEVEL: Released	



REV: PEO200