
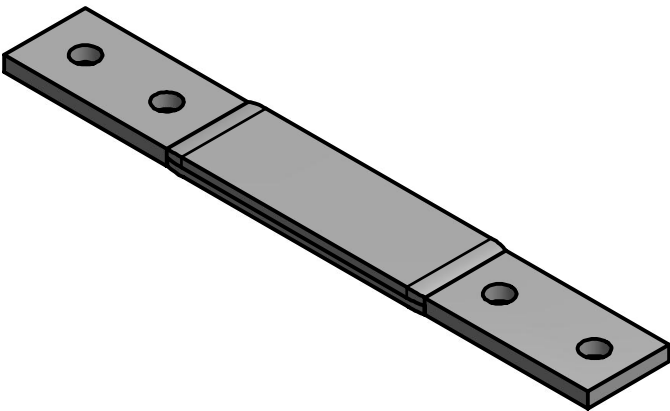
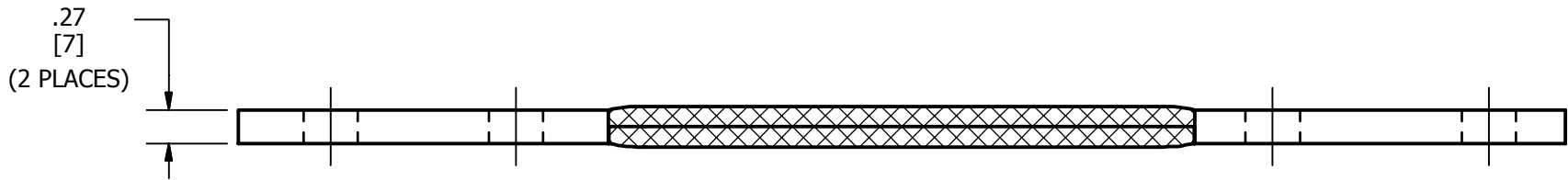


REV	DATE	DESCRIPTION	ECO	BY	C'H'K.
A	06/10/2013	CREATE STAND ALONE SALES DRAWING	32053	BSB	RG

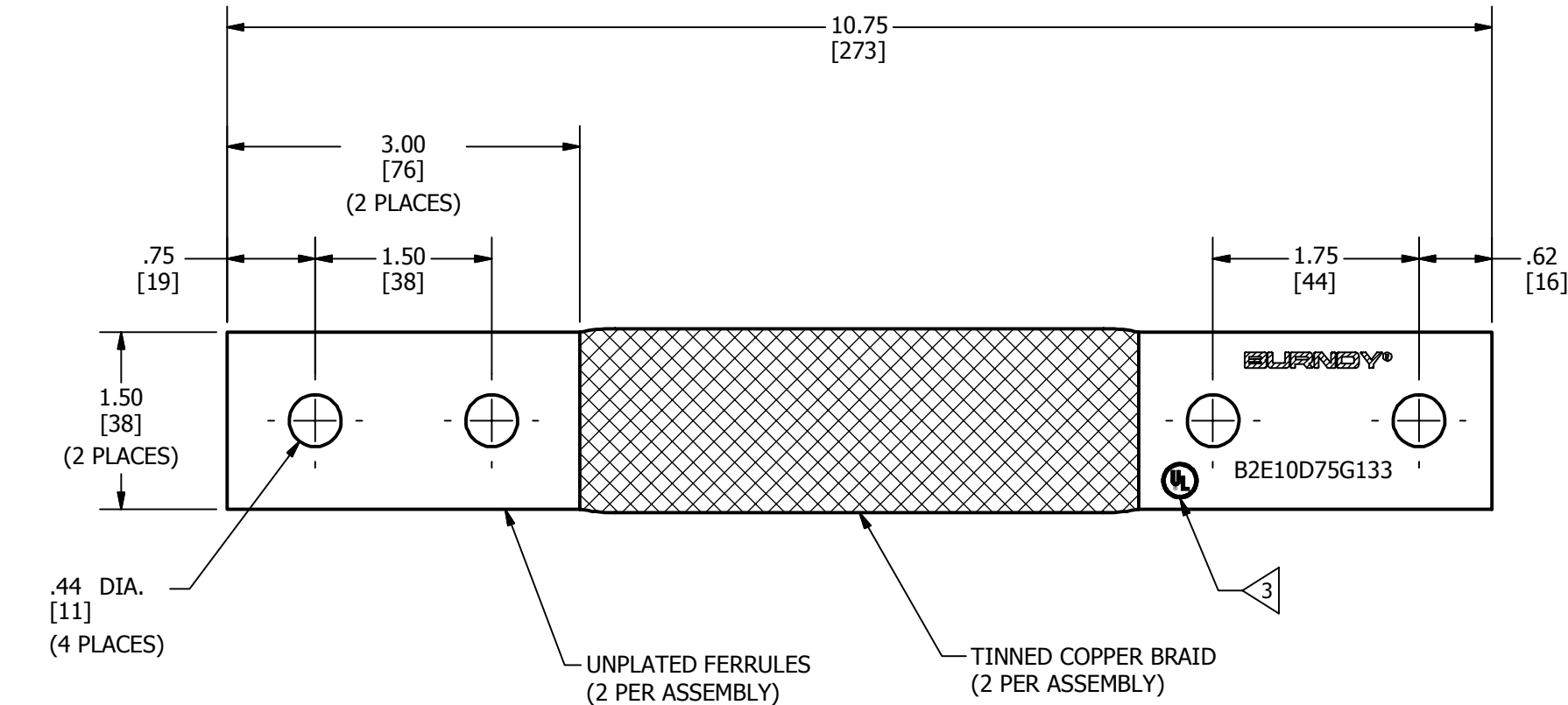

- NOTES:
- DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED, AND ARE FOR REFERENCE ONLY.
 - APPROXIMATE AMP RATING: 530 INDOOR, 635 OUTDOOR
THIS MAY VARY WITH AMBIENT CONDITIONS, ORENTATION OF THE BRAID AND OTHER SERVICE CONDITIONS.

3 BRAID IS LISTED TO UL 467 GROUNDING AND BONDING EQUIPMENT STANDARDS.

TO ORDER BURNDY® PRODUCTS CALL UNITED STATES 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES) FOR PRODUCT INFO: http://www.burndy.com	BRAID, FLEXIBLE			
	ITEM NO: 50025457			
	CAT. NO: B2E10D75G133			
	DRAWN BY: GNATH		06-06-2013	
	CHECKER: T.REYNOLDS		06-17-2013	
	DSN APRVL: E.MARTIN		06-17-2013	
	MFG APRVL: R.CRUIZ		06-17-2013	
	QA APRVL: J.MEDINA		06-17-2013	
	MKT APRVL: K.ROBICHEAU		06-17-2013	
	PROD FAM:		DRAWING NO	
PROJECT #:		REV		
DOCUMENT TYPE: SALES		50025458		
REL LEVEL: Released		SHEET 1 OF 1		
		A		