


DRAWING NO. SE210201	ITEM NUMBER	NO. OF BRAIDS IN FERRULE	DIMENSIONS							APPROX. AMP RATING	
			C	D	E	K DIA.	L	N	T	INDOOR	OUTDOOR
BE12	332245	1	1.50 [38]	3.00 [76]	1.50 [38]	.44 [11]	12.00 [305]	.75 [19]	.17 [4]	340	405
BE18	332255			1.50 [38]	1.50 [38]	.44 [11]	18.00 [457]	.75 [19]			
BE24	33264V			1.50 [38]	1.50 [38]	.44 [11]	24.00 [610]	.75 [19]			
BF12	332305			1.19 [30]	1.50 [38]	.44 [11]	12.00 [305]	.75 [19]			
BF12N	332201		1.19 [30]	1.50 [38]	1.75 [44]	.56 [14]	12.00 [305]	.62 [16]	.25 [6]		
BF12SV	33290U				1.50 [38]	.44 [11]	12.00 [305]	.75 [19]			
BF18	33264W		1.19 [30]	1.50 [38]	1.50 [38]	.44 [11]	18.00 [457]	.75 [19]	.25 [6]		
BF18N	33284H				1.75 [44]	.56 [14]	18.00 [457]	.62 [16]			
BF22N	33211F				1.75 [44]	.56 [14]	22.00 [559]	.62 [16]			
BF24	33286K				1.50 [38]	.44 [11]	24.00 [610]	.75 [19]			
BF24N	33267A		1.50 [38]	1.19 [30]	1.75 [44]	.56 [14]	24.00 [610]	.62 [16]	.25 [6]		
BG12	332360				1.50 [38]	.44 [11]	12.00 [305]	.75 [19]			
BG12N	33288G				1.75 [44]	.56 [14]	12.00 [305]	.62 [16]			
BG18	33266J				1.50 [38]	.44 [11]	18.00 [457]	.75 [19]			
BG18N	332248				1.75 [44]	.56 [14]	18.00 [457]	.62 [16]			
BG24	33266E				1.50 [38]	.44 [11]	24.00 [610]	.75 [19]			
BG24N	33284L	1.75 [44]			.56 [14]	24.00 [610]	.62 [16]				
BG26N	10076995	1.75 [44]			.56 [14]	26.00 [660]	.62 [16]				
BG28N	10021134	1.75 [44]	1.50 [38]	1.75 [44]	.56 [14]	28.00 [711]	.62 [16]	.25 [6]			
BG30N	332702			1.75 [44]	.56 [14]	30.00 [762]	.62 [16]				
BG48N	000193			1.75 [44]	.56 [14]	48.00 [1219]	.62 [16]				

REV.	DATE	DESCRIPTION	ECO	BY	C'K'D.
K	08/04/2014	ADD THE CATALOG NO BF22N	37244	SV	MB

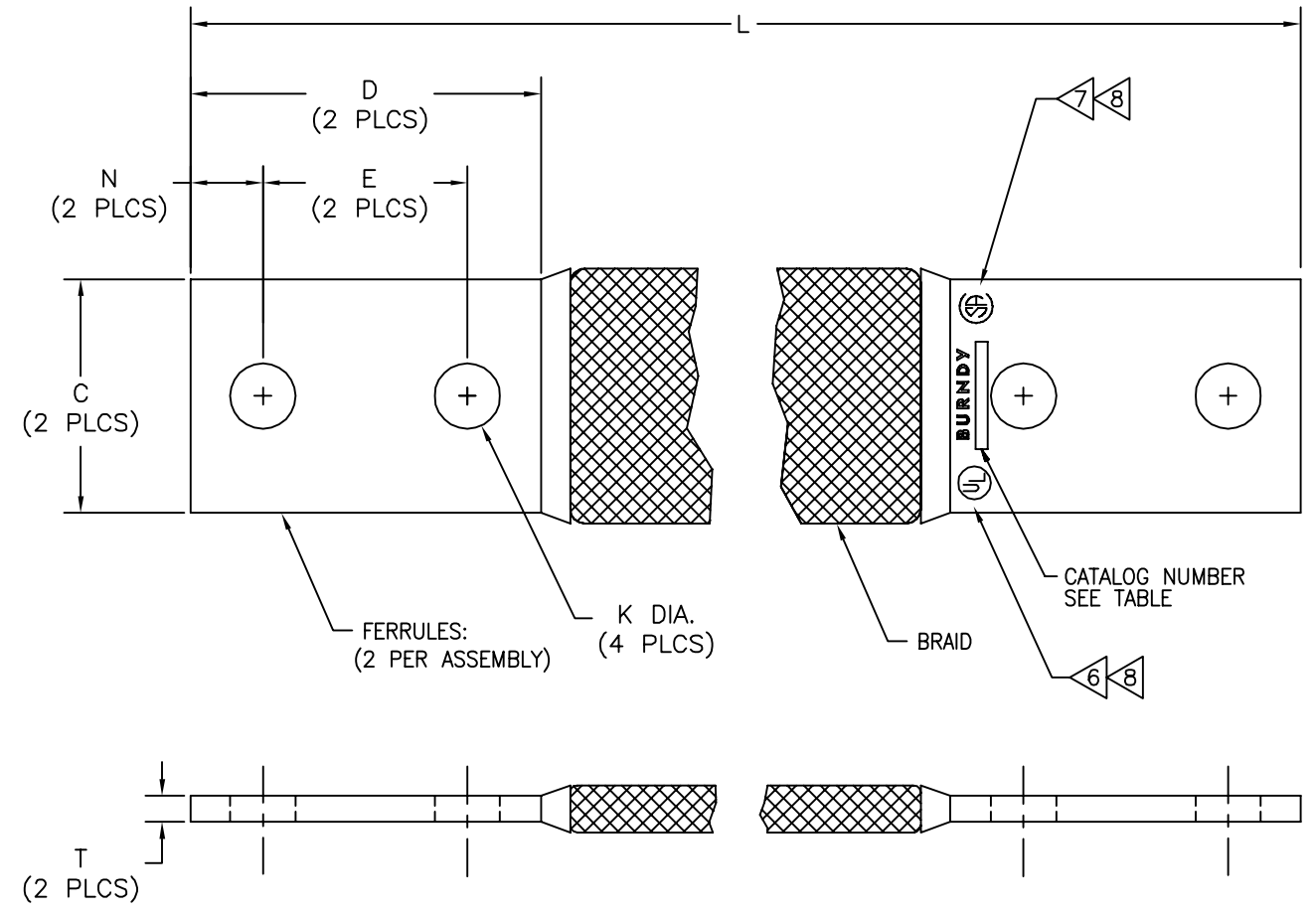

- NOTES:**
- MATERIAL: FERRULES: - COPPER
BRAID: - TINNED COPPER
 - FINISH: CATALOG NUMBER FOLLOWED BY 'SV' INDICATES SILVER PLATED FERRULES.
 - CATALOG NUMBERS ENDING IN 'N' INDICATES THE FERRULES ARE TWO HOLE NEMA DRILLED.
 - CURRENTS PROVIDED ARE BASED ON A 30°C RISE OVER AMBIENT TEMPERATURE. THIS RATING MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID, AND OTHER SERVICE CONDITIONS.
 - DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE NOTED, AND ARE FOR REFERENCE ONLY.
 - ALL SIZES ARE LISTED TO UL 467 GROUNDING & BONDING EQUIPMENT STANDARDS.
 - SPECIFIC SIZES AS INDICATED ARE LISTED TO CSA C22.2 NO.41 GROUNDING & BONDING EQUIPMENT STANDARDS.
 - BRAID SIZES MAY BE DESIGNATED BY SUFFIXES REPRESENTING VARIATIONS IN LENGTH, QUANTITY & SIZE OF MOUNTING HOLES, PAD SIZE AND FINISH. (REF. NOTES 6, 7)

TO ORDER BURNDY® PRODUCTS CALL		FLEXIBLE BRAID JUMPER	
UNITED STATES:		ITEM NO: N/A	
1-800-346-4175 (LONDONDERRY, NH)		CAT NO: B- (TABLE)	
CANADA:		SCALE: 1/1	
1-800-361-6975 (QUEBEC)		DRAWN BY: R. PERRAULT 11/03/95	
1-800-387-6487 (ALL OTHER PROVINCES)		CHECKER: J. MICHAUD 11/03/95	
FOR PRODUCT INFO: http://www.burndy.com		DSN APPVL: G. ZAHLMAN 11/14/95	
		MFG APPVL: --	
		QC APPVL: D. VARIO 11/14/95	
		MKT APPVL: C. CHADBOURNE 11/03/95	
		PROJ APPVL: --	
		PROJECT #: --	
		DOCUMENT TYPE: Sales	
		REL LEVEL: AutoCAD	
		DRAWING NO: SE210201	
		REV: K	
		SHEET 1 OF 3	