

DRAWING NO.
10096104

4




3

2

1

ITEM NUMBER	CAT. NUMBER	L
10089359	B3E20NSV	20.00 [508]
10089360	B3E33NSV	33.00 [838]

REV	DATE	DESCRIPTION	ECO	BY	CHK.
B	05/08/2017 10:21:00 AM	LOGO UPDATED	46682	SM	MB

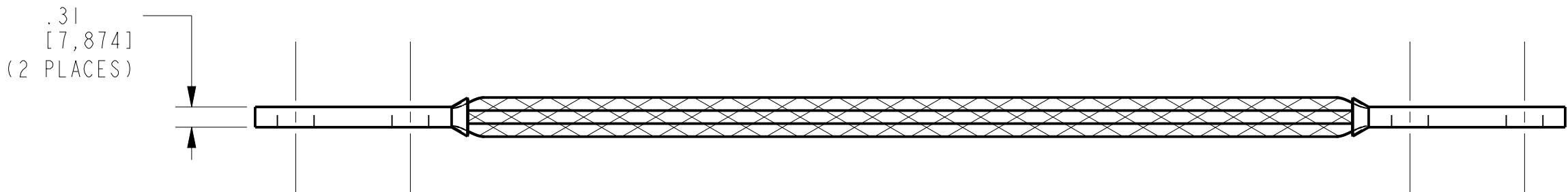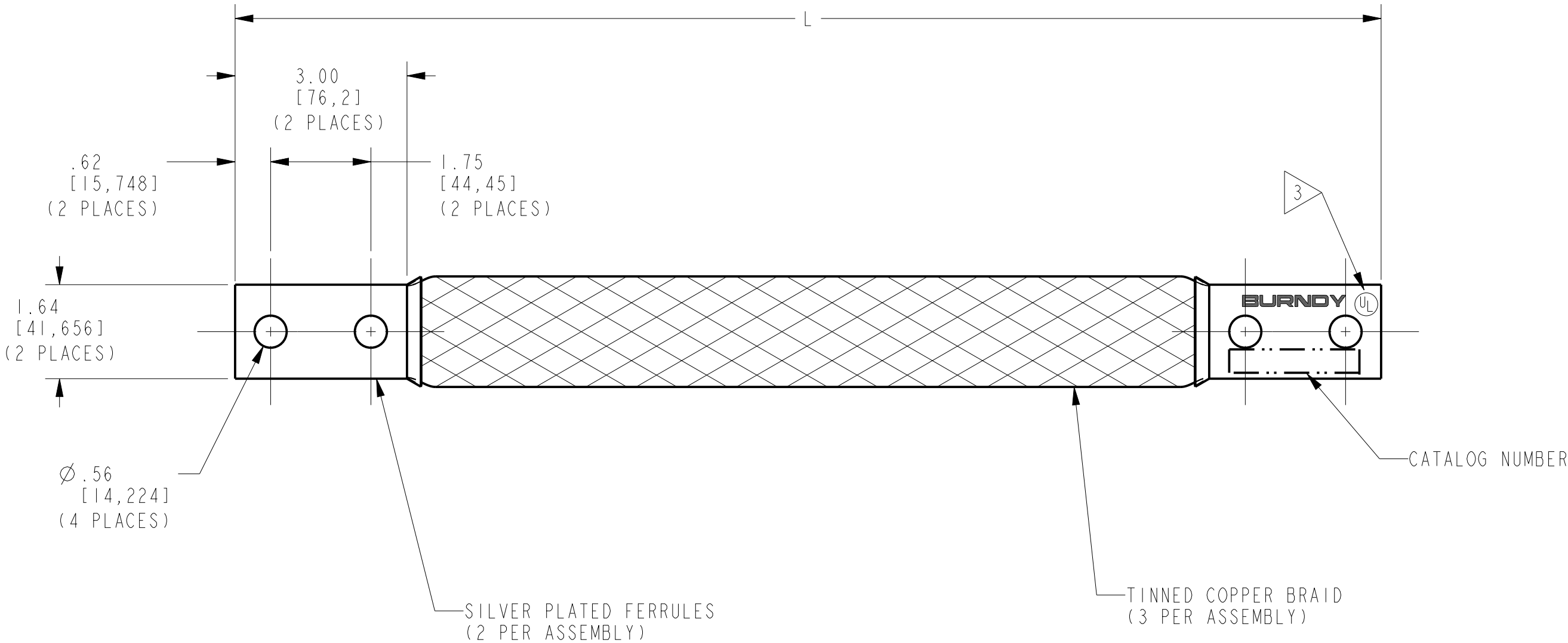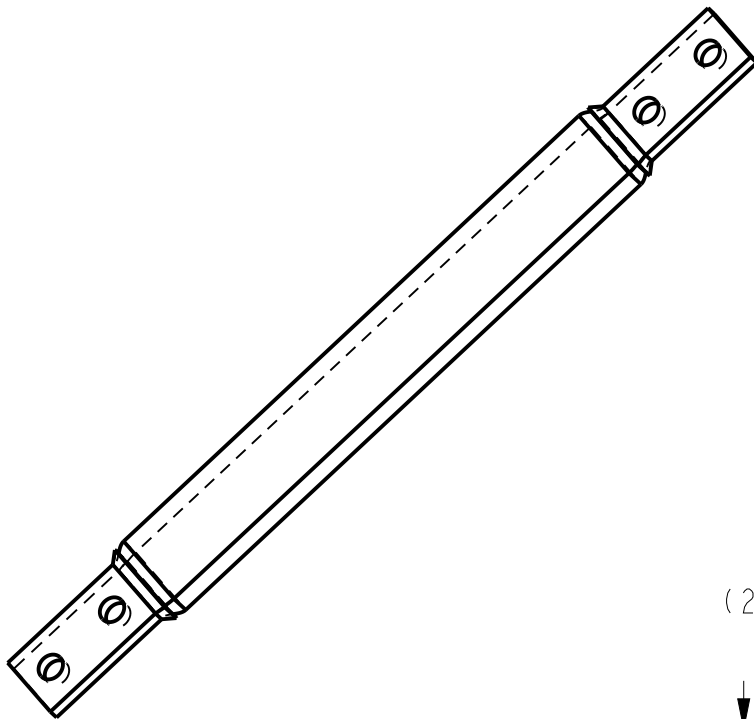

NOTES:

- DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED, AND ARE FOR REFERENCE ONLY.
 - APPROXIMATE AMP RATING: 700 INDOOR, 840 OUTDOOR
THIS MAY VARY WITH AMBIENT CONDITIONS, ORIENTATION OF THE BRAID AND OTHER SERVICE CONDITIONS.
- 3 'UL' SYMBOL FOR INTERNAL SPECIFICATION L4219, LOCATION AND SIZE TO BE DETERMINED BY MANUFACTURING.

TO ORDER BURNDY® PRODUCTS CALL UNITED STATES: 1-800-346-4175 (LONDONDERRY, NH) CANADA: 1-800-361-6975 (QUEBEC) 1-800-387-6487 (ALL OTHER PROVINCES) FOR PRODUCT INFO: http://www.burndy.com		BRAID	
		ITEM NO: (SEE TABLE)	
		CAT. NO: (SEE TABLE)	
		DRAWN BY: R. BOISVERT	03/17/09
		CHECKER: J. PARKER	03/17/09
		DSN APPVL: J. PARKER	01/16/09
		MFG APPVL: --	--
		QA APPVL: J. BRODEUR	01/19/09
		MKT APPVL: P. THERRIEN	03/13/09
		PROD FAM: --	SCALE: 1:2
		PROJECT #: --	DRAWING NO
		DOCUMENT TYPE: Sales	REV
		REL LEVEL: Released	B



4

3

2

1

REV: PE0200

A

A