


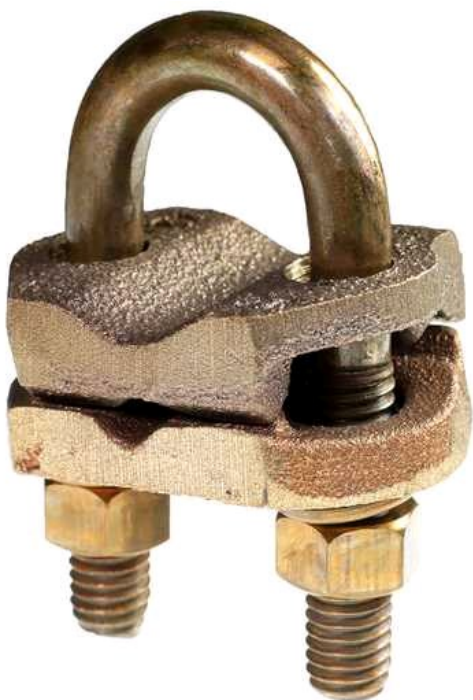

GAR6426SE

by Burndy
Catalog ID: GAR6426SE

Prop 65 Notice

Mechanical Grounding Connector, 4SOL - 2/OSTR PIPE SIZE: 3/8" IPS
ROD SIZE: 5/8" - 3/4" WITH SPLIT LOCK WASHERS DIRECT BURIAL

Product Details

General

Installation Torque Recommended in-lb	240 lb-in
Material	Copper Alloy
Plated	N
Plating Type	Unplated
UPC	781810503973
UPC 12 Digit	7818105039733

Dimensions

Dimension - Height inch	1.50 in
Dimension - L Length Overall mm	40 mm
Dimension - Length Overall inch	1.56 in
Dimension - Width inch	2.06 in
Dimension - Width mm	52 mm

Conductor Related

Conductor - Copper Solid Size Range	4 AWG-2/0 AWG
Conductor - Pipe or Round Tube Size	3/8 in
Conductor - Rod Size	0.625in - 0.75in

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	EX
UL Listed	Yes

Logistics

Minimum Pack Quantity	500
-----------------------	-----

For further technical assistance, please contact us

BURNDY Headquarters
47 East Industrial Park Drive
Manchester, New Hampshire 03109

Customer Service Hours:
8 AM - 8 PM Eastern Monday-Friday
Emergency Service 24-hours/365 Days
Phone: 1-800-346-4175
1-603-647-5299 (International)